

Wire Guards

Type: _____

Project/Location: _____

Contractor: _____

Prepared By: _____


Date: _____

Model No.: _____

EXIT SIGNS

PART #	MOUNTING	SIGNS		DIMENSIONS		
				W	H	D
460.0027-L	End Mount	LER800 Exit LER400 Exit 3000 Series - Nema-4X Exit LTEU Exit LER900 Exit	LMCE Exit LN Series LTSU Sortie LS Series	10 1/2" (26.7 cm)	6" (15.2 cm)	16" (40.6 cm)
460.0028-L	Ceiling Mount	LER800 Exit LER400 Exit 3000 Series - Nema-4X Exit LTEU Exit	LER900 Exit LMCE Exit LN Series LTSU Sortie LS Series	14 1/2" (36.8 cm)	6 1/4" (15.9 cm)	10 1/2" (26.5 cm)
460.0034-L	Wall Mount	RG12S Sortie NH50	RG12S Exit (cab "B") 3LSRSOW4T	28 1/8" (71.5 cm)	21 1/8" (53.7 cm)	10" (25.4 cm)
460.0048-L	End Mount	LSR800 Sortie LSR400 Sortie	LSR900 Sortie LSRLMCSU Sortie	10 1/2" (26.7 cm)	6" (15.2 cm)	21" (53.3 cm)
460.0057-L	Wall Mount	LSR800 Sortie LSR400 Sortie	LSR900 Sortie LSRLMCSU Sortie	20 3/4" (52.7 cm)	10" (25.4 cm)	4" (10.2cm)
460.0058-L	Ceiling Mount	LSR800 Sortie LSR400 Sortie	LSR900 Sortie LSRLMCSU Sortie	21 3/4" (55.2 cm)	5 1/2" (14 cm)	10 1/2" (26.7cm)
460.0059-L	Wall Mount	900B6L bilingual Series LMCSB6L Sortie	400B6L bilingual Series LMCEB6L Exit	31" (86.4 cm)	10" (25.4 cm)	4 1/2" (14 cm)
460.0060-L	End Mount	3000 Series-Nema-4X Exit Combo	8LMCEU EXIT Combo	20" (50.8 cm)	12" (30.5 cm)	15" (38.1 cm)
460.0060-L	Wall Mount	LN Series 3000 Combo	8LMCEU EXIT Combo	20" (50.8 cm)	12" (30.5 cm)	15" (38.1 cm)
460.0078-L	Wall Mount	3LSRLMCSU Sortie Combo Series 3000 Series-Nema-4X Exit Combo	8LMCEU Exit Combo LNC Series Grande Combo	18" (45.7 cm)	18" (45.7 cm)	7" (17.8 cm)
460.0079-L	Wall Mount	LER800 Exit LER400 Exit 3000 Series-Nema-4X Exit LTEU Exit LER900 Exit	LMCE Exit Grande Exit LN Series LS Series LTSU Sortie	14 1/4" (36.2 cm)	9 7/8" (25.0 cm)	4 5/8" (11.7 cm)
460.0080-L	Wall Mount	LER-HZ combo (class1 Div2)	LER-HZ Exit	15 1/4" (38.7 cm)	14 1/8" (35.9 cm)	6 1/2" (16.5 cm)
460.0081-L	Wall Mount	RG12S Exit (cab "A"), LAC, 3LER400 Exit Combo, 3LSR400 Sortie Combo, LSC		20" (50.8 cm)	17 1/8" (43.6 cm)	8 1/2" (21.6 cm)
460.0091-L	Wall Mount	LER400R Exit Series		15" (38.1 cm)	10 1/2" (26.7 cm)	1" (2.5 cm)
460.0092-L	Ceiling Mount	3LSRLMCSU Sortie Combo Series 900B6L Bilingual Series LMCEB6L	8LMCSU Sortie Combo LER400B6L	31" (53.3 cm)	4.5" (11.4 cm)	10" (25.4 cm)
460.0103-L	Wall Mount	SOW4T	LERB12L			
460.0104-L	End Mount	3LSRLMCSU Sortie Combo Series		25" (63.5 cm)	10" (25.4 cm)	20" (50.8 cm)

Type: _____
 Project/Location: _____
 Contractor: _____
 Prepared By: _____
 Date: _____
 Model No.: _____

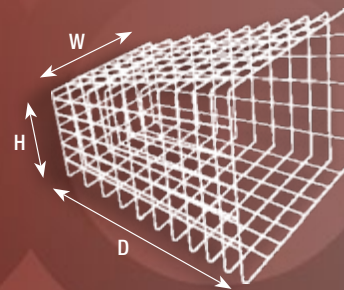

BATTERY UNITS

PART	MOUNTING	COMMERCIAL, DECO UNIT	DIMENSIONS		
			W	H	D
460.0078-L	Wall Mount	"A" Cabinet-6V, 12V, 24V-Max. 144W	18" (45.7 cm)	18" (45.7 cm)	7" (17.8 cm)
460.0081-L	Wall Mount	"B" Cabinet-6V-180W 12V-200 to 360W 24V-200 to 288W	20" (50.8 cm)	17 1/8" (43.6 cm)	8 1/2" (21.6 cm)
460.0034-L	Wall Mount	"C" Cabinet-12V-650watts 24V-350 to 720W	28 1/8" (71.5 cm)	21 1/8" (53.7 cm)	10" (25.4 cm)
460.0097-L	Wall or Ceiling Mount	Q-BIC	31"(53.3cm)	7"(17.8cm)	6"(15.2cm)
SMALL, 6 & 12 VOLT					
460.0080-L	Wall Mount	6V, 12V - 18 to 72watts	15 1/4" (38.7 cm)	14 1/8" (35.9 cm)	6 1/2" (16.5 cm)

REMOTE HEADS

PART	MOUNTING	DIMENSIONS		
		W	H	D
460.0029-L	MT1, MT2, DR1130, MQ, MQM, RSIOWP, WP25, MQM-NX, MQM-NC	8 1/4" (21.cm)	6 1/4" (15.9cm)	6 3/4" (17.2cm)
460.0031-L	RSQB, RG-NX, RS30T, RS20WP	25 1/4" (64.1cm)	8 1/2" (21.5cm)	8 1/2" (21.5cm)
460.0032-L	RSQB2, DR2130, DR2136	9 1/2" (24.1cm)	9 1/2" (24.1cm)	6 1/8" (15.6cm)
460.0033-L	RS22, RS34	9 1/2" (24.1cm)	9 1/2" (24.1cm)	4"(10.2cm)
460.0035-L	RS10, RS10WP, RS10WPRB, RSQB, RS40	8 1/4" (21.5cm)	6 1/4"(15.9cm)	8 1/2" (21.5cm)
460.0082-L	RS20, RS20WP, RS20WPRB, Saf-T-Ray®, Camray®, Phantom®	12"(30.5cm)	9"(22.9cm)	9"(22.9cm)
460.0100-L	DIVIDER®	14"(35.6cm)	5.8"(14.7cm)	5.6"(14.2cm)

MOUNTING SHELVES

PART # 440.0616-L FOR "A" CABINET	PART # 440.0620-L FOR "B" CABINET	PART # 440.0625-L FOR "C" CABINET