


LFP16B RCL

PAR16 floodlight with die cast aluminum housing, integral glare shield and tempered lens. Sleek good looks with minimal size. Supplied with 6" leads and ground wire. Medium base PAR16 lamp, 60 Watt max. Lamp not supplied.

Color: Black

Weight: 0.8 lbs

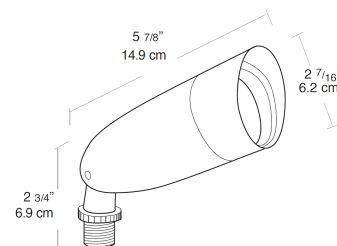

Lamp Info

Type: PAR16
 Watts: 60W
 Shape/Size: N/A
 Base: N/A
 ANSI: N/A
 Hours: 2,000
 Lamp Lumens: 650
 Efficacy: N/A

Ballast Info

Type: N/A
 120V: N/A
 208V: N/A
 240V: N/A
 277V: N/A
 Input Watts: 0W
 Efficiency: N/A

Technical Specifications

cUL Listing:

Suitable for wet locations. Suitable for mounting within 1.2m (4ft) of the ground.

Swivels:

1/2" NPS threaded arm with serrated locking swivel fits all standard mounting boxes. EZ Grip locknuts color matched to fixture.

Housings:

Precision die cast aluminum.

Compatibility:

Fixture is compatible with GE and Sylvania Par16 lamps. Not compatible with Philips Par16 lamp.

Voltage:

120.

Patents:

RC sensor and fixture designs are protected under Canadian and International Intellectual Property laws.

Sockets:

Medium base porcelain with all copper current carrying components and spring loaded center contact.