


# STL110 RCL

STEALTH Sensor with 110° view. Double Look Down lens, surge protection, LED detection indicator and Color Matched Lens.

Color: Bronze

Weight: 1.1 lbs

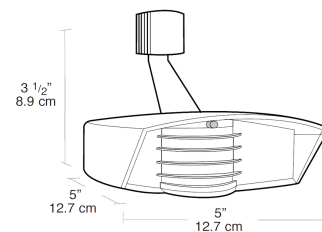

## Technical Specifications

### cUL Listing:

Suitable for wet locations.

### Power Consumption:

1 watt.

### Time Adjustment:

5 seconds to 12 minutes.

### Surge Protection:

Withstands up to 6000 volts.

### Wide Sensitivity Control:

Adjustable from 100% to 30%.

### Temperature Compensation:

Sensitivity adjusts automatically for consistent detection in hot and cold ambient temperatures.

### Wall Switch Manual Override:

Two flip logic prevents activation by momentary power outages. Override resets to auto at dawn. No extra wiring needed.

### LED Detection Indicator:

Shows when sensor is detecting in daytime and glows red at night for "on-guard" deterrence.

### Advanced Detection Logic:

Minimizes false triggers.

### Color Matched Lens:

Dark lens with bronze units, white lens with white units.

### RF Immunity:

Circuits fully shielded for maximum radio frequency immunity.

### Horizontal Lock, No-tool Joints:

Keeps sensing pattern level for fast, error-free installation.

### Photoelectric Control:

Deactivates lights during daylight. fully adjustable for 24 hour operation or custom applications.

### Floodlights:

Precision die cast aluminum. 1/2" NPS threaded arm with serrated locking swivel fits all standard mounting boxes and covers.

### Voltage:

120 Volts AC 60 Hertz.

### Detection:

Angle of view = 110°

Recommended Mounting Height = 10'-0"

Maximum Recommended Look-Out Zone = 50'-0"

### Switching Capacity:

1000 watts incandescent @ 120 volts, 8 amps.

### Patents:

RC sensor and fixture designs are protected under Canadian and International Intellectual Property laws.

### Warranty:

10 year sensor warranty.