


# WP2F84 RCL

Mid sized wallpack. All aluminum precision die cast construction with tempered glass refractor. Lamp supplied.

Color: Bronze

Weight: 10.9 lbs

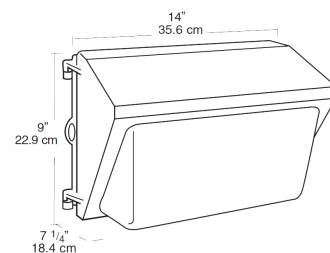

## Lamp Info

Type: 2-42W Triple  
 Watts: 84W  
 Shape/Size: N/A  
 Base: N/A  
 ANSI: N/A  
 Hours: 12,000  
 Lamp Lumens: 6,400  
 Efficacy: 69 LPW

## Ballast Info

Type: Elec HPF QT  
 120V: 0.78A  
 208V: 0.5A  
 240V: 0.5A  
 277V: 0.33A  
 Input Watts: 93W  
 Efficiency: 90%

## Technical Specifications

### cUL Listing:

Suitable for wet locations. HID fixtures can be wired with 90°C supply wiring if supply wires are routed 3" away from ballast.

### Housing:

Die cast aluminum, 1/2" NPS tapped holes top, both sides and back for conduit or photocontrol. Hinged refractor frame. Continuous silicone rubber gasket.

### Reflector:

specular anodized aluminum, removable for installation. Symmetrical light pattern maximizes distance between fixtures.

### Cutoff Lens:

Tempered glass.

### Refractor:

Prismatic optics designed to minimize glare and throw light down and out. Heat resistant borosilicate glass.

### Finish:

Our environmentally friendly polyester powder coatings are formulated for high-durability and long-lasting color, and contains no VOC or toxic heavy metals.

### Patents:

RC sensor and fixture designs are protected under Canadian and International Intellectual Property laws.

### Ballast Minimum Starting Temperature:

0°F.

