


PS 1300 – Universal Clamp for EMT, IMC & GRC

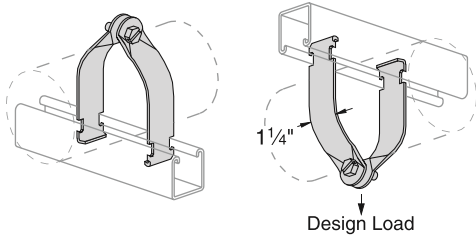

| Nominal Size | Fits O.D. | Stock Thickness | Hanging Load Rating/lbs. | Wt./100 pcs |
|--------------|-------------|-----------------|--------------------------|-------------|
| 1/2" | .706-.840 | .060 | 250 | 10 |
| 3/4" | .922-1.050 | .060 | 400 | 11 |
| 1" | 1.163-1.315 | | | 12 |
| 1 1/4" | 1.510-1.660 | .075 | 400 | 18 |
| 1 1/2" | 1.740-1.900 | .075 | 500 | 20 |
| 2" | 2.197-2.375 | | | 22 |

MATERIAL:

Power-Strut pipe, conduit and O.D. tubing clamps are made on punch press dies from hot rolled, pickled and oiled steel which conforms to the ASTM A-1008, A-1011 SS, A-575 and A-576 standards. Select sizes of O.D. tubing clamps are available in stainless steel or aluminum.

STANDARD FINISH:

All steel clamps are electro-galvanized. Select sizes of O.D. tubing clamps are available in copper plated finish. PVC coatings are available upon special request.

ORDERING INFORMATION:

When ordering, add the length or size and finish to the part number.

RECOMMENDED BOLT TORQUE:

| Bolt Size | 1/4"-20 | 5/16"-18 | 3/8"-16 | 1/2"-13 | 5/8"-11 | 3/4"-10 |
|--------------------|---------|----------|---------|---------|---------|---------|
| Rec. Torque Ft/Lbs | 6 | 11 | 19 | 50 | 100 | 125 |
| Max. Torque Ft/Lbs | 7 | 15 | 25 | 70 | 125 | 135 |

Project: _____
 Architect / Engineer: _____
 Date: _____ Phone: _____
 Contractor: _____
 Address: _____

Approval Stamp:

Notes 1: _____

Notes 2: _____