

# ACCESSORIES AND SUPPORTING DATA

## AVAILABLE COLOR TEMPERATURES




**12VDC  
POWER  
SUPPLY  
REQUIRED**

12VDC  
ELECTRONIC  
DIMMING  
PAGE 158-160

12VDC  
ELECTRONIC  
NON-DIM  
PAGE 161

12VDC  
MAGNETIC  
DIMMABLE  
PAGE 163-164

### CONNECTORS

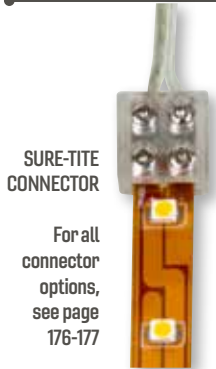

**SURE-TITE  
CONNECTOR**


For all  
connector  
options,  
see page  
176-177

### MOUNTING CHANNELS

This LED tape will fit into the following  
mounting channels:

- LED-CHL
- LED-CHL-45
- LED-CHL-45-1200\*
- LED-CHL-BND
- LED-CHL-D
- LED-CHL-W\*
- LED-CHL-XD\*
- LED-CHL-XD-F\*
- LED-CHL-XD-MD\*
- LED-CHL-XD-MD-F\*

\*Accepts Sure-Tite connectors

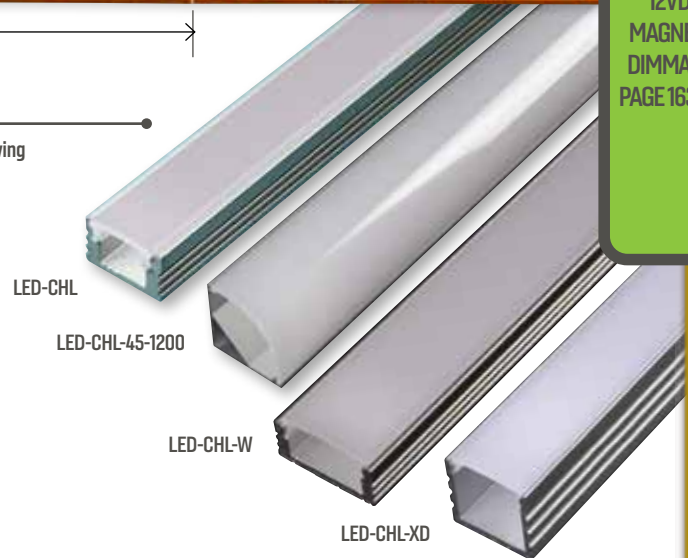

## CONNECTORS AND ACCESSORIES

Catalog No.	Description
STC-1	Sure-Tite tape to tape connector
STC-90	90° Sure-Tite connector
STLK-60	60" Sure-Tite flexible tape to tape connector
STW-60	60" Sure-Tite flexible tape to power supply connector
STW-CO	Sure-Tite tape to power supply connector only (no wire)
GMSB-W(B)	Splice Box in white (W) or black (B) 2" L x 1" W x 5/8" D

### CONNECTOR AND CHANNEL NOTES:

See connector compatibility chart, page 82.

For additional channel options, solder lead / connection options and channel mill work dimensions, see page 176.

Complete tape and channel compatibility matrix on page 176.