

## Insulated Industrial BiCut SuperCut



Cutting capacity up to 3mm hardened piano wire



⚡ 1000volt




- Double the power at the press of a button
- BiCut does the job of two pairs of pliers
- Up to 50% less hand strength required for cutting
- Cutting force doubled for extremely hard materials
- Easily switch between two strengths in one-handed operation

**32936 Insulated Industrial BiCut SuperCut. Insulation According to VDE 0682/part 201, EN/IEC 60900, ASTM F-1505, NFPA70E & CSA, up to 1000 Volt. Individually Tested.** Durable cutting is achieved through additional inductive hardening to approx. 64HRC. Drop forged of high C70 steel. For cutting various materials from soft to extremely hard, such as nails, screws, bolts, wire cables, spring wires, chains, etc.

| Item No. | mm  | Inch | Pkg. | lbs. |
|----------|-----|------|------|------|
| 32936    | 200 | 8.0  | 1    | .78  |

## Insulated BiCut SuperCut & Screwdriver Set

Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

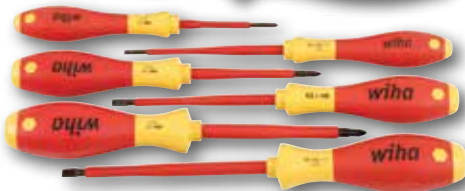

⚡ 1000volt

### 32942 7 Pc. Insulated Industrial BiCut SuperCut & Screwdrivers

Ergonomic two component molded grips. 10,000 Volt tested

| Item No.                             | Insulated BiCut SuperCut: |
|--------------------------------------|---------------------------|
| 32942                                | 8.0"/200mm BiCut SuperCut |
| Insulated Cushion Grip Screwdrivers: |                           |
| lbs.                                 | Phillips: #0, #1, #2      |
| 1.86                                 | Slotted: 3.0, 4.5, 5.5mm  |

## Wiha Insulated Industrial Tool Sets



Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

Individually Tested

⚡ 1000Volt

### 32981 3 Pc. Insulated Industrial Pliers & Cutters

| Item No. | Insulated Pliers & Cutters                                 |
|----------|--|
| 32981    | 8.0" Combo Pliers, 8.0" Long Pliers, 8.0" Diagonal Cutters |
|          | lbs. 2.18  |



Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

Individually Tested



⚡ 1000Volt

### 32983 5 Pc. Insulated Industrial Diagonal Cutters & Screwdrivers

| Item No. | Insulated Diagonal Cutters & Screwdrivers                 |
|----------|---|
| 32983    | 6.3"/160mm Diagonal Cutter                                |
|          | Insulated Drivers: Slotted: 3.0, 4.5mm • Phillips: #1, #2 |
|          | lbs. 1.17   |



Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

Individually Tested



⚡ 1000Volt

### 32984 6 Pc. Insulated Industrial Combo Pliers & Screwdrivers

| Item No. | Insulated Combination Pliers & Screwdrivers              |
|----------|--|
| 32984    | 8.0" Combination Pliers & 8" Long Nose Pliers            |
|          | Drivers: Slotted: 3.0, 4.5mm • Phillips: #2 • Square: #2 |
|          | lbs. 2.06  |


**Wiha Insulated Industrial Tool Sets**



**32982 3 Pc. Insulated Industrial Pliers/Cutters & Voltage Detector**

|                 |  |
|-----------------|--|
| <b>Item No.</b> | <b>Insulated Pliers/Cutters &amp; Cat. III Voltage Detector</b>                              |
| <b>32982</b>    | 6.3" Long Pliers, 6.3" Diagonal Cutters<br>Voltage Detector with both light and sound alerts |
|                 | 🔧 lbs. .98   |

**Wiha Insulated Tool Tray Sets**

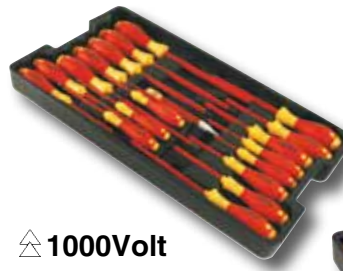

Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

⚡ **1000Volt**

Tool box set in blow molded trays



Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

⚡ **1000Volt**

Tool box set in blow molded tray

**32999 9 Piece Insulated Industrial Pliers & Cutters Set**

Insulated pliers & cutters set in a light weight tool box tray.

|                 |                       |                             |
|-----------------|-----------------------|-----------------------------|
| <b>Item No.</b> | 9.0" Lineman's Pliers | 8.0" High Lev. Combo Pliers |
| <b>32999</b>    | 6.3" Long Nose Pliers | 8.0" Cable Cutters          |
|                 | 8.0" Long Nose Pliers | 6.3" Stripping Pliers       |
|                 | 6.3" Diagonal Cutters | 7.0" Crimping Pliers        |
|                 | 8.0" Diagonal Cutters |                             |
|                 | lbs. 6.34             |                             |



In canvas tool bag

⚡ **1000Volt**



In Belt Pack Pouch

Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards



⚡ **1000Volt**

**32985 7 Pc. Insulated Industrial Pliers/Cutters & Screwdrivers**

|                 |  |
|-----------------|--|
| <b>Item No.</b> | <b>Insulated Pliers/Cutters &amp; Screwdrivers</b>   |
| <b>32985</b>    | 8.0" Combo Pliers, 6.3" Long Nose, 6.3" Diagonal Cutters<br><b>Insulated Drivers:</b> Slotted: 3.0, 4.5mm • Phillips: #1, #2 |
|                 | 🔧 lbs. 2.30  |

**32977 11 Pc. Pliers & Driver Set. Insulation According to VDE**

0682/part 201, EN/IEC 60900, ASTM F-1505, NFPA70E & CSA, up to 1000 volt. Individually Tested. In canvas tool bag

|                    |                                |                                    |
|--------------------|--------------------------------|------------------------------------|
| <b>Item# 32977</b> | <b>Set Includes:</b>           | 🔧 lbs. 6.30                        |
|                    | 8.0" Combination Pliers        | 6.3" Long Nose Pliers W/Cutter     |
|                    | 8.0" Long Nose Pliers W/Cutter | 6.3" Diagonal Cutter               |
|                    | 8.0" High Leverage Cutter      |                                    |
|                    | Insulated Phillips: #0, 1, 2   | Insulated Slotted: 3.0, 4.0, 6.5mm |