

Insulated Industrial BiCut SuperCut



Cutting capacity up to 3mm hardened piano wire



⚡ 1000volt




- Double the power at the press of a button
- BiCut does the job of two pairs of pliers
- Up to 50% less hand strength required for cutting
- Cutting force doubled for extremely hard materials
- Easily switch between two strengths in one-handed operation

32936 Insulated Industrial BiCut SuperCut. Insulation According to VDE 0682/part 201, EN/IEC 60900, ASTM F-1505, NFPA70E & CSA, up to 1000 Volt. Individually Tested. Durable cutting is achieved through additional inductive hardening to approx. 64HRC. Drop forged of high C70 steel. For cutting various materials from soft to extremely hard, such as nails, screws, bolts, wire cables, spring wires, chains, etc.

Item No.	mm	Inch	Pkg.	lbs.
32936	200	8.0	1	.78

Insulated BiCut SuperCut & Screwdriver Set

Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

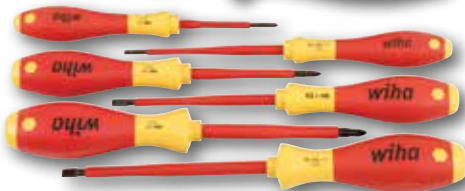

⚡ 1000volt

32942 7 Pc. Insulated Industrial BiCut SuperCut & Screwdrivers

Ergonomic two component molded grips. 10,000 Volt tested

Item No. Insulated BiCut SuperCut:

32942 8.0"/200mm BiCut SuperCut

Insulated Cushion Grip Screwdrivers:

lbs. Phillips: #0, #1, #2

1.86 Slotted: 3.0, 4.5, 5.5mm

Wiha Insulated Industrial Tool Sets



Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

Individually Tested

⚡ 1000Volt

32981 3 Pc. Insulated Industrial Pliers & Cutters

Item No. Insulated Pliers & Cutters

32981 8.0" Combo Pliers, 8.0" Long Pliers, 8.0" Diagonal Cutters

⚖ lbs. 2.18



Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

Individually Tested

⚡ 1000Volt

32983 5 Pc. Insulated Industrial Diagonal Cutters & Screwdrivers

Item No. Insulated Diagonal Cutters & Screwdrivers

32983 6.3"/160mm Diagonal Cutter

Insulated Drivers: Slotted: 3.0, 4.5mm • Phillips: #1, #2

⚖ lbs. 1.17



Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

Individually Tested

⚡ 1000Volt

32984 6 Pc. Insulated Industrial Combo Pliers & Screwdrivers

Item No. Insulated Combination Pliers & Screwdrivers

32984 8.0" Combination Pliers & 8" Long Nose Pliers

Drivers: Slotted: 3.0, 4.5mm • Phillips: #2 • Square: #2


⚖ lbs. 2.06

Wiha Insulated Industrial Tool Sets



32982 3 Pc. Insulated Industrial Pliers/Cutters & Voltage Detector
Item No. Insulated Pliers/Cutters & Cat. III Voltage Detector
32982 6.3" Long Pliers, 6.3" Diagonal Cutters
 Voltage Detector with both light and sound alerts
 lbs. .98


Wiha Insulated Tool Tray Sets

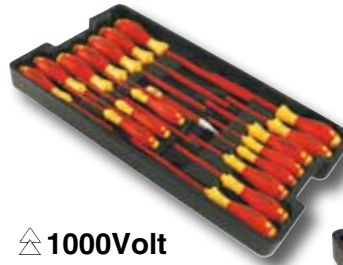

Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

1000Volt

Tool box set in blow molded trays

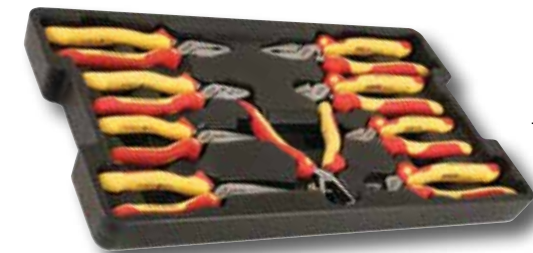

Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards

1000Volt

Tool box set in blow molded tray

32999 9 Piece Insulated Industrial Pliers & Cutters Set
 Insulated pliers & cutters set in a light weight tool box tray.

Item No.	9.0" Lineman's Pliers	8.0" High Lev. Combo Pliers
32999	6.3" Long Nose Pliers	8.0" Cable Cutters
	8.0" Long Nose Pliers	6.3" Stripping Pliers
lbs.	6.3" Diagonal Cutters	7.0" Crimping Pliers
6.34	8.0" Diagonal Cutters	



In canvas tool bag

1000Volt



In Belt Pack Pouch

Tools meet ASTM, IEC, VDE, EN, NFPA & CSA standards



1000Volt

32985 7 Pc. Insulated Industrial Pliers/Cutters & Screwdrivers
Item No. Insulated Pliers/Cutters & Screwdrivers
32985 8.0" Combo Pliers, 6.3" Long Nose, 6.3" Diagonal Cutters
Insulated Drivers: Slotted: 3.0, 4.5mm • Phillips: #1, #2
 lbs. 2.30

32977 11 Pc. Pliers & Driver Set. Insulation According to VDE 0682/part 201, EN/IEC 60900, ASTM F-1505, NFPA70E & CSA, up to 1000 volt. Individually Tested. In canvas tool bag
Item# 32977 Set Includes: lbs. 6.30

8.0" Combination Pliers	6.3" Long Nose Pliers W/Cutter
8.0" Long Nose Pliers W/Cutter	6.3" Diagonal Cutter
8.0" High Leverage Cutter	
Insulated Phillips: #0, 1, 2	Insulated Slotted: 3.0, 4.0, 6.5mm