

TRACJACK

Clarity Unshielded Modules



TracJack® modules combine the ease and reliability of a front-loading individual jack with popular 110 termination and offer universal T568A/B wiring.

OR-TJ6A Clarity 6A/10G Category 6A TracJacks



OR-TJ6A-99

Clarity 6A/10G Category 6A TracJacks

Clarity® 6A TracJacks offer the elevated performance of quad reactance to minimize internal crosstalk and reduce the injection of common mode noise, a significant source of alien crosstalk. These connectors work with Clarity 6A patch cords to provide a nearly transparent signal path for enhanced signal-to-noise (internal and alien) performance.

These front-loading jacks are icon-compatible and can be used in any TracJack workstation outlet. Meets TIA 568C.2 Category 6A component specifications.

PART NO.	DESCRIPTION
OR-TJ6A	Clarity 6A/10G, 180° exit, fog white

Notes: T568A/B wiring.

Clarity 6A jacks are available in these colors: -00=black, -36=blue, -42=red, -43=orange, -44=yellow, -45=green, -68=Wiremold® gray, -88=white, -99=Wiremold ivory. Add tailcode to end of part number.

OR-TJ6, OR-TJ5E Clarity 6 and Clarity 5E Center Tuned, Enhanced Category 6 and 5e TracJacks



OR-TJ600



OR-TJ645



OR-TJ5E00



OR-TJ5E45

Clarity 6 and Clarity 5E Center Tuned, Enhanced Category 6 and 5e TracJacks


Clarity TracJacks feature the improved performance of center tuned Category 6 or 5e connector technology. Enhanced IDC designs make it easier to terminate, while reducing the size of the jack. Clarity 6 and 5E TracJacks are available in flat or angled.

PART NO.	DESCRIPTION
OR-TJ600	Clarity 6 jack, 8-position, 180° exit, fog white
OR-TJ645	Clarity 6 jack, 8-position, 45° exit, fog white
OR-TJ5E00	Clarity 5e jack, 8-position, 180° exit, fog white
OR-TJ5E45	Clarity 5e jack, 8-position, 45° exit, fog white

Notes: T568A/B wiring. Icon compatible.

See color chart below for available colors.

COLOR OPTIONS

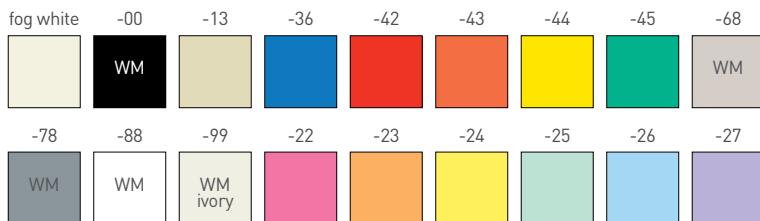

Notes: Clarity TJ5E00 and TJ600 jacks are available in all colors listed above. The Clarity TJ5E45 and TJ645 are not available in colors 22-27. WM indicates Wiremold color match. These color samples correspond with the tail codes inserted at the end of Legrand® part numbers (ex: OR-TJ600-45). Fog white is standard, requiring no tail code. Consult sales for availability and other colors.

Notes: All Ortronics® product dimensions are listed by width, height and depth unless specified otherwise.

TRACJACK

Additional TracJack Modules and Clarity Shielded Modules

OR-63730003, OR-63700005 Additional TracJack Modules



OR-63730003



OR-63700005

Additional TracJack Modules

PART NO.	DESCRIPTION
OR-63730003	Category 3 jack, 8-position, 180° exit, T568A/B wiring, icon compatible
OR-63700005*	RJ25 jack, 6-position, 180° exit, USOC wiring, icon compatible

Notes: Standard color for TracJack modules is fog white.

*Indicates also available in -99 Wiremold® ivory and -88 white. Contact Legrand sales department for other colors.

Shielded Jacks

Legrand® offers 2 jack options for workstation applications. In the TracJack® footprint, the TJS family is front loading, 110 terminated solution. For Keystone applications, TKS jacks provide a tool less self terminating, rear loading jack. Both are support above the standards shielded channel performance.

- Exceeds ISO 11801 2nd edition, including EN50173 2nd edition
- Exceeds TIA 568c.2 component specifications
- Easy to follow universal writing labels

OR-TJS6A, OR-TJS6, OR-TJS5E Clarity Shielded, Category 6A, 6 and 5e TracJacks



OR-TJS600

Clarity Shielded, Category 6A, 6 and 5e TracJacks

Legrand shielded TracJacks are available in Category 6A, 6, 5E and 110 terminated, tuned to Clarity® shielded patch cords for optimized performance that is measurable in the channel.

PART NO.	DESCRIPTION
OR-TJS6A	Clarity 6A, Category 6A shielded jack, 8-position, 180° exit
OR-TJS600	Clarity 6, Category 6 shielded jack, 8-position, 180° exit
OR-TJS5E00	Clarity 5E, Category 5e shielded jack, 8-position, 180° exit

Notes: T568A/B wiring.

OR-TKS6A Shielded, Category 6A, Keystone Jack



OR-TKS6A

Shielded, Category 6A, Keystone Jack

Legrand shielded Keystone jacks, available in 6A, utilize a tool less self terminating design and are tuned to Clarity 6A shielded patch cords for optimized performance that is measurable in the channel.

PART NO.	DESCRIPTION
OR-TKS6A	Category 6A shielded self terminating jack, 8-position rear loading

Notes: See page XX for Keystone faceplates.



TRACJACK

Faceplates

Legrand® offers a full range of TracJack® faceplates in plastic or stainless steel, with a variety of port capacities to match your workstation applications. All TracJack plates offer recessed label fields and slotted screw holes to adjust alignment. They are ruggedly constructed from high impact thermo-plastic 94V-0 rated to ensure long life. Two to 12-port plastic wall plates now include the ability to rear-load TracJack modules.

OR-403005

Single Gang Plastic TracJack Faceplates



OR-40300549



OR-40300548



OR-40300547



OR-40300546



OR-40300545

Single Gang Plastic TracJack Faceplates

PART NO.	DESCRIPTION
OR-40300549	Holds (1) TracJack, 2.75" x 4.5"
OR-40300548	Holds (2) TracJacks, 2.75" x 4.5"
OR-40300547	Holds (3) TracJacks, 2.75" x 4.5"
OR-40300546	Holds (4) TracJacks, 2.75" x 4.5"
OR-40300545	Holds (6) TracJacks, 2.75" x 4.5"

Notes: Standard color for plastic TracJack faceplates is fog white. For ivory add -13, for white add -88 and for Wiremold® ivory add -99 to end of part number. For other colors, contact sales.

OR-403STJ

Single Gang Stainless Steel TracJack Faceplates



OR-403STJ11



OR-403STJ12



OR-403STJ13



OR-403STJ14



OR-403STJ16

Single Gang Stainless Steel TracJack Faceplates

PART NO.	DESCRIPTION
OR-403STJ11	Holds (1) TracJack, 2.75" x 4.5"
OR-403STJ12	Holds (2) TracJacks, 2.75" x 4.5"
OR-403STJ13	Holds (3) TracJacks, 2.75" x 4.5"
OR-403STJ14	Holds (4) TracJacks, 2.75" x 4.5"
OR-403STJ16	Holds (6) TracJacks, 2.75" x 4.5"

OR-40300

Double Gang Plastic TracJack Faceplates



OR-40300555



OR-40300554



OR-40300620

Double Gang Plastic TracJack Faceplates

PART NO.	DESCRIPTION
OR-40300555	Holds (6) TracJacks, 4.5" x 4.5"
OR-40300554	Holds (8) TracJacks, 4.5" x 4.5"
OR-40300620	Holds (12) TracJacks, 4.5" x 4.5"

Notes: Standard color for TracJack plastic faceplates is fog white. For other available colors, contact sales.