

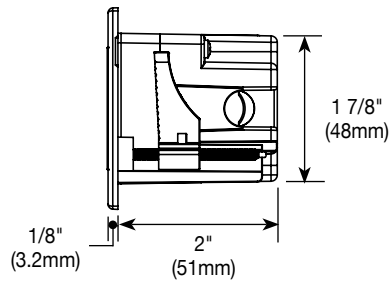
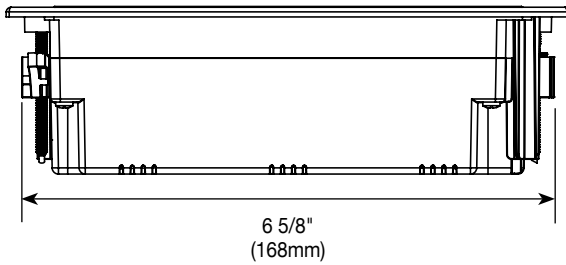


RD4R

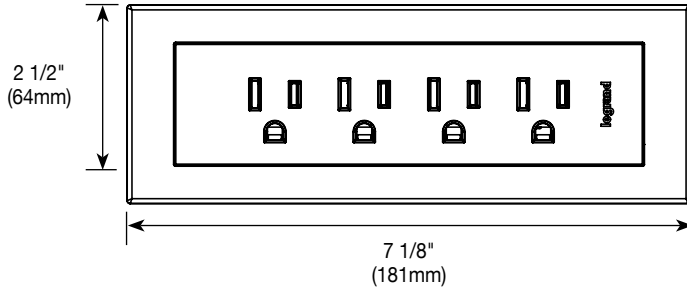

Ordering Information

RD2RBK
RD2RWH
RD2RNI

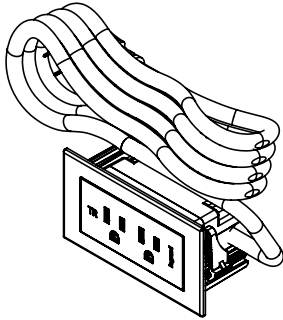

Power Only Two Outlet Unit (RD2Rxx) –


Two (2) tamper-resistant (TR) receptacles. 6' (1.83m) cord with pass-thru plug. Receptacles rated 15A, 125Vac. Overall dimensions 4 9/16" wide by 2 1/2" tall by 2 1/8" deep (116mm x 64mm.x.54mm). Mounting flange is 1/8" (3.2mm) thick. Requires a hole cut of 5 1/4" wide by 2" high (133mm x 51mm). Available in black (RD2RBK), white (RD2RWH), and nickel (RD2RNI).

RD2RBK10
RD2RWH10
RD2RNI10

Power Only Two Outlet Unit with 10' Power Cord (RD2Rxx10) –

Same as Power Only Unit but with 10' (3.1m) cord with pass-thru plug. Available in black (RD2RBK10), white (RD2RWH10) and nickel (RD2RNI10).

RD3RBK
RD3RWH
RD3RNI

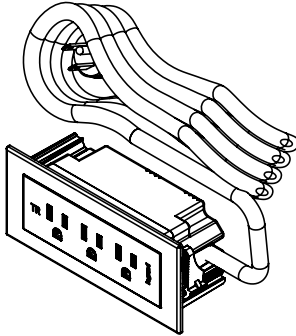

Power Only Three Outlet Unit (RD3Rxx) –


Three (3) tamper-resistant (TR) receptacles. 6' (1.83m) cord with pass-thru plug. Receptacles rated 15A, 125Vac. Overall dimensions 5 3/4" wide by 2 1/2" tall by 2 1/8" deep (146mm x 64mm.x.54mm). Mounting flange is 1/8" (3.2mm) thick. Requires a hole cut of 5 1/4" wide by 2" high (133mm x 51mm). Available in black (RD3RBK), white (RD3RWH), and nickel (RD3RNI).

RD3RBK10
RD3RWH10
RD3RNI10

Power Only Three Outlet Unit with 10' Power Cord (RD3Rxx10) –

Same as Basic Power Unit but with 10' (3.1m) cord with pass-thru plug. Available in black (RD3RBK10), white (RD3RWH10) and nickel (RD3RNI10).

RD4RBK
RD4RWH
RD4RNI

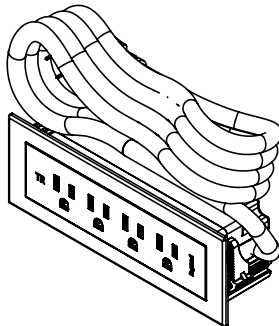

Power Only Four Outlet Unit (RD4Rxx) –

Four (4) tamper-resistant (TR) receptacles. 6' (1.83m) cord with pass-thru plug. Receptacles rated 15A, 125Vac. Overall dimensions 7 1/8" wide by 2 1/2" tall by 2 1/8" deep (181mm x 64mm.x.54mm). Mounting flange is 1/8" (3.2mm) thick. Requires a hole cut of 5 1/4" wide by 2" high (133mm x 51mm). Available in black (RD4RBK), white (RD4RWH), and nickel (RD4RNI).


RD4RBK10
RD4RWH10
RD4RNI10

Power Only Four Outlet Unit with 10' Power Cord (RD4Rxx10) –

Same as Basic Power Unit but with 10' (3.1m) cord with pass-thru plug. Available in black (RD4RBK10), white (RD4RWH10) and nickel (RD4RNI10).


Ordering Information

RDB2BK
RDB2WH
RDB2NI

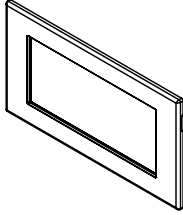


Replacement Bezel for Power Only Two Outlet Unit (RDB2xx) – Overall dimensions 4 9/16" wide by 2 1/2" tall by 1/8" thick (116mm x 64mm x 3.2mm). Available in black (RDB2BK), white (RDB2WH) and nickel (RDB2NI).

RDBBK
RDBWH
RDBNI

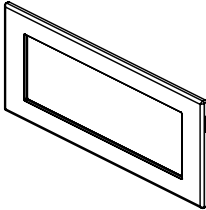

Replacement Bezel for Basic Power Unit & Power Only Three Outlet Unit (RDBxx) – Overall dimensions 5 5/8" wide by 2 1/2" tall by 1/8" thick (143mm x 64mm x 3.2mm). Available in black (RDBBK), white (RDBWH) and nickel (RDBNI).

RDSBBK
RDSBWH
RDSBNI

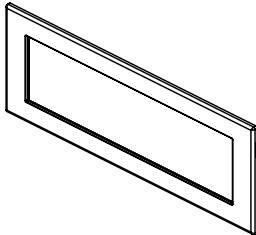

Replacement Bezel for Switching Unit & Power Only Four Outlet Unit (RDSBxx) – Overall dimensions 7 1/8" wide by 2 1/2" tall by 1/8" deep (181mm x 64mm x 3.2mm). Available in black (RDSBBK), white (RDSBWH) and nickel (RDSBNI).