

**M18 FUEL**  
**1/2" Hammer Drill/Driver w/ ONE-KEY™ Kit**

2706-22 (2706-20 Tool-Only)

**Specifications:**

Peak Torque	1,200 in-lbs
RPM	0 – 550 / 0 – 2,000
BPM	0 – 32,000
DRIVE CONTROL™	4-Mode (Customizable)
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-3/5"
Weight	4.9 lbs

**Includes:** (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Side Handle, Multi-Voltage Charger, Carrying Case



**M18™ 1/2" Hammer Drill/Driver Kit**

2607-22, 2607-22CT (2607-20 Tool-Only)

**Specifications:**

Peak Torque	525 in-lbs
RPM	0 – 450 / 0 – 1,800
BPM	0 – 28,800
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-3/4"
Weight	4.5 lbs

**Includes:** 2607-22 (2) M18™ REDLITHIUM™ XC Extended Capacity Battery Packs, Multi-Voltage Charger, Carrying Case; 2607-22CT Includes (2) M18™ REDLITHIUM™ Compact Battery Packs



**M18 FUEL**  
**1/2" Hammer Drill/Driver Kit**

2704-22 (2704-20 Tool-Only)

**Specifications:**

Peak Torque	1,200 in-lbs
RPM	0 – 550 / 0 – 2,000
BPM	0 – 32,000
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-3/4"
Weight	4.9 lbs

**Includes:** (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Side Handle, Multi-Voltage Charger, Carrying Case



**M18 FUEL**  
**1/2" Drill/Driver w/ ONE-KEY™ Kit**

2705-22 (2705-20 Tool-Only)

**Specifications:**

Peak Torque	1,200 in-lbs
RPM	0 – 550 / 0 – 2,000
DRIVE CONTROL™	4-Mode (Customizable)
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-1/5"
Weight	4.8 lbs

**Includes:** (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Side Handle, Multi-Voltage Charger, Carrying Case



**M18™ 1/2" Compact Brushless Hammer Drill/Driver Kit**

2702-22CT (2702-20 Tool-Only)

**Specifications:**

Peak Torque	1,500 in-lbs
RPM	0 – 450 / 0 – 1,800
BPM	0 – 28,800
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-3/8"
Weight	3.8 lbs

**Includes:** (2) M18™ REDLITHIUM™ 2.0 Compact Battery Packs, Multi-Voltage Charger, Carrying Case



**M18 FUEL**  
**1/2" Drill/Driver Kit**

2703-22 (2703-20 Tool-Only)

**Specifications:**

Peak Torque	1,200 in-lbs
RPM	0 – 550 / 0 – 2,000
Chuck type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	7-1/2"
Weight	4.9 lbs

**Includes:** (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Side Handle, Multi-Voltage Charger, Carrying Case



**M18™ 1/2" Compact Brushless Drill/Driver Kit**

2701-22CT (2701-20 Tool-Only)

**Specifications:**

Peak Torque	500 in-lbs
RPM	0 – 450 / 0 – 1,800
Chuck Type	1/2" Metal Single Sleeve – Ratcheting Lock
Length	6-7/8"
Weight	3.7 lbs

**Includes:** (2) M18™ REDLITHIUM™ 2.0 Compact Battery Packs, Multi-Voltage Charger, Carrying Case



**M18™ 3/8" Right Angle Drill/Driver Kit**

2615-21, 2615-21CT (2615-20 Tool-Only)

**Specifications:**

Peak Torque	125 in-lbs
RPM	0 – 1,500
Clutch Settings	11 Settings plus Drill Mode
Chuck Type	3/8" Single Sleeve
Head Profile	3-3/4"
Weight	4.3 lbs

**Includes:** 2615-21 (1) M18™ REDLITHIUM™ XC Extended Capacity Battery Pack, Multi-Voltage Charger, Carrying Case; 2615-21CT Includes (1) M18™ REDLITHIUM™ Compact Battery Pack



**M18 FUEL**  
**Drywall Screw Gun Kit**


2866-22, 2866-22CT (2866-20 Tool-Only)

**Specifications:**

RPM	0 – 4,500
Belt Clip	Yes
Auto Start Mode	Yes
Length	9"
Weight	4.1 lbs

**Includes:** 2866-22 (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, PR2 Bit, Multi-Voltage Charger, Contractor Bag; 2866-22CT Includes (2) M18™ REDLITHIUM™ 2.0 Compact Battery Packs

**Related Accessory:**  
49-20-0001 MILWAUKEE® Collated Magazine  
Screw Capacity: Up to 2"  
Compatible with all major screw brands

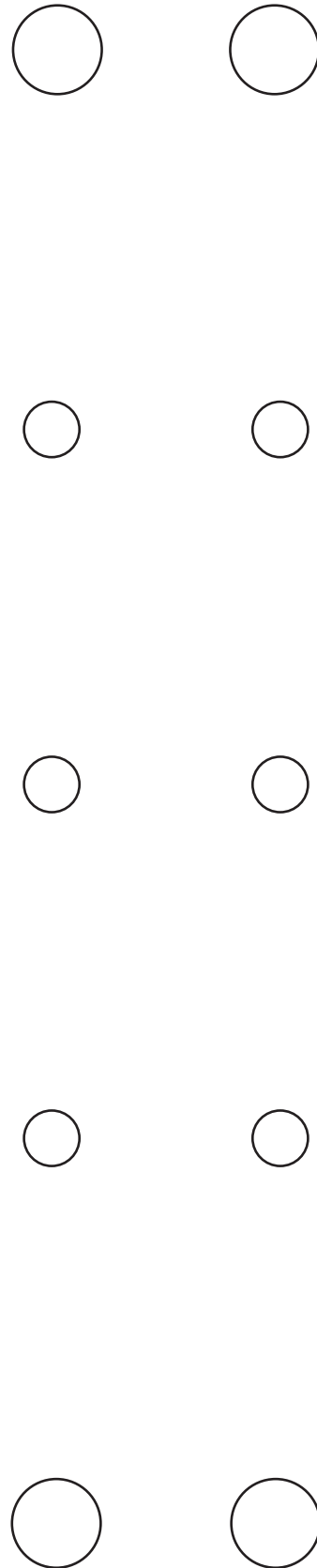





**M18 FUEL**  
**SUPER HAWG™ 1/2" Right Angle Drill Kit**

2709-22HD, 2709-22 (2709-20 Tool-Only)

**Specifications:**

RPM	0 – 350 / 0 – 950
Chuck Type	1/2" Metal Keyed
Capacity	For Self-Feed Bits up to 4-5/8"; Hole Saws up to 6"
Mechanical Clutch	Yes
Length	22"
Weight	14.9 lbs

**Includes:** 2709-22HD (2) M18™ REDLITHIUM™ HIGH DEMAND™ 9.0 Battery Packs, Chuck Key, Side Handle, Rapid Charger, Contractor Bag; **2709-22** Includes (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs



**M18 FUEL**  
**HOLE HAWG® Right Angle Drill Kit w/ QUIK-LOK™**

2708-22HD, 2708-22 (2708-20 Tool-Only)

**Specifications:**

RPM	0 – 1,200
Chuck Type	7/16" Hex QUIK-LOK™
Capacity	For Augers up to 1-1/4"; Self-Feed Bits up to 2"
Length	17"
Weight	9.3 lbs

**Includes:** 2708-22HD (2) M18™ REDLITHIUM™ HIGH DEMAND™ 9.0 Battery Packs, Rapid Charger, Carrying Case; **2708-22** Includes (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Multi-Voltage Charger



**M18 FUEL**  
**1-1/2" Magnetic Drill Kit**

2787-22HD

**Specifications:**

Capacity	1-1/2" Annular Cutter; 1/2" Twist Bit
RPM	400 / 690
Magnet	Operates Without Electricity
Dimensions (L x W x H)	13-3/4" x 7-1/2" x 15-1/2"
Weight	30.4 lbs

**Includes:** (2) M18™ REDLITHIUM™ HIGH DEMAND™ 9.0 Battery Packs, Magnetic Lubrication Tank, 3/4" Weldon to 1/2" Chuck Adapter, Chuck Key, (2) 1" Retracting Pilot Pins, Safety Strap, Rapid Charger, Carrying Case



**M18 FUEL**  
**HOLE HAWG® 1/2" Right Angle Drill Kit**

2707-22HD, 2707-22 (2707-20 Tool-Only)

**Specifications:**

RPM	0 – 1,200
Chuck Type	1/2" Metal Keyed
Capacity	For Augers up to 1-1/4"; Self-Feed Bits up to 2"
Length	17"
Weight	9.8 lbs

**Includes:** 2707-22HD (2) M18™ REDLITHIUM™ HIGH DEMAND™ 9.0 Battery Packs, Chuck Key, Rapid Charger, Carrying Case; **2707-22** Includes (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Multi-Voltage Charger



**M18 FUEL**  
**1-1/2" Lineman Magnetic Drill Kit**

2788-22HD

**Specifications:**

Capacity	1-1/2" Annular Cutter; 1/2" Twist Bit
RPM	400 / 690
Magnet	Operates Without Electricity
Dimensions (L x W x H)	13-3/4" x 7-1/2" x 15-1/2"
Weight	30.4 lbs

**Includes:** (2) M18™ REDLITHIUM™ HIGH DEMAND™ 9.0 Battery Packs, Magnetic Lubrication Tank, 3/4" Weldon to 1/2" Chuck Adapter, Chuck Key, (2) 1" Retracting Pilot Pins, Safety Strap, AC/DC Wall and Vehicle Charger, Carrying Case



**M18 FUEL**  
**SUPER HAWG™ Right Angle Drill Kit w/ QUIK-LOK™**

2711-22HD, 2711-22 (2711-20 Tool-Only)

**Specifications:**

RPM	0 – 350 / 0 – 950
Chuck Type	7/16" Hex QUIK-LOK™
Capacity	For Self-Feed Bits up to 4-5/8"; Hole Saws up to 6"
Mechanical Clutch	Yes
Length	22"
Weight	14.8 lbs

**Includes:** 2711-22HD (2) M18™ REDLITHIUM™ HIGH DEMAND™ 9.0 Battery Packs, Side Handle, Rapid Charger, Contractor Bag; **2711-22** Includes (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs



**M18 FUEL**  
**1-9/16" SDS Max Rotary Hammer Kit**

2717-22HD (2717-20 Tool-Only)

**Specifications:**

RPM	0 – 440
BPM	0 – 3,000
Impact Energy	5.0 ft-lbs
2-Mode Operation	Rotary Hammer and Hammer Only
Weight	13.75 lbs

**Includes:** (2) M18™ REDLITHIUM™ HIGH DEMAND™ 9.0 Battery Packs, Side Handle, Depth Rod, Rapid Charger, Carrying Case

**Related Accessory:**

**2306-22** M12™ HAMMERVAC™ Universal Dust Extractor



**M18 FUEL**  
**1-1/8" SDS Plus Rotary Hammer Kit**

2715-22HD, 2715-22, 2715-22DE (2715-20 Tool-Only)

**Specifications:**

RPM	0 – 1,350
BPM	0 – 5,000
Impact Energy	3.3 ft-lbs
3-Mode Operation	Rotary Hammer, Hammer Only and Rotation Only
Weight	10.1 lbs

**Includes:** 2715-22HD (2) M18™ REDLITHIUM™ HIGH DEMAND™ 9.0 Battery Packs, Slide Handle, Depth Rod, Rapid Charger, Carrying Case; **2715-22** Includes (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Multi-Voltage Charger; **2715-22DE** Includes (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, HAMMERVAC™ Dedicated Dust Extractor, HEPA Filter, Replacement Nozzle, Multi-Voltage Charger



**HAMMERVAC™ Dedicated Dust Extractor**

2715-DE

**Specifications:**

Compatibility	For use with 2715-20
In-Line Dedicated Design	Engineered to Fit in the Most Confined Workspaces
Adjustable Depth Stop and Ruler	Easily and Precisely Adjust for Accurate Hole Depths
Replaceable Certified HEPA Filter	Filters 99.97% of Debris 0.3 Microns and Above
Max Bit Size	5/8"

**Includes:** Replacement Nozzle and HEPA Filter



**M18 FUEL**  
**1" SDS Plus Rotary Hammer Kit**

2712-22HD, 2712-22, 2712-22DE (2712-20 Tool-Only)

**Specifications:**

RPM	0 – 1,400
BPM	0 – 4,900
Impact Energy	1.7 ft-lbs
3-Mode Operation	Rotary Hammer, Hammer Only and Rotation Only
Weight	9.4 lbs

**Includes:** 2712-22HD (2) M18™ REDLITHIUM™ HIGH DEMAND™ 9.0 Battery Packs, Slide Handle, Depth Rod, Rapid Charger, Carrying Case; **2712-22** Includes (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Multi-Voltage Charger; **2712-22DE** Includes (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, HAMMERVAC™ Dedicated Dust Extractor, HEPA Filter, Replacement Nozzle, Multi-Voltage Charger



**HAMMERVAC™ Dedicated Dust Extractor**

2712-DE

**Specifications:**

Compatibility	For use with 2712-20
In-Line Dedicated Design	Engineered to Fit in the Most Confined Workspaces
Adjustable Depth Stop and Ruler	Easily and Precisely Adjust for Accurate Hole Depths
Replaceable Certified HEPA Filter	Filters 99.97% of Debris 0.3 Microns and Above
Max Bit Size	5/8"

**Includes:** Replacement Nozzle and HEPA Filter



**M18 FUEL**  
**1" SDS Plus D-Handle Rotary Hammer Kit**

2713-22HD, 2713-22 (2713-20 Tool-Only)

**Specifications:**

Capacity	1"
Impact Energy	2.15 ft-lbs
RPM	0 – 1,500
BPM	0 – 4,400
Length	16-1/2"
Weight	8.5 lbs

**Includes:** 2713-22HD (2) M18™ REDLITHIUM™ HIGH DEMAND™ 9.0 Battery Packs, Slide Handle, Depth Rod, Rapid Charger, Carrying Case; **2713-22** Includes (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Multi-Voltage Charger



**M18™ 7/8" SDS Plus Rotary Hammer Kit**

2605-22 (2605-20 Tool-Only)

**Specifications:**

RPM	0 – 1,400
BPM	0 – 4,800
Impact Energy	1.4 ft-lbs
3-Mode Operation	Hammer Only, Rotary Hammer and Rotation Only
Weight	7.2 lbs

**Includes:** (2) M18™ REDLITHIUM™ XC Extended Capacity Battery Packs, Side Handle, Depth Rod, Multi-Voltage Charger, Carrying Case

**Related Accessory:**

**2306-22** M12™ HAMMERVAC™ Universal Dust Extractor



**M18™ 5/8" SDS Plus Rotary Hammer Kit**

2612-22, 2612-21 (2612-20 Tool-Only)

**Specifications:**

RPM	0 – 1,300
BPM	0 – 7,000
Impact Energy	1.0 ft-lbs
2-Mode Operation	Rotary Hammer and Rotation Only
Weight	5.5 lbs

**Includes:** 2612-22 (2) M18™ REDLITHIUM™ XC Extended Capacity Battery Packs, Side Handle, Depth Rod, Multi-Voltage Charger, Carrying Case; **2612-21** Includes (1) M18™ REDLITHIUM™ XC Extended Capacity Battery Pack

**Related Accessory:**

**2306-22** M12™ HAMMERVAC™ Universal Dust Extractor





**M18 FUEL**  
**1/4" Hex Impact Driver w/ ONE-KEY™ Kit**

2757-22, 2757-22CT (2757-20 Tool-Only)

**Specifications:**

Fastening Torque	1,800 in-lbs
IPM	0 – 3,700
RPM	0 – 3,000
DRIVE CONTROL™	4-Mode (Customizable)
Chuck Type	1/4" Hex
Length	5-1/4"
Weight	4.0 lbs

**Includes:** 2757-22 (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Multi-Voltage Charger, Carrying Case; 2757-22CT Includes (2) M18™ REDLITHIUM™ 2.0 Compact Battery Packs



**M18 FUEL**  
**1/4" Hex Impact Driver Kit**

2753-22, 2753-22CT (2753-20 Tool-Only)

**Specifications:**

Fastening Torque	1,800 in-lbs
IPM	0 – 3,700
RPM	0 – 3,000
DRIVE CONTROL™	4-Mode
Chuck Type	1/4" Hex
Length	5-1/4"
Weight	3.9 lbs

**Includes:** 2753-22 (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Multi-Voltage Charger, Carrying Case; 2753-22CT Includes (2) M18™ REDLITHIUM™ 2.0 Compact Battery Packs



**M18™ 1/4" Hex Brushless Impact Driver Kit**

2750-22CT (2750-20 Tool-Only)

**Specifications:**

Fastening Torque	1,500 in-lbs
IPM	0 – 3,600
RPM	0 – 2,900
Chuck Type	1/4" Hex
Length	5-3/8"
Weight	3.1 lbs

**Includes:** (2) M18™ REDLITHIUM™ 2.0 Compact Capacity Battery Packs, Belt Clip, Multi-Voltage Charger, Carrying Case



**M18 FUEL**  
**SURGE™ 1/4" Hex Hydraulic Driver Kit**

2760-22, 2760-22CT (2760-20 Tool-Only)

**Specifications:**

Sustained Fastening Torque	450 in-lbs
IPM	0 – 4,000
RPM	0 – 3,000
DRIVE CONTROL™	4-Mode
Length	5"
Weight	3.9 lbs

**Includes:** 2760-22 (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Multi-Voltage Charger, Carrying Case; 2760-22CT Includes (2) M18™ REDLITHIUM™ 2.0 Battery Packs



**M18™ 1/4" Hex Compact Impact Driver Kit**

2656-22CT (2656-20 Tool-Only)

**Specifications:**

Fastening Torque	1,500 in-lbs
IPM	0 – 3,450
RPM	0 – 2,750
Chuck Type	1/4" Hex Quick Change
Length	5-1/2"
Weight	3.8 lbs

**Includes:** 2657-22 (2) M18™ REDLITHIUM™ Compact Battery Packs, Belt Clip, Multi-Voltage Charger, Carrying Case



**M18™ 1/4" 2-Speed Impact Driver Kit**

2657-22, 2657-22CT (2657-20 Tool-Only)

**Specifications:**

Fastening Torque	1,500 in-lbs
IPM	0 – 3,450
RPM	0 – 2,750
Chuck Type	1/4" Hex Quick Change
Length	5-1/2"
Weight	3.8 lbs

**Includes:** 2657-22 (2) M18™ REDLITHIUM™ XC Extended Capacity Battery Packs, Belt Clip, Multi-Voltage Charger, Carrying Case; 2657-22CT Includes (2) M18™ REDLITHIUM™ Compact Battery Packs



**M18 FUEL**  
**3/8" Impact Wrench w/ Friction Ring w/ ONE-KEY™ Kit**

2758-22, 2758-22CT (2758-20 Tool-Only)

**Specifications:**

Fastening Torque	210 ft-lbs
IPM	0 – 3,200
RPM	0 – 2,500
DRIVE CONTROL™	4-Mode (Customizable)
Chuck Type	3/8" Friction Ring
Length	5-9/10"
Weight	4.2 lbs

**Includes:** 2758-22 (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Multi-Voltage Charger, Carrying Case; 2758-22CT Includes (2) M18™ REDLITHIUM™ 2.0 Compact Battery Packs



**M18 FUEL**  
**3/8" Compact Impact Wrench w/ Friction Ring Kit**

2754-22, 2754-22CT (2754-20 Tool-Only)

**Specifications:**

Fastening Torque	210 ft-lbs
IPM	0 – 3,200
RPM	0 – 2,500
DRIVE CONTROL™	4-Mode
Chuck Type	3/8" Friction Ring
Length	5-9/10"
Weight	4.2 lbs

**Includes:** 2754-22 (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Multi-Voltage Charger, Carrying Case; 2754-22CT Includes (2) M18™ REDLITHIUM™ 2.0 Compact Battery Packs



**M18™ 3/8" Compact Impact Wrench Kit**

2658-22, 2658-22CT (2658-20 Tool-Only)

**Specifications:**

Fastening Torque	167 ft-lbs
IPM	0 – 3,350
RPM	0 – 2,450
Anvil	3/8" Friction Ring
Length	6"
Weight	4.1 lbs

**Includes:** 2658-22 (2) M18™ REDLITHIUM™ XC Extended Capacity Battery Packs, Belt Clip, Multi-Voltage Charger, Carrying Case; 2658-22CT Includes (2) M18™ REDLITHIUM™ Compact Battery Packs



**M18 FUEL**  
**1/2" Compact Impact Wrench w/ Pin Detent w/ ONE-KEY™ Kit**

2759-22, 2759B-22 (2759-20, 2759B-20 Tool-Only)

**Specifications:**

Fastening Torque	220 ft-lbs
IPM	0 – 3,200
RPM	0 – 2,500
DRIVE CONTROL™	4-Mode (Customizable)
Chuck Type	1/2" Pin Detent
Length	6-1/10"
Weight	4.2 lbs

**Includes:** 2759-22 (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Multi-Voltage Charger, Carrying Case; 2759B-22 1/2" Compact Impact Wrench w/ Friction Ring w/ ONE-KEY™ Kit



**M18 FUEL**  
**1/2" Compact Impact Wrench w/ Pin Detent Kit**

2755-22, 2755B-22 (2755-20, 2755B-20 Tool-Only)

**Specifications:**

Fastening Torque	220 ft-lbs
IPM	0 – 3,200
RPM	0 – 2,500
DRIVE CONTROL™	4-Mode
Chuck Type	1/2" Pin Detent
Length	6-1/10"
Weight	4.2 lbs

**Includes:** 2755-22 (2) M18™ REDLITHIUM™ XC5.0 Extended Capacity Battery Packs, Belt Clip, Bit Holder, Multi-Voltage Charger, Carrying Case; 2755B-22 1/2" Compact Impact Wrench w/ Friction Ring Kit

