

PROJECT:	DATE:
CAT. NO.:	TYPE:
NOTES	VOLTS:

### GENERAL

Surface mounted wrap-around luminaire for indoor applications. Convenient 3 3/8" shallow fixture profile. Prismatic diffuser provides optimum light output; optional opal diffuser offers soft illumination. Suitable for continuous row mounting.

### CONSTRUCTION

Rigid die-formed housing fabricated from code gauge steel.

### FINISH

Standard finish is high gloss white polyester powder coat paint. Baked white enamel.

### SHIELDING


Clear acrylic prismatic wrap-around diffuser supplied as standard. White opal diffuser available as option.

### ELECTRICAL

Instant start electronic ballast, 120V-50/60Hz. Other ballasts and voltages available upon request.

### CERTIFICATIONS

CSA and/or UL approved.

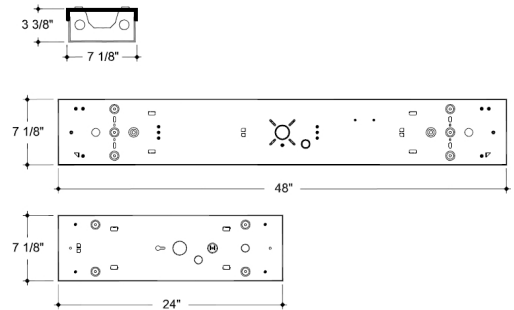

### Ordering Information

SERIES	DIFFUSER	MODULE WIDTH	MODULE LENGTH	LAMPS	WATTS	VOLTAGE	BALLAST
PEL		51					
	C = Clear Prismatic Acrylic  O = Opal	51 = 7 1/8" wide	2 = 2'  4 = 4'	2	14 (2' T5) 17 (2' T8) 24 (2' T5HO)  28 (4' T5) 32 (4' T8) 54 (4' T5HO)	120 277 347	IS PRS RS