

Volume Controls

RUSSOUND'S VOLUME CONTROL WARRANTY

Hassle-Free Gold Guarantee

Two Reasons to Purchase Russound Volume Controls


BULLETPROOF

The ALTx line of Volume Controls has a high power handling capability of 126W for superior performance, added reliability and durability.

HASSLE-FREE GOLD GUARANTEE

Russound is so confident in the performance and reliability of its ALTx Volume Controls that if one should fail for any reason, we'll send you a replacement free of charge (no return necessary).

Simply contact Russound customer support with your shipping address and we will promptly send a free replacement to you. Proof of purchase may be required.

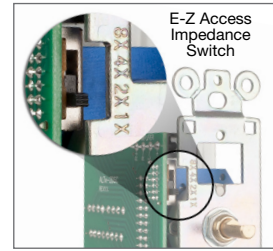

ALT-126R 126 Watt Impedance Matching Volume Control

- Easy access impedance switch behind front plate
- 126W peak, 42W RMS continuous
- 12 steps of attenuation including Off
- Accepts up to 12AWG cable
- Includes both white and Lt. Almond Decora® plates, inserts and knobs
- Easily converts to standard style plate with ALT-VC Standard Color Kit
- Lifetime warranty

Dimensions: 1.625"W x 2.675"H x 2.5"D (41 x 73 x 63 mm)

Shipping Weight: 1.2lbs (0.54kg)

6100-536281 ALT-126R White and Lt. Almond



ALT-VC Decora Color Kit

Contains 1 each of: Decora insert, Decora cover plate, screws (pair), knob.

Shipping Weight: 1 lb (0.5 kg)

- 6100-536670 Almond
- 6100-536694 Black
- 6100-536717 Bone
- 6100-536731 Brown
- 6100-536755 Lt Almond
- 6100-536779 White



ALT-VC Standard Color Kit

Converts ALT-126R to standard plate style. Contains one each of: Standard plate, knob and screws (pair).

Shipping Weight: 1 lb (0.5 kg)

- 6100-536687 Almond
- 6100-536700 Black
- 6100-536724 Bone
- 6100-536748 Brown
- 6100-536762 Lt Almond
- 6100-536786 White



WALTx-2

Weatherproof volume control with standard gray plate and knob. 12 position switch. Provides 1x, 2x, 4x, 8x impedance matching. Fits a standard 3/4" PVC outdoor conduit.



Dimensions:
3" W x 5" H x 3.75" D (76.5 x 127 x 95.5 mm)

Shipping Weight: 1.75 lbs (0.79 kg)

6500-114113 WALTx-2



EZB-8 E-Z Connect Speaker Terminal Block

Simplifies system wiring with volume control installations. Connects up to 8 pairs of speakers. Removable, screw-down connectors. Easily mounts to a wall, cabinet or structured wiring can with push-lock plugs included. Easily add additional speakers. Works with up to 12AWG wire.

Dimensions:
6.85 W x 3.0 H x 1.0" D (17.4 x 7.6 x 2.5cm)

Shipping Weight: 0.7 lbs (0.3 kg)

8100-536106 EZB-8



TBL-75 Table Top Volume Control

126 watt volume control with headphone jack speaker override. Installer configurable from 1x, 2x, 4x or 8x impedance matching.

Dimensions:
6.1" W x 2.5" H x 2" D (154 x 63.5 x 49.3 mm)

Shipping Weight: 2.5 lbs (1.1 kg)

6400-113161 TBL-75