


# 1 & 2 Pole Combination Type Arc-Fault Circuit Interrupters

## Plug-in and Bolt-on

### Data Sheet

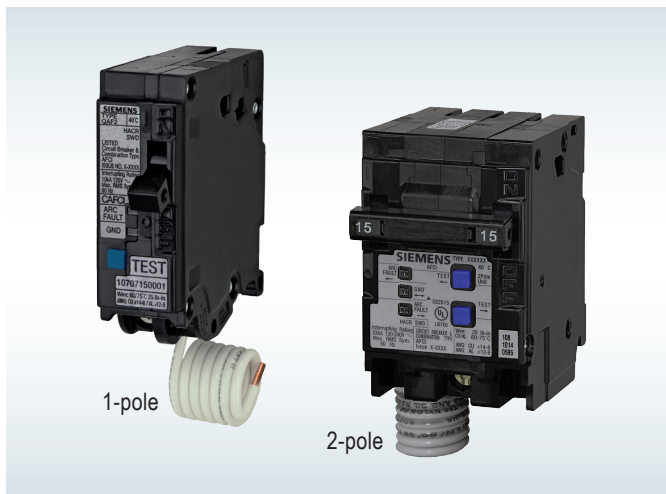

#### Features

- Available in 1 & 2 Pole, 15A & 20A
- New and improved electronics
- 1/4" more wiring bend space than our previous design
- Both lugs at the same angle - for easier wiring
- Plug-in or bolt-on branch circuit breakers for Siemens single phase load centers or panelboards
- LED trip indicator – a Siemens exclusive!
- Available with interrupting rating of 10kA, 22kA or 65kA
- UL Listed
- Ratings:
  - HACR
  - SWD
- 120 Volts AC
- Wire range:
  - #14 – #8 AWG Cu
  - #12 – #8 AWG Al
- Torque rating: 25 lb. in.

#### 1-Pole Plug-in Arc-Fault Circuit Interrupters

Catalog number	Ampere rating	Interrupting rating	UL type
QA115AFC	15	10kA	QAF2
QA120AFC	20	10kA	
QA115AFCH	15	22kA	QAFH2
QA120AFCH	20	22kA	
QA115AFCHH	15	65kA	HQAF2
QA120AFCHH	20	65kA	

#### 1-Pole Bolt-on Arc-Fault Circuit Interrupters

Catalog number	Ampere rating	Interrupting rating	UL type
BA115AFC	15	10kA	BAF2
BA120AFC	20	10kA	
BA115AFCH	15	22kA	BAFH2
BA120AFCH	20	22kA	
BA115AFCHH	15	65kA	HBAF2
BA120AFCHH	20	65kA	

#### 2-Pole Plug-in Arc-Fault Circuit Interrupters

Catalog number	Ampere rating	Interrupting rating	UL type
Q215AFC	15	10kA	QAF
Q220AFC	20	10kA	
Q215AFCH	15	22kA	QAFH
Q220AFCH	20	22kA	

#### 2-Pole Bolt-on Arc-Fault Circuit Interrupters

Catalog number	Ampere rating	Interrupting rating	UL type
B215AFC	15	10kA	BAF
B220AFC	20	10kA	
B215AFCH	15	22kA	BAFH
B220AFCH	20	22kA	