


## Armoured Cable and Flexible Metal Conduit Fittings




T&B squeeze fittings will fit every size of armoured cable, leaded cable and flexible conduit. Malleable iron or steel construction. Part No. 253-TB is steel.

### Squeeze Fittings

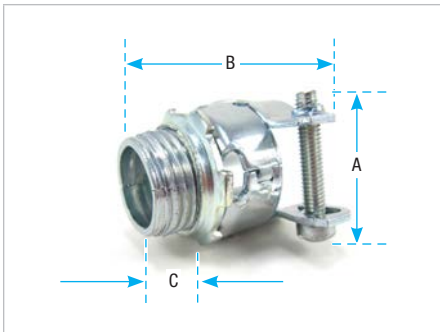

Cat. No.	Cable Opening (in.)		Trade Size (in.)	K.O. Size (in.)	Dimensions (in.)		
	max.	min.			A	B	C
252	0.531	0.437	5/16	3/8	13/16	25/32	11/32
253-TB†	0.585	0.455	3/8	1/2	31/32	1-13/64	5/8
254-C†	0.938	0.812	1/2	1/2	1-7/32	1-3/8	13/32
255	1.094	0.938	3/4	3/4	1-1/4	1-17/32	7/16
256	1.375	1.250	1	1	1-19/32	1-5/8	1/2
257	1.656	1.500	1-1/4	1-1/4	1-7/8	1-23/32	17/32
258	1.875	1.688	1-1/2	1-1/2	2-1/4	1-7/16	9/16
259	2.500	2.313	2	2	2-31/32	2-5/8	11/16
249	3.062	2.812	2-1/2	2-1/2	3-5/16	2-11/16	3/4
277	3.563	3.312	3	3	3-13/16	2-7/8	3/4

† UL Listed for armoured cable only. Fitting material steel

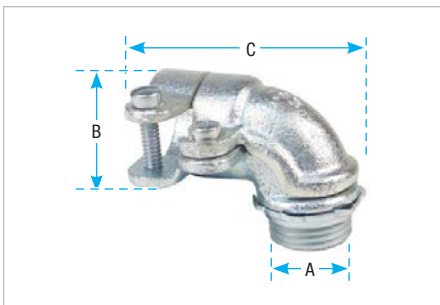

3/8 in. and 1/2 in. sizes made in steel. Cap lifts off by simply loosening screws part way. Only two screws to tighten. 3/4 in. size and larger made of malleable iron.


### Squeeze Fittings – 90° Angle



Cat. No.	Cable Opening (in.)		Trade Size (in.)	K.O. Size (in.)	Dimensions (in.)		
	max.	min.			A	B	C
266-C	0.656	0.406	3/8	1/2	1-1/2	1-13/32	1-7/16
272†	0.812	0.688	3/8	1/2	1-9/16	1-7/8	1-9/16
268-C	0.937	0.813	1/2	1/2	1-11/16	1-13/16	1-7/8
279	1.000	0.875	3/4	3/4	1-13/16	2-1/16	1-13/16
270	1.125	1.000	3/4	3/4	1-7/8	1-3/4	1-13/16
273-TB	1.406	1.187	1	1	2-3/8	2-7/32	2-7/16
274‡	1.656	1.375	1-1/4	1-1/4	3	2-9/16	2-7/8
275‡	1.875	1.625	1-1/2	1-1/2	3-7/32	3-1/16	4-1/8
276‡	2.500	2.125	2	2	4-5/8	3-5/8	4-7/8

† UL Listed for armoured cable only

‡ UL Listed for flexible metal conduit only

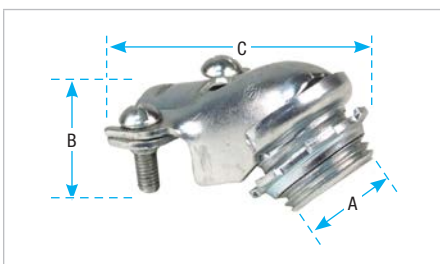

3/8 in. and 1/2 in. sizes made in steel. Cap lifts off by simply loosening screws part way

### Squeeze Fittings – 45° Angle



Cat. No.	Cable Opening (in.)		Trade Size (in.)	K.O. Size (in.)	Dimensions (in.)		
	max.	min.			A	B	C
265	0.656	0.406	3/8	1/2	1-7/16	1-5/32	1-1/8
267	0.937	0.813	1/2	1/2	1-3/16	1/2	1-1/4
269	1.125	1.000	3/4	3/4	1-7/8	17/32	1-9/16