

Assembled Stations plastic enclosures



Emergency Stop Enclosure



Emergency Stop Enclosure with Shroud




2-seat Plastic Enclosure

Description	Catalogue No.	List Price	Weight Kg
1-seat Plastic Enclosures			
Emergency Stop Pushbutton, 40 mm. Twist release. No Legend Plate. Yellow top / light grey bottom			
● Red 2 NC	MEPY1-1005		0.234
● Red 1 NO + 2 NC	MEPY1-1024		0.250
● Red 1 NC	MEPY1-1010		0.218
1-seat Plastic Enclosures			
Emergency Stop Pushbutton, 40 mm. Twist release. Legend Plate: "Emergency Stop" Yellow top/light grey bottom			
● Red 2 NC	MEPY1-1026		0.240
1-seat Plastic Enclosure			
☐ Yellow/Light grey Twist release. Red button 2 NC	CEPY1-1001		0.108
☐ Yellow/Light grey Pull release. Red button 2 NC	CEPY1-1002		0.108
☐ Yellow/Light grey Key release. Red button 2 NC	CEPY1-1006		0.105
1-seat Plastic Enclosure with Shroud			
☐ Yellow/Light grey Twist release. Red button 2 NC	CEPY1-2002		0.124
☐ Yellow/Light grey Pull release. Red button 2 NC	CEPY1-2001		0.124
1-seat Plastic Enclosure with Black Mushroom Pushbutton			
☐ Dark grey/Light grey Twist release. Black button 1 NO + 1 NC	CEP1-1001		0.108
☐ Dark grey/Light grey Pull release. Black button 1 NO + 1 NC	CEP1-1002		0.108
1-seat Plastic Enclosure with Black Mushroom Pushbutton and Shroud			
☐ Dark grey/Light grey Twist release. Black button 1 NO + 1 NC	CEP1-2001		0.124
☐ Dark grey/Light grey Pull release. Black button 1 NO + 1 NC	CEP1-2002		0.124
1-seat Plastic Enclosure			
Dark grey top / light grey bottom Selector Switch 3 position, maintained. Legend Plate ← off →			
● Black 2 NO	MP1-1994		0.240
2-seat Plastic Enclosure			
Dark grey top / light grey bottom Two Flush Pushbuttons. Momentary.			
Left	Right		
● Green 1 NO I Start	● Red 1 NC O Stop		
		MEP2-1001	0.280
		MEP2-1991	0.280
3-seat Plastic Enclosure			
Dark grey top / light grey bottom Two flush pushbuttons, pilot light in center position			
Left	Center	Right	
● Red 1 NO Stop	○ Clear 1 NC ON	● Green 1 NC Start	
			MEP3-1991 0.320
Three flush pushbuttons, momentary			
● Green 1 NO FWD	● Green 1 NC Stop	● Green 1 NC Rev	
			MEP3-1994 0.320


Legend Plates for pushbuttons




Legend Plates

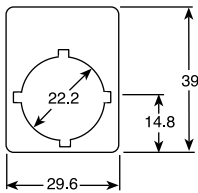

For two-position Selector Switch

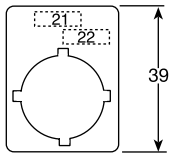

For three-position Selector Switch

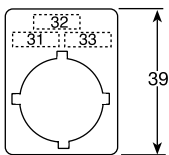



Text	Catalogue No.	List Price	Weight Kg.
Engraved Fixed Legend Plates, with text¹. Of silvergrey aluminum			
For Pushbuttons – with text in English			
CLOSE	CBK-NPE1		0.002
DOWN	CBK-NPE2		0.002
EMERGENCY STOP	CBK-NPE3		0.002
FAST	CBK-NPE4		0.002
FORWARD	CBK-NPE5		0.002
INCHING	CBK-NPE6		0.002
IN	CBK-NPE7		0.002
LEFT	CBK-NPE8		0.002
LOWER	CBK-NPE9		0.002
OFF	CBK-NPE10		0.002
ON	CBK-NPE11		0.002
OPEN	CBK-NPE12		0.002
RAISE	CBK-NPE13		0.002
RESET	CBK-NPE14		0.002
REVERSE	CBK-NPE15		0.002
RUN	CBK-NPE16		0.002
RIGHT	CBK-NPE17		0.002
SLOW	CBK-NPE18		0.002
START	CBK-NPE19		0.002
STOP	CBK-NPE20		0.002
UP	CBK-NPE21		0.002
FAULT	CBK-NPE34		0.002
POWER ON	CBK-NPE35		0.002
JOG	CBK-NPE40		0.002
TEST	CBK-NPE41		0.002
TRIP	CBK-NPE50		0.002
For two-position Selector Switches– with text in English (Text Pos 21 Pos 22)			
HAND AUTO	CBK-NPE22		0.002
JOG RUN	CBK-NPE23		0.002
OFF ON	CBK-NPE24		0.002
STOP START	CBK-NPE25		0.002
FWD REV	CBK-NPE32		0.002
LOCAL AUTO	CBK-NPE36		0.002
OPEN CLOSE	CBK-NPE37		0.002
SLOW FAST	CBK-NPE46		0.002
For three-position Selector Switches – with text in English (Text Pos 31 Pos 32 Pos 33)			
Hand O Auto	CBK-NPE26		0.002
Slow Off Fast	CBK-NPE27		0.002
Low Off High	CBK-NPE31		0.002
FWD Off Rev	CBK-NPE33		0.002
Open Auto Close	CBK-NPE45		0.002




Text	Catalogue No.	List Price	Weight Kg.	
Engraved Fixed Legend Plates, with text¹. Of silvergrey aluminum				
For Pushbuttons – with text in French				
FERMETURE	CBK-NPF1		0,002	
DESCENTE	CBK-NPF2		0,002	
ARRÊT D'URGENCE	CBK-NPF3		0,002	
RAPIDE	CBK-NPF4		0,002	
AVANT	CBK-NPF5		0,002	
À COUPS	CBK-NPF6		0,002	
ENTRÉE	CBK-NPF7		0,002	
GAUCHE	CBK-NPF8		0,002	
BAS	CBK-NPF9		0,002	
HORS SERVICE	CBK-NPF10		0,002	
SOUS-TENSION	CBK-NPF11		0,002	
OUVERTURE	CBK-NPF12		0,002	
LEVER	CBK-NPF13		0,002	
RÉARMEMENT	CBK-NPF14		0,002	
ARRIÈRE	CBK-NPF15		0,002	
EN SERVICE	CBK-NPF16		0,002	
DROITE	CBK-NPF17		0,002	
LENT	CBK-NPF18		0,002	
MARCHE	CBK-NPF19		0,002	
ARRÊT	CBK-NPF20		0,002	
MONTÉE	CBK-NPF21		0,002	
FAUTE	CBK-NPF34		0,002	
EN CIRCUIT	CBK-NPF35		0,002	
ALARME	CBK-NPF36		0,002	
ALIMENTATION	CBK-NPF37		0,002	
DEPART	CBK-NPF38		0,002	
SILENCE	CBK-NPF39		0,002	
SURCHARGE	CBK-NPF40		0,002	
For two-position Selector Switches– with text in French (Text Pos 21 Pos 22)				
MAN	AUTO	CBK-NPF22	0.002	
À COUPS	MARCHE	CBK-NPF23	0.002	
HORS	EN	CBK-NPF24	0.002	
MARCHE	ARRÊT	CBK-NPF25	0.002	
ARRIÈRE	AVANT	CBK-NPF32	0.002	
HORS	TEST	CBK-NPF42	0.002	
LENT	RAPIDE	CBK-NPF46	0.002	
For three-position Selector Switches – with text in French (Text Pos 31 Pos 32 Pos 33)				
MAN	HORS	AUTO	CBK-NPF26	0.002
LENT	HORS	RAPIDE	CBK-NPF27	0.002
BAS	HORS	HAUT	CBK-NPF31	0.002
AV	HORS	ARR	CBK-NPF33	0.002
AUTO	HORS	TEST	CBK-NPF45	0.002



Legend Plates

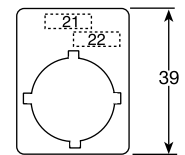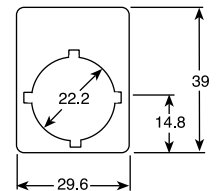

For two-position Selector Switch

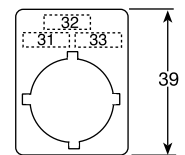

For three-position Selector Switch