

# Type RW Reducing Washers

NEC/CEC:  
Listed for Ordinary Locations

## Features

- To reduce a knockout or sliphole in a sheet metal enclosure to a smaller trade size.

## Standard Materials

- Steel

## Standard Finishes

- Zinc pre-galvanized


## NEC/CEC Certifications and Compliances

- UL Standard: ANSI/UL 514B
- UL Listed: E-14817
- CSA Standard: C22.2 No. 18
- CSA Certified: 057250
- NEMA: FB-1

| Trade Size (Inches) | Dimensions in Millimeters (Inches) |               | Catalog Number |
|---------------------|------------------------------------|---------------|----------------|
|                     | A                                  | B             |                |
| 3/4 x 1/2           | 22.35 (0.88)                       | 36.58 (1.44)  | RW-2S          |
| 1 x 1/2             | 22.35 (0.88)                       | 44.45 (1.75)  | RW-3S          |
| 1 x 3/4             | 28.19 (1.11)                       | 44.45 (1.75)  | RW-4S          |
| 1-1/4 x 1/2         | 22.35 (0.88)                       | 55.63 (2.19)  | RW-5S          |
| 1-1/4 x 3/4         | 28.19 (1.11)                       | 55.63 (2.19)  | RW-6S          |
| 1-1/4 x 1           | 34.80 (1.37)                       | 55.63 (2.19)  | RW-7S          |
| 1-1/2 x 1/2         | 22.35 (0.88)                       | 63.50 (2.50)  | RW-8S          |
| 1-1/2 x 3/4         | 28.19 (1.11)                       | 63.50 (2.50)  | RW-9S          |
| 1-1/2 x 1           | 34.80 (1.37)                       | 63.50 (2.50)  | RW-10S         |
| 1-1/2 x 1-1/4       | 43.94 (1.73)                       | 63.50 (2.50)  | RW-11S         |
| 2 x 1/2             | 22.35 (0.88)                       | 76.20 (3.00)  | RW-12S         |
| 2 x 3/4             | 28.19 (1.11)                       | 76.20 (3.00)  | RW-13S         |
| 2 x 1               | 34.80 (1.37)                       | 76.20 (3.00)  | RW-14S         |
| 2 x 1-1/4           | 43.94 (1.73)                       | 76.20 (3.00)  | RW-15S         |
| 2 x 1-1/2           | 50.29 (1.98)                       | 76.20 (3.00)  | RW-16S         |
| 2-1/2 x 1/2         | 22.35 (0.88)                       | 88.90 (3.50)  | RW-17S         |
| 2-1/2 x 3/4         | 28.19 (1.11)                       | 88.90 (3.50)  | RW-18S         |
| 2-1/2 x 1           | 34.80 (1.37)                       | 88.90 (3.50)  | RW-19S         |
| 2-1/2 x 1-1/4       | 43.94 (1.73)                       | 88.90 (3.50)  | RW-20S         |
| 2-1/2 x 1-1/2       | 50.29 (1.98)                       | 88.90 (3.50)  | RW-21S         |
| 2-1/2 x 2           | 62.23 (2.45)                       | 88.90 (3.50)  | RW-22S         |
| 3 x 1               | 34.80 (1.37)                       | 104.90 (4.13) | RW-25S         |
| 3 x 1-1/4           | 43.94 (1.73)                       | 104.90 (4.13) | RW-26S         |
| 3 x 1-1/2           | 50.29 (1.98)                       | 104.90 (4.13) | RW-27S         |
| 3 x 2               | 62.23 (2.45)                       | 104.90 (4.13) | RW-28S         |
| 3 x 2-1/2           | 75.44 (2.97)                       | 104.90 (4.13) | RW-29S         |
| 3-1/2 x 1-1/2       | 50.29 (1.98)                       | 117.60 (4.63) | RW-34S ①       |
| 3-1/2 x 2           | 62.23 (2.45)                       | 117.60 (4.63) | RW-35S ①       |
| 3-1/2 x 2-1/2       | 75.44 (2.97)                       | 117.60 (4.63) | RW-36S ①       |
| 3-1/2 x 3           | 91.19 (3.59)                       | 117.60 (4.63) | RW-37S ①       |
| 4 x 2               | 63.50 (2.50)                       | 130.81 (5.15) | RW-43S ①       |
| 4 x 2-1/2           | 75.44 (2.97)                       | 130.81 (5.15) | RW-44S ①       |
| 4 x 3               | 91.19 (3.59)                       | 130.81 (5.15) | RW-45S ①       |
| 4 x 3-1/2           | 104.90 (4.13)                      | 130.81 (5.15) | RW-46S ①       |



Type RW

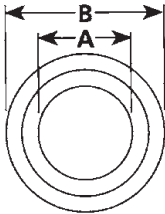

① Not CSA Certified.