

# 60W

## ROTATABLE LUMINAIRE



Ideal for security lighting, wall washing, flood lighting, and more  
Use as a flood light - uplight, downlight, or both!

2 Independent Rotatable Modules  
to offer flexible light control

Oversized Heat Sink  
for superior thermal management



Heavy Die Cast  
Aluminum

LM80 tested  
CREE chips

Superior anodized  
paint finish

## TECHNICAL DATA




### LIGHT SPECIFICATIONS

Lumens	7,853 lm
Efficacy	129.43 lm/W
CCT	5000K
Beam angle	60°
CRI	73.8
Dimmable	No
Rated hours	50,000
Warranty	10-year

### APPROVALS AND LISTINGS

cUL	E482965
DLC PREMIUM	PLM7XH1EFYRU

### DIMENSIONS

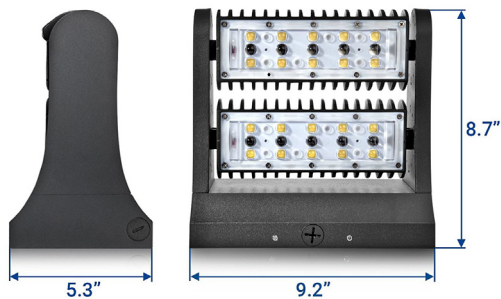

MAKE THE SMART CHOICE.  
COMPARE LUMENS PER WATT  
**129+ LM/W**

### ELECTRICAL

Wattage	60W
Voltage	100-277V
Power factor	0.91
THD	12.31%
Operating temp	-30° to 45° C

### CONSTRUCTION

Housing	Cast aluminum
Finish	Anodized finish
Colour	Black
IP rating	IP65
Weight	6.68 lbs
Carton qty	2

### ILLUMINANCE CONE

