



# LED Swivel

The LED Swivel is the perfect solution to replace traditional Xenon undercabinet luminaires. Working directly off of line voltage, no LED driver is required; connections can be made directly inside the luminaire.


A colour temperature switch is also available directly on the luminaire, allowing you to choose between 2 700 K, 3 000 K and 4 000 K. Being able to go from task to ambiance lighting. The LED Swivel also offers the option to direct the light where desired depending on the installation and the needs of the application.

- Selectable Colour Temperature - 2 700 K / 3 000 K / 4 000 K
- Easy and quick installation with no LED driver required
- Up to 300 W can be installed in daisy chain
- Light source that swivels
- Surface mount
- Dimmable



## LED Swivel

Order code	Description	Watts (W)	Volts (VAC)	Colour temp. (K)	Lumen output (lm)	CRI	Life L70 (hrs)	Beam angle (°)	Housing finish	Lens finish	Traditional Equivalent (W)	Case qty (master)
<b>12"</b>												
67194	UCS/12IN/120V/5W/SEL/FR/WH/STD	5	120	2 700 3 000 4 000	330	90	50 000	120	White	Frosted	50	10
<b>18"</b>												
67195	UCS/18IN/120V/8W/SEL/FR/WH/STD	8	120	2 700 3 000 4 000	530	90	50 000	120	White	Frosted	80	10
<b>24"</b>												
67196	UCS/24IN/120V/12W/SEL/FR/WH/STD	12	120	2 700 3 000 4 000	800	90	50 000	120	White	Frosted	120	10
<b>32"</b>												
67197	UCS/32IN/120V/16W/SEL/FR/WH/STD	16	120	2 700 3 000 4 000	1060	90	50 000	120	White	Frosted	160	10

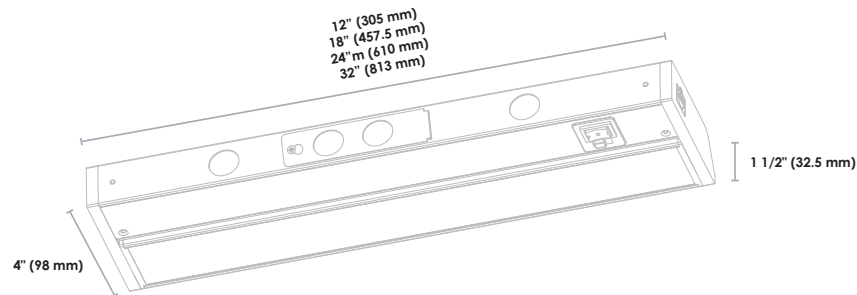

## Accessories

Order code	Description	Type	Figure	Length in. (mm)	Case qty (master)
67202	UCS/PLUG/120V/STD	120 V Power Cord Plug	A	73 5/8 (1870)	100
67203	UCS/JUMPER/6IN/STD	6" Jumper	B	6 (152.5)	500
67204	UCS/JUMPER/24IN/STD	24" Jumper	B	24 (610)	250
67205	UCS/JUMPER/36IN/STD	36" Jumper	B	36 (914)	100



Lumen values are derived from photometric testing. For a complete list of compatible dimmers, please visit [www.standardpro.com](http://www.standardpro.com)