

OWP-SL-101-LED

LED Die-Cast Slimline Wall Pack Series

25 Wattage / 2700 Lumens

Catalog Number:

Project Name:

Note:

Type:



APPLICATIONS:

The Slimline Wall Pack maintains a traditional appearance while reducing energy consumption by over 75%. Dusk to dawn technology ensures that the fixture will automatically turn on when light is needed. An ideal solution for multi-family, residential, apartment complexes, mobile home parks, and university housing.

FEATURES:

- Sealed die-casting profile for outdoor applications
- Consumes 25W to replace 50W HID
- MVOLT (120-277V)
- Lumen output of 2700 lumens with efficacy of 108lm/W
- Long lasting with lifespan 50,000 hrs
- Built-in UL Class 2 LED driver, 120-277V photocell included
- UL Wet location listed
- DLC qualified**


LENS:

Polycarbonate optical lens with UV stabilizers


SPECIFICATIONS:

LUMENS	2700 lumens
WATTAGE	25W
CCT	30K, 40K, 50K
CRI	70
VOLTAGE	120-277 VAC
POWER FREQUENCY	50/60 Hz
FINISH	Bronze, White
APPLICABLE ENVIRONMENT	Dry/Damp/Wet location

DIMENSION:

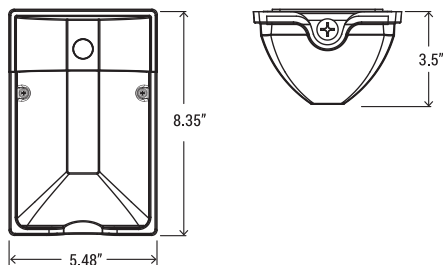

PHOTOMETRICS:

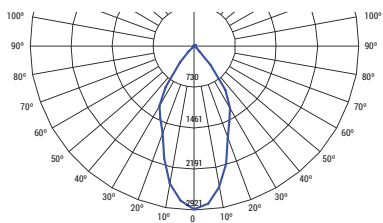

B	U	G
1	3	1



* For list of qualified DLC fixture, please consult factory

Ordering Guide > Example: OWP-SL-101-LED-2700L-MVOLT-40K-BZ

OWP-SL-101-LED				
SERIES	PERFORMANCE	VOLTAGE	CCT	FINISH
OWP-SL-101-LED	2700L - 2700 lumens	MVOLT - 120/277V	30K - 3000K 40K - 4000K 50K - 5000K	BZ - Bronze WH - White

INSTALLATION:

Convenient cast-in template for easy mounting over standard 4" outlet box; or there are top, back, side 1/2" threaded hubs available for conduit entry.

** DesignLights Consortium® (DLC) qualified product. Not all versions of this product may be DLC qualified. Please check the DLC Qualified Products List at www.designlights.org to confirm which versions are qualified.



Submittal form is available @ www.oraclelighting.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

Issued-B1118-Rev. 1