

Technical Information Bulletin

Worklights




Date: _____ Name of distributor: _____
 In hands date of project: _____ Client #: _____
 Project name/Number: _____ Name of end user: _____

ORDERING INFORMATION

Order code: 66852
 Description: TL/25FT/DSC/16AWG/METAL/OR/STD
 UPC: 69549668522
 Case quantity: 12

TECHNICAL DRAWINGS AND DIMENSIONS

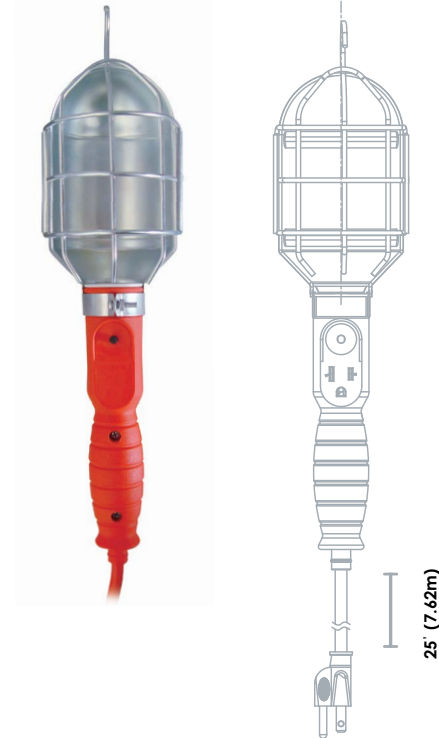

PHYSICAL DATA

Type: Trouble Light
 Wire length ft. (m): 25 (7.6)
 Wire specifications: SJTW 16 AWG/3C
 Housing colour: Orange
 Socket: E26
 Amount of sockets: 1
 Lamp guard material: Metal
 Can be daisy chained: Yes

PERFORMANCE DATA

Maximum Watts per socket (W): 75
 Volts (VAC): Socket 120, String 125
 Amperage (A): 10
 Environment: Wet
 Operating temp. range: -40°C to 60°C (-40°F to 140°F)



RECOMMENDED COMPATIBLE LED LAMPS

Order code	Description
60 W Equivalent	
66182	LED/A19/S4/9.8W/40K/STD
66183	LED/A19/S4/9.8W/50K/STD
75 W Equivalent	
66186	LED/A19/S4/11W/40K/STD
66187	LED/A19/S4/11W/50K/STD
100 W Equivalent	
66190	LED/A19/S4/15W/40K/STD
66191	LED/A19/S4/15W/50K/STD



DESCRIPTION AND OTHER OPTIONS

TL	25FT	DSC	16AWG	METAL	OR	STD
Family	Wire length	Feature	Wire Gauge	Lamp Guard Material	Colour	Brand
TL Trouble Light	25FT 25 ft (7.6 m)	DSC Can be daisy chained	16AWG 16 AWG	METAL Metal Cage	OR Orange	STD STANDARD

Qty	Description	Price

I accept the specifications of the luminaire configuration mentioned above.

Name: _____
 Company: _____
 Signature: _____

Date: _____