
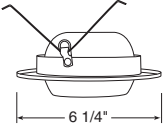

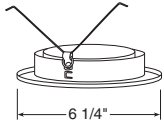

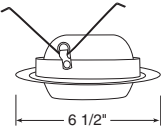

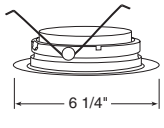

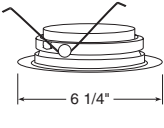


Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_

Location: \_\_\_\_\_

Contact/Phone: \_\_\_\_\_

Trim Series	Dimensions	Catalog No.	Housing/Lamp Compatibility
 <p><b>Eyeball with Baffle</b></p>	 <p>6 1/4"</p>	<p><b>208NW-WH</b> - White Baffle, White Trim  <b>208NB-WH</b> - Black Baffle, White Trim</p>	<p>IC20/IC20W/IC20S/IC20R: 50W PAR20, 50W R20            IC20N/IC20NW: 50W PAR20, 50W R20            TC20/TC20S/TC20R: 50W PAR20, 50W R20            IC25/IC25S/IC25W/IC25R Series: 50W PAR20, 50W R20</p>
Adjustment: 35° vertical, 358° rotation			
 <p><b>Gimbal Ring with Flat Trim</b></p>	 <p>6 1/4"</p>	<p><b>209N-WH</b> - White Trim</p>	<p>IC20/IC20W/IC20S/IC20R: 75W PAR30            TC20/TC20S/TC20R: 75W PAR30            IC25/IC25S/IC25W/IC25R Series: 35W PAR30</p>
Adjustment: 30° vertical, 358° rotation			
 <p><b>PAR30 Eyeball</b></p>	 <p>6 1/2"</p>	<p><b>529-ABZ</b> - Classic Aged Bronze Trim  <b>529-SC</b> - Satin Chrome Trim  <b>529-WH</b> - White Trim</p>	<p>IC20/IC20W/IC20S/IC20R: 75W PAR30            IC20N/IC20NW: 50W PAR20, 50W R20            TC20/TC20S/TC20R: 75W PAR30            IC25/IC25S/IC25W/IC25R Series: 50W PAR30</p>
Adjustment: 30° vertical, 358° rotation			
 <p><b>Gimbal Ring in Baffle</b></p>	 <p>6 1/4"</p>	<p><b>688W-WH</b> - White Baffle, White Trim  <b>688B-WH</b> - Black Baffle, White Trim</p>	<p>IC20/IC20W/IC20S/IC20R: 50W PAR30            TC20/TC20S/TC20R: 75W PAR30            IC25/IC25S/IC25W/IC25R Series: 35W PAR30</p>
Adjustment: 30° vertical, 358° rotation			
 <p><b>Gimbal Ring in Cone</b></p>	 <p>6 1/4"</p>	<p><b>689C-WH</b> - Clear Alzak<sup>®</sup>, White Trim  <b>689G-WH</b> - Gold Alzak<sup>®</sup>, White Trim  <b>689HZ-WH</b> - Haze Alzak<sup>®</sup>, White Trim  <b>689WHZ-WH</b> - Wheat Haze, White Trim  <b>689WHZ-ABZ</b> - Wheat Haze, Classic Aged Bronze Trim</p>	<p>IC20/IC20W/IC20S/IC20R: 50W PAR30            TC20/TC20S/TC20R: 75W PAR30            IC25/IC25S/IC25W/IC25R Series: 35W PAR30</p>
Adjustment: 30° vertical, 358° rotation			