



TRAC-MASTER®

Avant Garde

FRONT LAMPING OPEN BACK SPOTLIGHTS

T687, T689 and T690

Project: _____

Fixture Type: _____

Location: _____

Contact/Phone: _____

PRODUCT DESCRIPTION

The clean, functional lines of the open back allows maximum adjustability. Front Loading Open Back Spotlights relamp from the front and have fixed socket mount and on/off switch. The minimum profile with stylized yoke design is ideal for retail and commercial applications.

Construction Die-formed steel.

Socket Medium base porcelain with nickel plated copper screw shell.

Aiming 90° vertical aiming capability and 358° rotation.

Adapter Copper alloy contacts provide precise spring action - no arcing and will not take a set • True, positive electrical ground • On/off switch included
 • Patented embossed polarity arrows on bottom of adapter • Spring-loaded positive latch with embossed polarity arrows secures trac light to trac • "Pull-up" contact to up position for two-circuit application.


Labels UL listed, CSA certified.

Product specifications subject to change without notice.




Line Voltage PAR20

Catalog Number	Finish	Lamp
T687WH	White	35-50W PAR20
T687BL	Black	35-50W PAR20
T687SL	Silver	35-50W PAR20
T687NA	Natural	35-50W PAR20

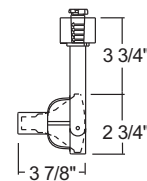

Line Voltage PAR30

Catalog Number	Finish	Lamp
T689WH	White	35-75W PAR30
T689BL	Black	35-75W PAR30
T689SL	Silver	35-75W PAR30
T689NA	Natural	35-75W PAR30

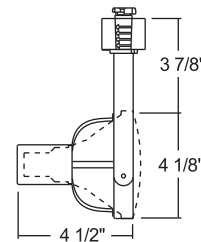

TRAC-MASTER®

Avant Garde

FRONT LAMPING OPEN BACK SPOTLIGHTS

T687, T689 and T690

Line Voltage PAR38

Catalog Number	Finish	Lamp
T690WH	White	45-250W PAR38
T690BL	Black	45-250W PAR38
T690SL	Silver	45-250W PAR38
T690NA	Natural	45-250W PAR38

