

VuLite® 6" Line Voltage Housings and Trims

Economy Recessed Lighting

IC Housings


V6ICW 6" IC New Construction
V6ICNW 6" IC New Construction with Floating Socket



Energy efficient housing.
 May be covered with insulation.

Dimensions:
 13-3/4"L x 13-3/8"W x 7-3/8"H

Ceiling Cutout: 6-1/2" Dia.

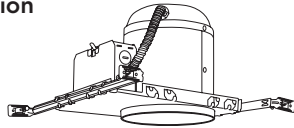


V6ICRW 6" IC Remodel



Energy efficient housing.
 May be covered with insulation.

Dimensions:
 13-3/4"L x 6-3/4"W x 7-3/8"H

Ceiling Cutout: 6-1/4" Dia.

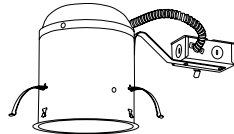

Accessories: **VALG4** Airloc® gasket kit for V4IC housing when an Airloc® trim is not being used.
G2405 Set of (4) T-bar clips for installation in suspended ceilings.


TC Housings

V6TCW 6" TC New Construction

Requires 3" spacing from insulation.

Dimensions:
 13-3/4"L x 13-3/8"W x 7-3/8"H

Ceiling Cutout: 6-1/2" Dia.

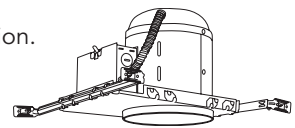


V6TCRW 6" TC Remodel

Requires 3" spacing from insulation.

Dimensions:
 13-3/4"L x 6-3/4"W x 7-3/8"H

Ceiling Cutout: 6-1/4" Dia.

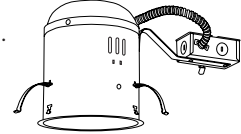


6" Compatible Trims

Conical Baffle

V3024W-WH: White
 V3024B-WH: Black

Aperture: 5-3/4"
 Outer Diameter: 7-3/4"

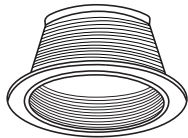

VuLite Housing: Lamp Wattage/Type

V6ICW, V6ICRW: 50W PAR30, 75W PAR30L, 65W BR30
 V6TCW, V6TCRW: 75W PAR30/PAR30L, 65W BR30, 120W BR40

Juno Compatible Housing: Lamp Wattage/Type

IC22, IC22R: 50W PAR30, 75W PAR30L, 65W BR30
 IC2, TC2, TC2R: 75W PAR30 w/socket extender, 75W PAR30L, 65W BR30

Full Baffle

V3034W-WH: White
 V3034B-WH: Black
 V3034TW-WH: White w/Torsion Springs
 V3034TB-WH: Black w/Torsion Springs

Aperture: 5-3/4"
 Outer Diameter: 7-5/8"



VuLite Housing: Lamp Wattage/Type

V6ICW, V6ICNW, V6ICRW: 40W A19*, 75W PAR30/PAR30L, 65W BR30, 90W BR40, 90W PAR38*
 V6TCW, V6TCRW: 60W A19*, 75W PAR30/PAR30L, 85W BR30, 120W BR40, 150W PAR38*

* No A19 listing and 75W PAR38 max. for the V3034B Series

Juno Compatible Housing: Lamp Wattage/Type

IC22, IC22R, IC23: 40W A19, 75W PAR30/PAR30L, 65W BR30, 90W BR40, 90W PAR38
 IC2: 60W A19, 75W PAR30/PAR30L, 85W BR30, 100W PAR38, 120W BR40
 TC2, TC2R: 60W A19, 75W PAR30/PAR30L, 85W BR30, 150W PAR38, 120W BR40
 ICPL6 Series: 32W max. CFLT
 PL6 Series: 42W max CFLT


†Note: For best performance, 26W is recommended.

Patent Pending

Straight Baffle

V3025W-WH: White
 V3025B-WH: Black

Aperture: 5-3/4"
 Outer Diameter: 7-3/4"

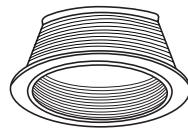

VuLite Housing: Lamp Wattage/Type

V6ICW, V6ICRW: 50W PAR30/PAR30L, 75W PAR38
 V6TCW, V6TCRW: 75W PAR30/PAR30L, 65W BR30, 120W BR40, 120W PAR38

Juno Compatible Housing: Lamp Wattage/Type

IC22, IC22R: 75W PAR30/PAR30L, 65W BR30, 75W PAR38
 IC2: 75W PAR30 w/socket extender, 75W PAR30L, 65W BR30, 90W PAR38, 100W BR40
 TC2, TC2R: 75W PAR30 w/socket extender, 75W PAR30L, 65W BR30, 150W PAR38, 120W BR40

Clear Cone

V3027C-WH: Clear

Aperture: 5-3/4"
 Outer Diameter: 7-3/4"



VuLite Housing: Lamp Wattage/Type

V6ICW, V6ICRW: 50W PAR30, 75W PAR30L, 65W BR30
 V6TCW, V6TCRW: 75W PAR30/PAR30L, 65W BR30, 90W BR40

Juno Compatible Housing: Lamp Wattage/Type

IC2, IC22, IC22R: 50W PAR30, 75W PAR30L, 65W BR30
 TC2, TC2R: 75W PAR30/PAR30L, 65W BR30