

# VuLite® 4" Line Voltage Housings and Trims

Economy Recessed Lighting

## IC Housing

### V4ICW


#### 4" IC New Construction

Energy efficient double wall housing. May be covered with insulation.

#### Dimensions:

12"L x 13-3/8"W x 6"H

Ceiling Cutout: 4-1/2" Dia.

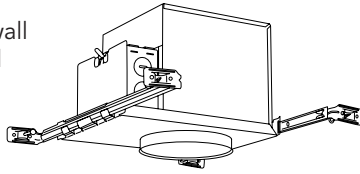

## TC Housings

### V4TCW


#### 4" TC New Construction

Requires 3" spacing from insulation.

#### Dimensions:

12-1/8"L x 13-3/8"W x 5-1/2"H

Ceiling Cutout: 4-1/2" Dia.

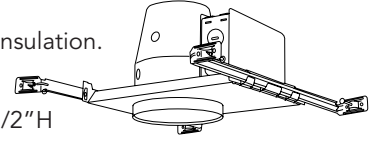

### V4TCRW


#### 4" TC Remodel

Requires 3" spacing from insulation.

#### Dimensions:

12"L x 4-1/4"W x 5-1/2"H

Ceiling Cutout: 4-3/8" Dia.

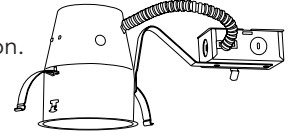

**Accessories:** **VALG4** Airloc® gasket kit for V4IC housing when an Airloc® trim is not being used.  
**G2405** Set of (4) T-bar clips for installation in suspended ceilings.

## 4" Compatible Trims - Line Voltage


### Baffle

V4034W-WH: White

V4034B-WH: Black

Aperture: 3-7/8"

Outer Diameter: 5"

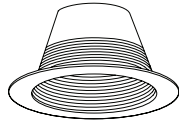

VuLite Housing: Lamp Wattage/Type

V4ICW: 50W PAR20, 30W R20

V4TCW, V4TCRW: 50W PAR20, 50W R20

Juno Compatible Housing: Lamp Wattage/Type

IC1P, TC1, TC1R: 50W PAR20, 50W R20

IC1: 50W PAR20, 30W R20

### Eyeball

V4018-WH: White

Outer Diameter: 5"



VuLite Housing: Lamp Wattage/Type

V4ICW, V4TCW, V4TCRW: 60W PAR16, 40W R16

Juno Compatible Housing: Lamp Wattage/Type


IC1, IC1P, TC1, TC1R: 60W PAR16, 40W R16

### Cone

V4017C-WH: Clear

Aperture: 3-7/8"

Outer Diameter: 5"

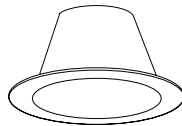

VuLite Housing: Lamp Wattage/Type

V4ICW, V4TCW, V4TCRW: 50W PAR20, 50W R20

Juno Compatible Housing: Lamp Wattage/Type

IC1, IC1P, TC1, TC1R: 50W PAR20, 50W R20

### Stippled Opal Lens Shower with Reflector

V4012-WH: White

Outer Diameter: 5"



VuLite Housing: Lamp Wattage/Type

V4ICW: 35W PAR20, 30W R20

V4TCW, V4TCRW: 50W PAR20, 50W R20

Juno Compatible Housing: Lamp Wattage/Type  
 (Remove reflector when using Juno IC1 housing)

IC1: 35W PAR20, 30W R20

IC1P: 50W PAR20, 30W R20

 
TC1, TC1R: 50W PAR20, 50W R20

### Gimbal Ring

V4010-WH: White

V4010-BN: Brushed Nickel

Outer Diameter: 5"



VuLite Housing: Lamp Wattage/Type

V4ICW, V4TCW, V4TCRW: 50W PAR20

Juno Compatible Housing: Lamp Wattage/Type

IC1P, TC1, TC1R: 50W PAR20