

FEATURES & SPECIFICATIONS

INTENDED USE — High-performance parabolic luminaires for superior light control, visual comfort and light cutoff in open area applications.

CONSTRUCTION — Designed exclusively for use with T8 and CF40 lamps, electronic ballasts and sockets. Housing formed from 20-gauge CRS.

Black reveal provides floating louver appearance.

T-hinges die-formed for maximum strength. Latches spring-loaded, concealed in reveal.

Louvers formed from anodized aluminum. No asbestos is used in this product.

Finish: Five-stage iron-phosphate pretreatment ensures superior paint adhesion and rust resistance. Painted parts finished with high-gloss, baked white enamel.

ELECTRICAL — Thermally protected, resetting, Class P, HPF, non-PCB, UL Listed, CSA certified ballast is standard. Electronic ballasts are sound rated A.

Luminaire is suitable for damp locations. AWM, TFN or THHN wire used throughout, rated for required temperatures.

LISTINGS — UL Listed.

WARRANTY — 1-year limited warranty. Complete warranty terms located at www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx


Note: Specifications subject to change without notice.

Catalog Number
Notes
Type

PARAMAX® Parabolic Troffer

2PM3N 2'X2' NY

3" LOUVER FAMILY
Compact Fluorescent and
Narrow U Lamps

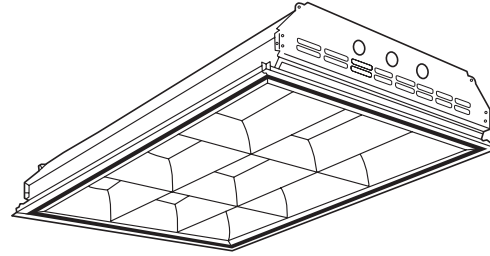

Specifications

Length: 24 (609)

Width: 24 (609)

Depth: 5-13/16 (148)

Weight: 18 lbs (8.2 kg)

All dimensions are inches (millimeters) unless otherwise indicated.

ORDERING INFORMATION

For shortest lead times, configure product using **standard options (shown in bold)**.

Example: 2PM3N G B 3 U31 9LD MVOLT 1/3 GEB10IS NY3

2PM3N	G	B					
Series	Trim type	Air function	Number of lamps	Lamp type	Number of cells	Finish	Voltage
2PM3N Paramax 3" parabolic, 2' wide	G Grid	B Static (no air function)	2 3 4 Not included.	CF40 40W T5 (24") ¹ U31 31W T8 (1-5/8" leg)	6 9 12 16	LD Low iridescent anodized diffuse silver	MVOLT ² Others available.
Options							
1/3 One 3-lamp ballast				EL14 Emergency battery pack (nominal 1400 lumens)			
1/4 One 4-lamp ballast				PWS90N1836 6' prewire, 3/8" dia., 18-gauge, 1 circuit, 90° connector			
2/2 Two 2-lamp ballasts				PWS90N1846 6' prewire, 3/8" dia., 18-gauge, 2 circuits, 90° connector			
GEB10IS Electronic ballast, ≤ 10% THD, instant start				LP735 Lamped, 700-series, 3500K			
GEB10RS Electronic ballast, ≤ 10% THD, rapid start				LP___ Lamped, specify lamp type and color			
EL Emergency battery pack (nominal 300 lumens)				NY3 New York City, Local 3			

Notes


1 Not available with 4-lamp models.

2 MVOLT standard for 120V and 277V applications.

2PM3N 2'x2' NY Compact Fluorescent and Narrow U Lamps, 3" Louver Family

MOUNTING DATA

Ceiling Type	Appropriate Trim Type
Exposed grid tee	G
Concealed grid tee	G

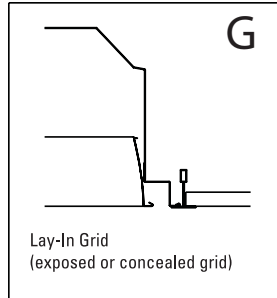

Notes

For hard-ceiling applications, order a drywall grid adaptor (DGA22) as an accessory.

DIMENSIONS

