

Catalog Number	
Notes	Type

## FEATURES & SPECIFICATIONS

### INTENDED USE

For use with housings L3 R6, and L3R R6.

### CONSTRUCTION

White finish has integral flange.

Black baffle finish has polymeric flange ring as standard.

### INSTALLATION

Socket to trim interface.

Retaining clips pull and snap onto top of reflector to hold trim inside housing.


### LISTING

U.L. Listed to U.S. and Canadian safety standards.


Damp location listed.

Pull on clip Patent # (U.S.) 5707143, (Canada) 2193902.

# 4" Trims

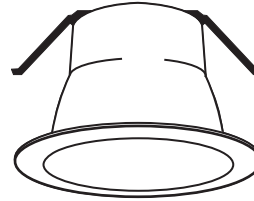

**INCANDESCENT**  
IC/Non-IC  
New Construction  
Remodel

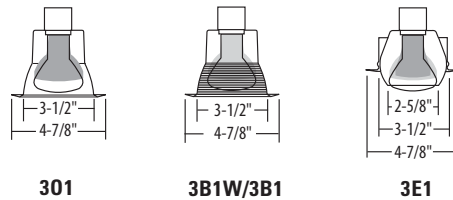

## ORDERING INFORMATION

Must be ordered in standard carton quantity multiples.

<i>Catalog Number</i>	<i>UPC</i>	<i>Description</i>	<i>Max Lamp Wattages</i>	<i>Size</i>	<i>Color</i>	<i>Type</i>	<i>Pallet Qty.</i>	<i>Standard Carton Qty.</i>
301 R12	745975234158	4" trim	IC: 30 R20, 35 Par20; Non-IC: 50 Par20	Narrow	White	Open	1344	12
3B1W R24	745975234264	4" trim	IC: 35 PAR20; Non-IC: 50 Par20	Narrow	White	Baffle	1536	24
3B1 R12	745975234295	4" trim	IC: 35 PAR20; Non-IC: 50 Par20	Narrow	Black	Baffle	1296	12
3E1 R6	745973752937	4" trim	IC: 35 PAR20; Non-IC: 50 R20, 50 Par20	Narrow	White	Eyeball	1080	6

# 4" Trims


Description      Maximum wattage  
Catalog number      Sheet number

---

## General/Task

Open Narrow Flange

**301**      White

<i>IC</i>		30 R20 35 PAR20
<i>Non IC</i>		50 PAR20
IC/Non IC		ROPN-250

---

Baffle Narrow Flange

**3B1**      Black

**3B1W**      White


<i>IC</i>		35 PAR20
<i>Non IC</i>		50 PAR20
IC/Non IC		RBAF-230

---

## Accent/Wallwash

Eyeball Narrow Flange

**3E1**      White

<i>IC</i>		35 PAR20
<i>Non IC</i>		50 PAR20 50 R20
IC/Non IC		RADJ-210

---