

Catalog Number	
Notes	Type

FEATURES & SPECIFICATIONS

INTENDED USE

For use with Non-IC housings LV3, LP3V, LV3R and IC housing LIV3.

CONSTRUCTION

White polyester powder coat paint on flange and sphere.

Tempered safety lens.

30 degree vertical tilt standard.

White integral flange.

INSTALLATION

Retaining clips attached to trim ring to retain trim in housing.


LISTING

U.L. Listed to U.S. and Canadian Standards.

Damp location listed.

3" Finishing Trim

3VDW1

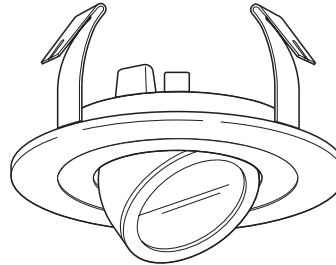

DIRECTIONAL WALLWASH

Low Voltage

Narrow Flange


Specifications

Height: 3-7/8 (9.8)

Lamp Opening: 1-3/4 (4.4)

Diameter: 5 (12.7)

All dimensions are inches (centimeters).

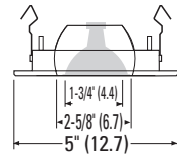

ORDERING INFORMATION

Lead times will vary depending on options selected. Consult with your sales representative.

Example: 3VDW1W

3VDW1W		
Series	Finish	
3VDW1	W	White

Housing Compatibility

Housing and trim ordered separately.

Application	Source	Maximum wattage	Housing
IC	Low Voltage/12v	50 MR16	LIV3
Non-IC	Low Voltage/12v	50 MR16	LV3, LV3R
Non-IC	Low Voltage/12v	75 MR16	LP3V

3VDW1 3" Directional Low Voltage Trim

