

FEATURES & SPECIFICATIONS

INTENDED USE

For use with housings L5 and L5R.

CONSTRUCTION

All finishes are one-piece aluminum open reflectors with integral white flange.

INSTALLATION

Socket to trim interface.

Retaining clips pull and snap on to top of trim to hold trim inside housing.

LISTING

UL Listed to U.S. and Canadian safety standards.


Damp location listed.

Catalog Number	
Notes	Type

5" Finishing Trim

502

OPEN DEEP
Narrow Flange

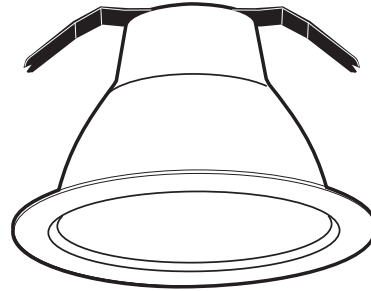


Specifications

Height: 5-3/4 (14.6)

Lamp opening: 5-1/8 (13)

Diameter: 6-3/8 (16.2)

All dimensions are inches (centimeters).

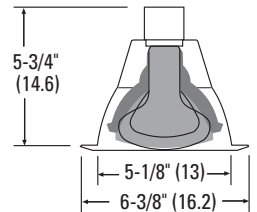

ORDERING INFORMATION

Lead times will vary depending on options selected. Consult with your sales representative.

Example: **502A**

502	
Series	Finish
502	Anodized finish ²
	A Clear diffuse
	AZ Clear specular
	BLZ Black specular

NOTES:

1 Not available with torsion springs or white finish. For white finish, see 502-TOR spec sheet.

Housing Compatibility

Housing and trim ordered separately.

Application	Source	Maximum wattage	Housing
IC	Incandescent	60 PAR38	L5, L5R
		65 BR30	L5, L5R
		50 R20	L5, L5R
		75 PAR30 (short neck)	L5, L5R

502 5" Open Deep Full Reflector Trim

For BR and PAR reflector lamps, see lamp manufacturer's published raw lamp data for photometrics.

