


3" IC/Non-IC Housing

# LI3 & L3

**IC/Non-IC Rated Full Trim** – All trims are damp location listed. WETlite™ is listed for wet locations. Lamp types and maximum wattages are listed for each trim. White flange standard, except as noted.

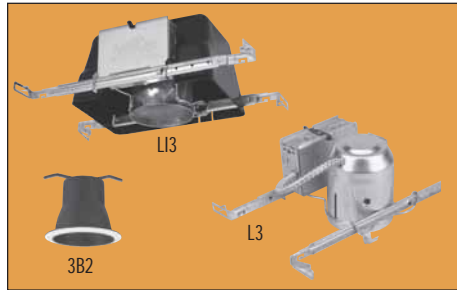

**Intended Use**

Recessed housing rated IC or Non-IC for new construction applications. Approved for direct burial in insulation (IC) and through-branch circuit wiring. Approved for most wiring and ceiling types.

**Features**

One-piece aluminum can. Compact thermal plastic shroud on LI3 for higher wattages in IC installations. Galvanized steel rod frame and J-box.

Factory-installed, captive bar hangers span 24" and feature built-in nailers and T-bar clips. Snap-lock rail clip locks fixture into place. J-box has built-in Romex clamps and a ground wire.

Suitable for ceilings up to 2" thick.

Socket clips to trim to ensure proper and consistent lamp position.

**Listings**

UL Listed to U.S. and Canadian safety standards.

**Shallow open trim**

- 301 White
- 301A Clear diffuse
- 301AZ Clear specular
- 301G Gold diffuse
- 301GZ Gold specular
- 301BLZ Black specular



IC (L3)	IC (LI3)	Non-IC (LI3)
30 R20	50 R20	50 PAR20
35 PAR20	50 PAR20	75 PAR16
	40 PAR16	

**Deep, open trim**

- 302 White
- 302A Clear diffuse
- 302AZ Clear specular
- 302G Gold diffuse
- 302GZ Gold specular
- 302BLZ Black specular



IC (LI3)	Non-IC (L3)
40 A19	50 PAR20
40 PAR16	60 PAR16
30 R20	
35 PAR20	

**Shallow baffle**

- 3B1 Black
- 3B1W White



IC (L3)	IC (LI3)	Non-IC (L3)
30 R20	50 R20	50 PAR20
35 PAR20	50 PAR20	75 PAR16
	40 PAR16	

**Deep baffle**


- 3B2 Black
- 3B2W White



IC (LI3)	Non-IC (L3)
40 PAR16	50 PAR20
30 R20	45 PAR16
35 PAR20	

**Wallwash**

- 3W1 White

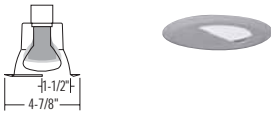

IC (LI3)	Non-IC (L3)
30 R20	50 R20
35 PAR20	50 PAR20
	40 PAR16

**Eyeball**

- 3E1 White



IC (L3)	IC (LI3)	Non-IC (L3)
35 PAR20	75 R20	50 R20
40 PAR16	50 PAR20	50 PAR20
75 PAR16		

**Pinhole**

- 3S1 White



IC (L3, LI3)	Non-IC (L3)
35 R20	50 R20
35 PAR20	35 PAR20
	45 PAR16

**WETlite™**

- 3H20 White
- 3H20PC Polished Chrome<sup>1</sup>
- 3H20CP Polished Copper<sup>1</sup>





IC (LI3)	IC (L3)
75 PAR30	75 PAR30

(Ships with outdoor-rated 75W PAR30 lamp)

**Ordering Information**

Example: **L3**

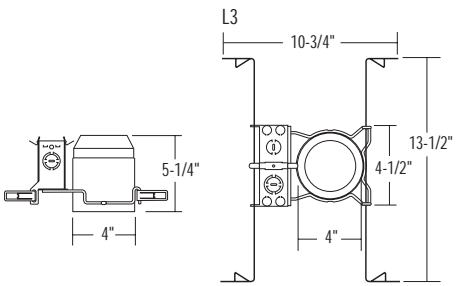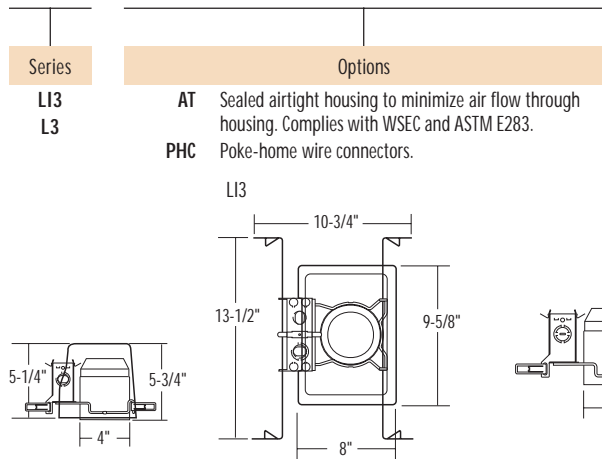

**lightquick<sup>®</sup> XD**  
Express delivery products.  
See page 11 for details about LightQuick XD.

Description
L3 M6
3B1W M12
3E1 M6
3H20

NOTES:  
1 Flange matches trim finish.

**IMPORTANT:** For packaging information, see page 322. See specification sheets for complete trim selection.

Drawings are for dimensional detail only and may not represent actual mechanical configuration. Dimensions are shown in inches.

www.lithonia.com, keywords: LI3 and L3