

Catalog Number	
Notes	Type

FEATURES & SPECIFICATIONS

INTENDED USE

For use with Non-IC housings LV3, LP3V, LV3R and IC housing LIV3.

CONSTRUCTION

White polyester powder coat paint.

White eyelid conical cone.

Tempered safety lens.

30 degree vertical tilt standard.

White integral flange.

INSTALLATION

Retaining clips attached to trim ring to hold trim in housing.


LISTING

U.L. Listed to U.S. and Canadian safety standards.

Damp location listed.

3" Finishing Trim

3VW1

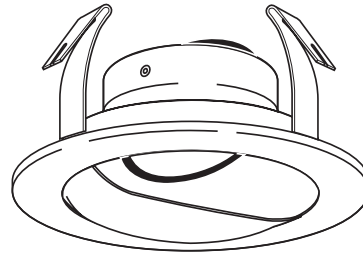

EYELID WALLWASHER

Low Voltage

Narrow Flange


Specifications

Height: 3-7/8 (9.8)

Lamp Opening: 1-3/4 (4.5)

Diameter: 5 (12.7)

All dimensions are inches (centimeters).

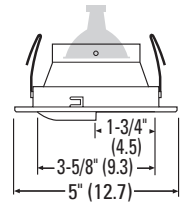

ORDERING INFORMATION

Lead times will vary depending on options selected. Consult with your sales representative.

Example: 3VW1

3VW1	
Series	Finish
3VW1	(blank) White

Housing Compatibility

Housing and trim ordered separately.

Application	Source	Maximum wattage	Housing
IC	Low Voltage	50 MR16	LIV3
Non-IC	Low Voltage	50 MR16	LV3, LV3R
Non-IC	Low Voltage	75 MR16	LP3V

3VW1 3" Wallwash Low Voltage Trim

