

| | |
|----------------|------|
| Catalog Number | |
| Notes | Type |

FEATURES & SPECIFICATIONS

INTENDED USE

For use with housings LC6, L7X, L7XR.

CONSTRUCTION

Oil-rubbed bronze, brushed nickel and white finishes are one-piece aluminum open reflector with integral flange.

INSTALLATION

Socket to trim interface.

Trim retention is achieved by utilizing two side-mounted torsion springs on the trim and two receiving brackets in the can, ensuring a consistently tight fit with the ceiling.

LISTINGS

U.L. Listed to U.S. and Canadian safety standards.



Wet location listed when used with outdoor rated 75W PAR38 or 75W PAR30 short neck lamp.

NOTE: Specifications subject to change without notice.

6" Finishing Trim

6H20

WETLITE
Drop Flange

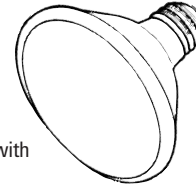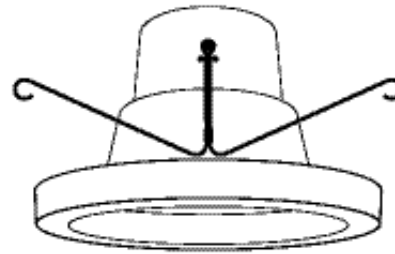

Lamp included with trim
(75W PAR30)


Specifications

Height: 4-3/4 (12.1)

Lamp opening: 6-1/8 (15.6)

Diameter: 7-5/8 (19.4)

All dimensions are inches (centimeters) unless otherwise specified.

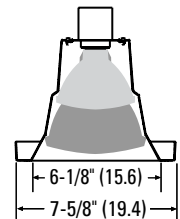

ORDERING INFORMATION

For shortest lead times, configure product using **standard options (shown in bold)**.

Example: **6H20 TOR**

| 6H20 | | TOR | |
|-------------|--|-----------------|------------------------|
| Series | Finish | Mounting method | |
| 6H20 | (blank) White MW Matte white ORB Oil-rubbed bronze BN Brushed nickel | TOR | Torsion springs |

Housing Compatibility

Housing and trim ordered separately.

| Application | Source | Maximum wattage | Housing |
|-------------|--------------|-----------------------|----------------|
| IC | Incandescent | 75 PAR38* | LC6, L7X, L7XR |
| | | 75 PAR30* (shortneck) | LC6, L7X, L7XR |

*outdoor rated lamp only

6H20 6" Wetlite Drop Flange Full Reflector Trim

For BR and PAR reflector lamps, see lamp manufacturer's published raw lamp data for photometrics.

