

Catalog Number	
Notes	Type

FEATURES & SPECIFICATIONS

INTENDED USE

Recessed remodeler rated Non-IC for use in Remodel applications.

Approved for all ceiling and wiring types.

CONSTRUCTION

Snap-on splice box provided with ground wire and knockout opening for Romex clamp.

ELECTRICAL SYSTEM

Durable medium base porcelain socket is mounted securely to top of reflector housing, or eyeball.

Thermal protection provided against improper insulation use.

INSTALLATION

Mounting ring prongs provide snug reflector fit in ceiling.

Galvanized metal mounting ring accommodates ceiling thickness from 1/8" to 1" and provides snug reflector fit.

For end of run wiring installations only.


LISTING

U.L. Listed to U.S. and Canadian safety standards.

Damp location listing.

3" Remodeler


E3 Series

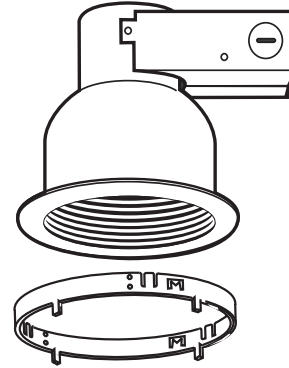

INCANDESCENT

Non-IC

Remodel Construction
Complete Optical/Electrical

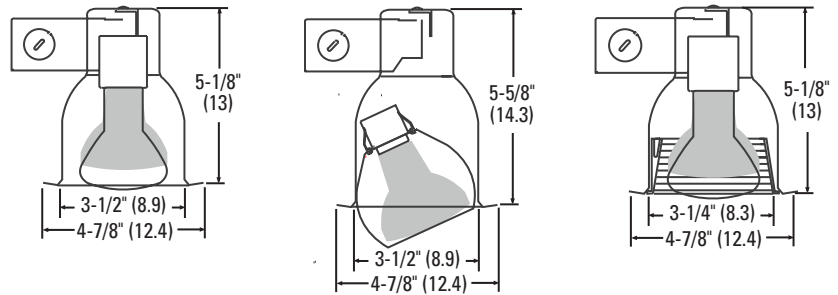

All dimensions are inches (centimeters).

ORDERING INFORMATION

Example: **E3B1**

Choose the boldface catalog nomenclature that best suits your needs and write it on the appropriate line. Order accessories as separate catalog number.

E3

Series	Finish
E3	01 White Open
	B1 Black Baffle
	B1W White Baffle
	E1 White Eyeball

NOTE:

See trim summary on reverse side for maximum wattages.

E3 Series 3" Incandescent Complete Optical Fixtures

Description Maximum wattage
Catalog number Sheet number

General/Task

Open

E301 White



50W R20
50W PAR20

Non-IC RCMP-110

Baffle

E3B1 Black Baffle

E3B1W White Baffle



 
50W R20
50W PAR20

Non-IC RCMP-110

Accent

Eyeball

E3E1 White



50W R20
50W PAR20

IC RCMP-110

NOTES:

1 Maximum wattage listed. Lower wattage lamps may be used.



An **AcuityBrands** Company

Lithonia Lighting

Acuity Lighting Group, Inc.

Recessed Downlighting

One Lithonia Way, Conyers, GA 30012

Phone: 800-315-4935 Fax: 770-860-3106

In Canada: 1100 50th Ave., Lachine, Quebec H8T 2V3

www.lithonia.com