

Catalog Number	
Notes	Type

FEATURES & SPECIFICATIONS

INTENDED USE

Recessed housing rated IC. For remodel construction only.
 Approved for factory assembled wiring only.
 Approved for direct burial in insulation.

CONSTRUCTION

Self flanged aluminum housing.
 Four remodel clips for installation in existing plaster, sheet rock or mechanical ceiling.
 Heavy-gauge galvanized steel raceway arm.
 Galvanized steel junction box with four built in romex clamps. Seven 1/2" knockouts with slots for pryout. Not suitable for pulling wires.
 Rated for 90° C.
 Ground wire provided.
 Removable J-box doors for easy access.

ELECTRICAL SYSTEM

Durable medium base porcelain socket with nickel plated copper alloy screw shell and contact.
 Socket clips to top of housing to prevent paint overspray in socket screw shell.
 Socket attaches to reflector to ensure proper and consistent lamp position.
 Thermal protection provided against improper lamp usage.
 120 volt only.

INSTALLATION


2 x 8 existing ceiling or T-bar ceiling panel installation.
 Clip adjustment on housing (up to 1-1/4") allows for flush mounting with ceiling face.
 Ceiling cutout 5-9/16".

LISTING

U.L. listed (standard). CSA Certified (see Options). Damp location listing (See trim selection for wet location listing).

5" Housing


L5R

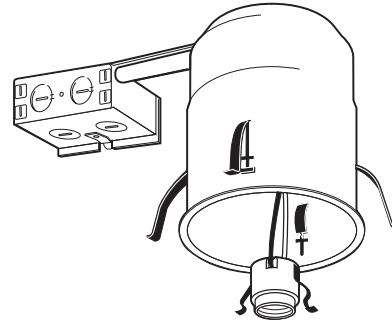

INCANDESCENT
 IC
 Remodel Construction

Specifications

Height: 7-1/2" (19.1)
 Length: 11-1/2" (29.2)
 Width: 5-3/4" (14.6)

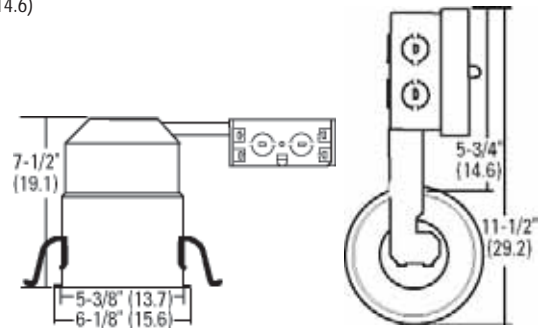

All dimensions are inches (centimeters).

ORDERING INFORMATION

Choose the boldface catalog nomenclature that best suits your needs and write it on the appropriate line. Order accessories as separate catalog number.

Example: **L5R AT**

L5R	
Series	Options
L5R	(Shipped installed in fixture) AT Airtight gasketing seals housing to minimize air flow through rough-in. Complies with WSEC. CSA CSA Certified. PHC Poke-home wire connectors.

Accessories:

Order as separate catalog number.

ATK5 Airtight kit

NOTE:

See trim summary on reverse side for maximum wattages.

