

MX8 8" MH ED17 Downlight Magnetic Ballast, Protected Lamp

Features

- Clear specular reflector or black baffle with white trim ring
- Extruded aluminum socket housing
- Extended husk socket accepts only protected MH lamps rated for open luminaires
- Butterfly style mounting brackets accommodate 1/2" EMT, 3/4" & 1 1/2" C-channel and linear bars
- UL/CSA Listed for feed through and damp locations







Description

Provides uniform light distribution with very good brightness control

Rough-In Ordering Example: **MX8-70-Q**

Catalog No.	Description	Ballast	Options (add as suffix)
MX8-70	70W MH, Medium Base	120/277V Dual Tap HPF Magnetic	Q -Quartz Restrike (Add as suffix to rough in and reflector catalog number) CN -120/347V Dual Tap ballast ***F -Fuse and Fuseholder (where *** = Voltage)
MX8-100	100W MH, Medium Base	120/277V Dual Tap HPF Magnetic	


Reflector Ordering Example: **8800XCQ-WH**

Catalog No.	Description
 8800XC-WH	ED17 Open Multiplier, Specular Clear w/White Trim Ring
 8801XB-WH	ED17 Black Baffled Open Multiplier, Specular Clear w/White Trim Ring
 8840-WH	Prismatic Glass Lens w/Regressed Black Baffle Trim w/White Trim Ring
 8842-WH	Fresnel Lens w/Regressed Black Baffle Trim w/White Trim Ring

Accessories Ordering Example: **HB-26**

Catalog No.	Description
HB-26	26" C-Channel Bar Hangers (Set of 2)
HB-50	50" C-Channel Bar Hangers (Set of 2)
LB-27	27" Linear Bar Hangers (Set of 2)

Dimensions

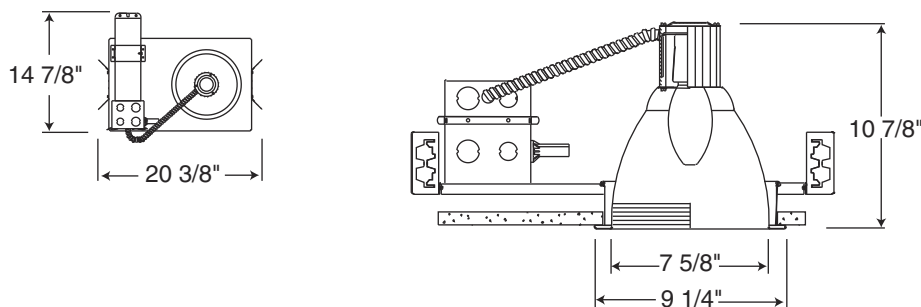

8 1/2" Ceiling Cutout





Features

- Clear specular reflector or black baffle with clear glass safety lens and white trim ring
- Extruded aluminum socket housing
- Butterfly style mounting brackets accommodate 1/2" EMT, 3/4" & 1 1/2" C-channel and linear bars
- UL/CSA Listed for feed through and damp locations




Description

Provides uniform light distribution with very good brightness control

Rough-In Ordering Example: **M8-70-Q**

Catalog No.	Description	Ballast	Options (add as suffix)
M8-70	70W MH, Medium Base	120/277V Dual Tap HPF Magnetic	Q -Quartz Restrike (Add as suffix to rough-in and reflector catalog number) CN -120/347V Dual Tap ballast F -Slow Blow fuse and fuseholder ***F -Fuse and Fuseholder (where *** = Voltage)
M8-100	100W MH, Medium Base	120/277V Dual Tap HPF Magnetic	


Reflector Ordering Example: **8800CQ-WH**

Catalog No.	Description
 8800C-WH	ED17 Open Multiplier, w/Clear Glass Safety Lens, Specular Clear w/White Trim Ring
 8801B-WH	ED17 Black Baffled Open Multiplier w/Clear Glass Safety Lens w/White Trim Ring
 8840-WH 8842-WH	Prismatic Glass Lens w/Regressed Black Baffle Trim w/White Trim Ring Fresnel Lens w/Regressed Black Baffle Trim w/White Trim Ring

Accessories Ordering Example: **HB-26**

Catalog No.	Description
HB-26	26" C-Channel Bar Hangers (Set of 2)
HB-50	50" C-Channel Bar Hangers (Set of 2)
LB-27	27" Linear Bar Hangers (Set of 2)

Dimensions

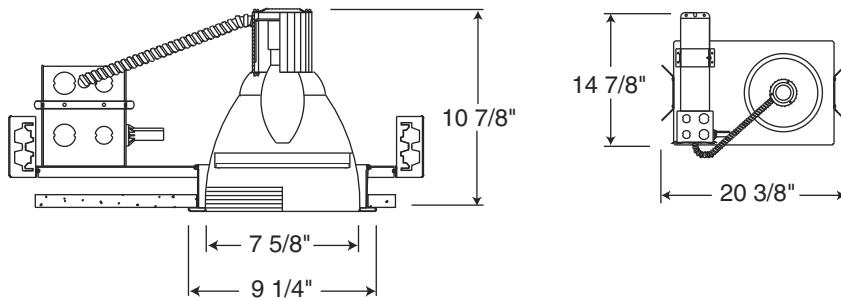


8 1/2" Ceiling Cutout

MX8-E 8" MH ED17 Downlight Electronic Ballast, Protected Lamp

Features

- Clear specular reflector or black baffle with white trim ring
- Electronic ballast provides 10-17% greater efficiency, improved lumen/color maintenance and up to 20% longer life as compared to MH lamps operated off of magnetic ballasts
- Extended husk socket accepts only protected MH lamps rated for open luminaires
- Open and baffled multipliers are interchangeable with common rough-in housing
- Butterfly style mounting brackets accommodate 1/2" EMT, 3/4" & 1 1/2" C-channel, linear bars and Real Nail™ 3 bar hangers
- UL/CSA Listed for feed through and damp locations

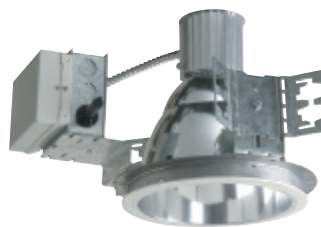





Description

Provides uniform light distribution with very good brightness control

Rough-In Ordering Example: **MX8-70E-Q**

Catalog No.	Description	Ballast	Options (add as suffix)
MX8-70E	70W MH, Medium Base	120/277V HPF Electronic	Q -Quartz Restrike (Add as suffix to rough in and reflector catalog number)
MX8-100E	100W MH, Medium Base	120/277V HPF Electronic	***F -Fuse and Fuseholder
MX8-150E/120	150W MH, Medium Base	120V HPF Electronic	(where *** = Voltage)
MX8-150E/277	150W MH, Medium Base	277V HPF Electronic	


Reflector Ordering Example: **8800XCQ-WH**

Catalog No.	Description
 8800XC-WH	ED17 Open Multiplier, Specular Clear w/White Trim Ring
 8801XB-WH	ED17 Black Baffled Open Multiplier, Specular Clear w/White Trim Ring
 8840-WH	Prismatic Glass Lens w/Regressed Black Baffle Trim w/White Trim Ring
 8842-WH	Fresnel Lens w/Regressed Black Baffle Trim w/White Trim Ring

Accessories Ordering Example: **HB-26**


Catalog No.	Description
HB-26	26" C-Channel Bar Hangers (Set of 2)
HB-50	50" C-Channel Bar Hangers (Set of 2)
HB-1	Adjustable 13 1/2" - 25" Real Nail 3 Bar Hangers
LB-27	27" Linear Bar Hangers (Set of 2)

Dimensions

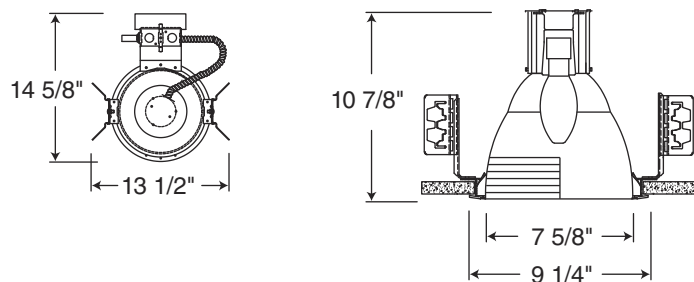

8 1/2" Ceiling Cutout



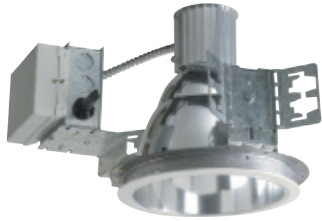

Description

Provides uniform light distribution with very good brightness control





Features

- Clear specular reflector or black baffle with clear glass safety lens and white trim ring
- Extruded aluminum socket housing
- Butterfly style mounting brackets accommodate 1/2" EMT, 3/4" & 1 1/2" C-channel, linear bars and Real Nail™ 3 bar hangers
- UL/CSA Listed for feed through and damp locations

Rough-In Ordering Example: M8-70E-Q

Catalog No.	Description	Ballast	Options (add as suffix)
M8-70E	70W MH, Medium Base	120/277V HPF Electronic	Q -Quartz Restrike (Add as suffix to rough in and reflector catalog number) ***F -Fuse and Fuseholder (where *** = Voltage)
M8-100E	100W MH, Medium Base	120/277V HPF Electronic	
M8-150E/120	150W MH, Medium Base	120V HPF Electronic	
M8-150E/277	150W MH, Medium Base	277V HPF Electronic	


Reflector Ordering Example: 8800CQ-WH

Catalog No.	Description
 8800C-WH	ED17 Open Multiplier w/Clear Glass Safety Lens, Specular Clear w/White Trim Ring
 8801B-WH	ED17 Black Baffled Open Multiplier w/Clear Glass Safety Lens, Specular Clear w/White Trim Ring
 8840-WH	Prismatic Glass Lens w/Regressed Black Baffle Trim w/White Trim Ring
 8842-WH	Fresnel Lens w/Regressed Black Baffle Trim w/White Trim Ring

Accessories Ordering Example: HB-26

Catalog No.	Description
HB-26	26" C-Channel Bar Hangers (Set of 2)
HB-50	50" C-Channel Bar Hangers (Set of 2)
HB-1	Adjustable 13 1/2" - 25" Real Nail 3 Bar Hangers
LB-27	27" Linear Bar Hangers (Set of 2)

Dimensions

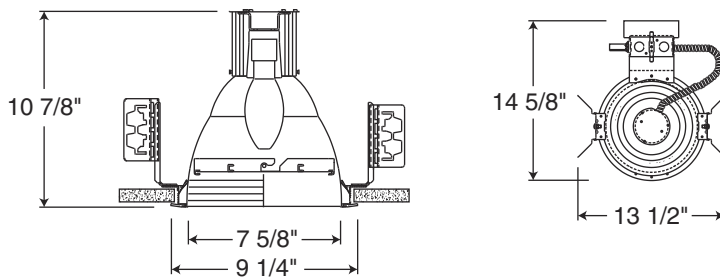

8 1/2" Ceiling Cutout