


FEATURES

- Designed for applications requiring the clean appearance of a flat bottom diffuser
- 100% acrylic prismatic diffuser
- Diffuser hinges open from both sides for easy cleaning and service
- Intended for surface or stem mounting, unit or row installation

Square-Basket Wraps

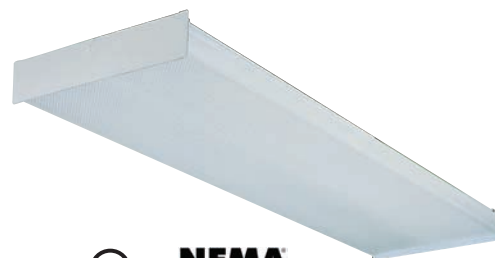


ORDERING INFORMATION

Catalog Number	UPC	Description	# of Lamps	Length	# of Ballast	Wattage	Voltage	Ballast Type	Lamp Included	Pallet Qty.	Standard Carton Qty.
SB217 MV	745975145188	Wraparound	2	24"	1	17	120-277	NEMA Premium®, Instant Start	N	150	1
SB232 MV	745975083633	Wraparound	2	48"	1	32	120-277	NEMA Premium®, Instant Start	N	75	1
SB432 MV	745975083619	Wraparound	4	48"	1	32	120-277	NEMA Premium®, Instant Start	N	42	1

DIMENSIONS

Height: 2-5/8" (2-lamp) or 2-7/8" (4-lamp)
 Length: 24" or 48"
 Width: 8-5/8" (2-lamp) or 13-3/4" (4-lamp)

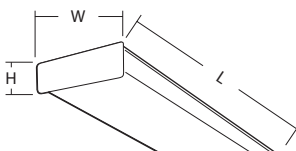


ACCESSORIES

- **DSB24** 24" Replacement Lens for 2-Lamp
- **DSB48** 48" Replacement Lens for 2-Lamp
- **D2SB48** 48" Replacement Lens for 4-Lamp

FEATURES

- Small profile design is ideal for light commercial and residential applications
- One-piece channel/end plate design
- Acrylic prismatic diffuser lift and shift into place
- Intended for surface mounting, unit installation

Narrow-Basket Wraps

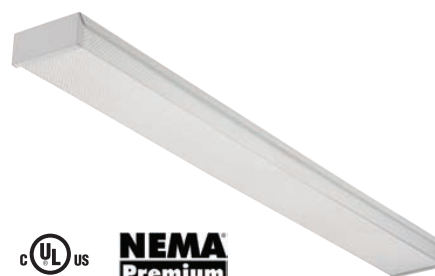


ORDERING INFORMATION

Catalog Number	UPC	Description	# of Lamps	Length	Wattage	# of Ballast	Voltage	Ballast Type	Lamp Included	Pallet Qty.	Standard Carton Qty.
RB217 MV	745976984540	Wraparound	2	24-7/8"	17	1	120-277	NEMA Premium®, Instant Start	N	288	1
RB232	745973790076	Wraparound	2	48-7/8"	32	1	120	Electronic, Instant Start	N	144	1
RB232 MV	745975747092	Wraparound	2	48-7/8"	32	1	120-277	NEMA Premium®, Instant Start	N	144	1

DIMENSIONS

Length: 24-7/8" or 48-7/8"

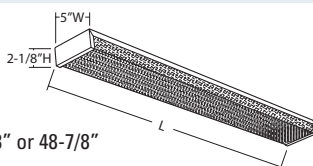

ACCESSORIES

- **D3348/DRB 4** 48" Replacement Lens for 2-Lamp

Certain airborne contaminants can diminish integrity of acrylic. See pg.132 for Acrylic Compatibility table for suitable uses.