

Catalog Number	
Notes	Type



Low-Profile Reflectors

FEATURES & SPECIFICATIONS


CONSTRUCTION

Die-formed from code-gauge, cold-rolled steel. Secured to channel.
 Finish: Five-stage, iron-phosphate pretreatment ensures superior paint adhesion and rust-resistance. High-gloss, baked white enamel finish. SSR specular finish aluminum reflectors available.


Z5ASR/Z5SMR

2', 3', 4', 6' or 8' length
 Asymmetric or Symmetric

Reflectors for Z Series Fixtures

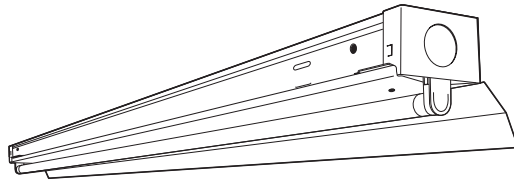

ASR One Lamp

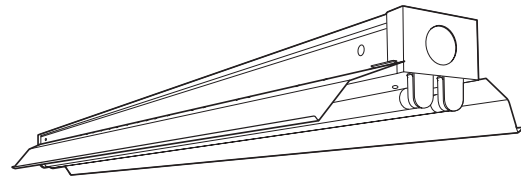

SMR Two Lamps

ORDERING INFORMATION

For shortest lead times, configure product using **standard options (shown in bold)**.

Example: Z5SMR 46 A8

Series	Length	Distribution	Finish
Z5ASR Asymmetric reflector	22 Nominal 22" length	A2 ASR with 2% uplight	(blank) White
Z5SMR Symmetric reflector	34 Nominal 34" length	A4 ASR with 4% uplight	MB Matte black
	46 Nominal 46" length	A5 SMR with 5% uplight	GALV Galvanized
		A8 SMR with 8% uplight	SKGY Smoke gray
			SSR Specular finish aluminum (95% reflectance)
			P Perforated

Accessories

Order as separate catalog numbers.

- ZSPRG Tong and T-grid hanger
- WGZ5SMR46 4' wireguard, white, for symmetric reflector
- WGZ5ASR46 4' wireguard, white, for asymmetric reflector

