

Catalog Number	
Notes	Type

FEATURES & SPECIFICATIONS

INTENDED USE

Recessed remodeler rated Non-IC for use in Remodel applications.

Approved for all ceiling and wiring types.

CONSTRUCTION

Snap-on splice box provided with ground wire and knockout opening for Romex clamp.

ELECTRICAL SYSTEM

Durable medium base porcelain socket is mounted securely to top of reflector housing.

Thermal protection provided against improper insulation use.

INSTALLATION

Mounting ring prongs provide snug reflector fit in ceiling.

Galvanized metal mounting ring accommodates ceiling thickness from 1/8" to 1" and provides snug reflector fit.

For end of run wiring installations only.


LISTING

U.L. Listed to U.S. and Canadian safety standards.

Damp location listing.

4" Remodeler


E3 SERIES

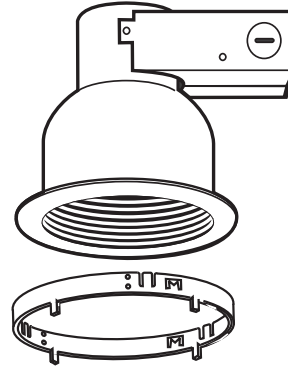

INCANDESCENT

Non-IC

Remodel Construction
Complete Optical/Electrical

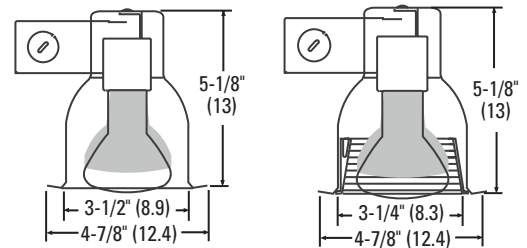

All dimensions are inches (centimeters).

ORDERING INFORMATION

Lead times will vary depending on options selected. Consult with your sales representative.

Example: E3B1W

E3	
Series	Finish
E3	01 White open
	B1 Black oaffle
	B1W White baffle

NOTE:

See trim summary on reverse side for maximum wattages.

E3 Series 4" Incandescent Complete Optical Fixtures

Description Maximum wattage
Catalog number Sheet number

General/Task

Open

E301 White

50W R20
50W PAR20

Non-IC RCMP-110

Baffle

E3B1 Black Baffle

E3B1W White Baffle

50W R20
50W PAR20

Non-IC RCMP-110

NOTES:

- 1 Maximum wattage listed. Lower wattage lamps may be used.

