

FEATURES

- Affordable LED lay-in that delivers general ambient lighting for many applications such as schools, offices and hospitals
- Smooth hemmed sides and smooth inward-formed end flanges for easy handling
- Long-life LEDs, coupled with high-efficiency drivers, provide a superior level of illumination
- Rated to deliver L80 performance for 50,000 hours
- Fully dimmable down to 10%
- CSA certified to U.S. and Canadian standards
- Design Lights Consortium (DLC) Listed

2'x2' and 2'x4'




ORDERING INFORMATION

Catalog Number	UPC	Description	Lumens*	Color Temperature*	Lens Type	Voltage	Wattage*	Pallet Qty.	Standard Carton Qty.
GTLED4 45L D50	753573225300	2x4 LED Recessed Troffer	4,500	3500K	Matte White	120 - 277	50	7	1
GTLED2 31L D38	784231950470	2x2 LED Recessed Troffer	3,100	3500K	Matte White	120 - 277	38	14	1


* Numbers listed are nominal.

DIMENSIONS

GTLED 2x4

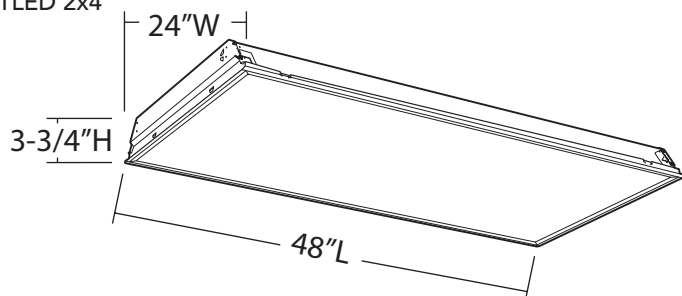

GTLED 2x2

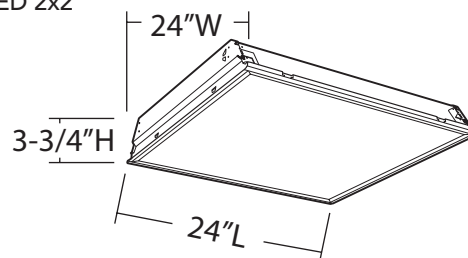

Certain airborne contaminants can diminish integrity of acrylic. See pg.116 for Acrylic Compatibility table for suitable uses.