

Catalog Number
Notes
Type

FEATURES & SPECIFICATIONS

INTENDED USE

Provides an LED lighting platform to deliver general ambient lighting for surface-mount ceiling applications. Light engine delivers long life and excellent color to ensure a quality, low-maintenance light installation.

CONSTRUCTION

Metal parts are die formed from code-gauge steel. Diffuser is 100% textured durable white acrylic. Continuous side flanges on fixture body provide light trap and continuous diffuser support to prevent accidental opening and simplify maintenance.

Finish: Five-stage iron phosphate pretreatment assures superior paint adhesion and rust resistance. Painted parts finished with high-gloss, high-reflectivity baked white polyester enamel (low VOC).

OPTICS

Thermal formed diffuser is of highly transmissive material to minimize lamp image and provides high-angle brightness control. One piece contemporary design wrap around diffuser softens appearance for improved aesthetics.

ELECTRICAL

Long-life LEDs, coupled with a high-efficiency driver, provide extended service life. Standard input = 35 watts, 88 lumens per watt. FMLL is rated to deliver L70 performance at 50,000 hours. Fixture operates at 120 volts, 60Hz.

Actual wattage may differ by +/- 5% when operating at 120V +/- 10%.

LISTINGS

CSA certified to US and Canadian standards. Listed for damp locations.

WARRANTY


5-year limited warranty. Complete warranty terms located at www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Actual performance may differ as a result of end-user environment and application.


Note: Specifications subject to change without notice.

Decorative Indoor

LED Litepuff Linear Low Profile Flush Mount

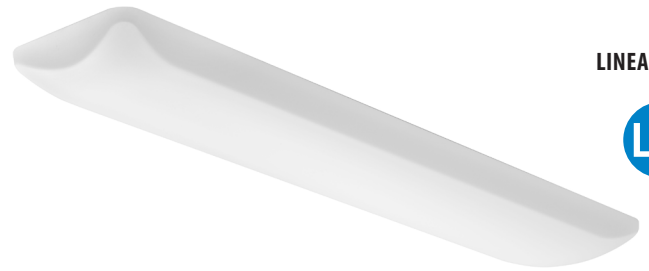

LINEAR LED

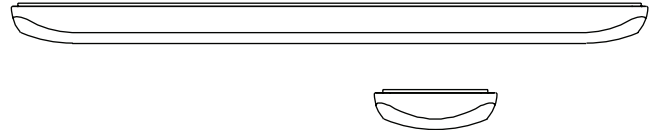

Specifications

Width: 9-1/4 (23.5)

Length: 47-7/8 (121.7)

Depth: 3-1/4 (8.3)

Weight: 7.18 lbs

All dimensions are inches (centimeters) unless otherwise indicated.

ORDERING INFORMATION

For shortest lead times, configure products using **bolded options**.

Example: FMLL 9 30840

Series¹	
FMLL 9 30840	4' LED low profile linear flush mount, 120V, 3074 lumens, 85.5 CRI, 4000 K

Accessories/Replacement parts	
DFMLL	1' x 4' white acrylic diffuser

Notes

¹ Use with non-dimmable switches only.

LED Linear Flush Mount

PHOTOMETRICS

Full photometric data report available within 2 weeks from request. Consult factory.