

FEATURES & SPECIFICATIONS

INTENDED USE

For use with housings L3 and L3R. The small aperture adjustable gimbal designed for PAR20 lamps are an excellent choice for lower installation-height applications such as soffits, casework, and niches. Ideal for hospitality, retail, residential and apartment interior spaces, such as kitchens, dining rooms, bedrooms, and lounge areas.

CONSTRUCTION

Durable powder-coated steel finishing trim.

Directional accent lighting gimbal ring available in matte white and black, oil rubbed bronze, brush nickel and clear diffuse finishes.

35° vertical tilt standard.

180° horizontal rotation.

INSTALLATION

Socket to trim interface.

Retaining clips attached to trim ring hold trim inside housing.

LISTINGS

cETLus listed to U.S. and Canadian safety standards.

Damp location listed.

WARRANTY

1-year limited warranty. Complete warranty terms located at

www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Actual performance may differ as a result of end-user environment and application.

Note: Specifications subject to change without notice.

Catalog Number
Notes
Type

4" Finishing Trim

4G2 PAR



 
GIMBAL
Narrow Flange



Matte black



Brushed nickel



Oil-rubbed bronze



Clear diffuse


Specifications

Height: 3-3/4 (9.6) with PAR Lamp

Lamp opening: 2-1/2 (6.3)

Diameter: 5-1/8 (13.01)

All dimensions are inches (centimeters) unless otherwise indicated.

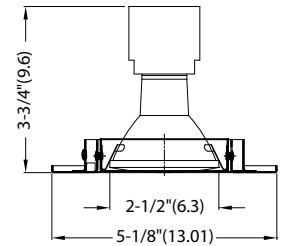

ORDERING INFORMATION

For shortest lead times, configure product using **bolded options**.

Example: 4G2MW PAR20

4G2		Lamp
Series	Finish	
4G2	MW Matte white	PAR20
	ORB Oil rubbed bronze	
	BN Brushed nickel	
	MB Matte black	
	A Clear diffuse	

Housing Compatibility: Housing and trim ordered separately.

Application	Source	Maximum wattage	Housing
IC	Incandescent	50 PAR20 <i>short or long neck</i>	L3, L3R
	LED	8 PAR20	

4G2 4" Gimbal Trim

For PAR reflector lamps, see lamp manufacturer's published raw lamp data for photometrics.