

OVERVIEW

Utilizing pre-terminated **CAT-5e** cables is a great way to reduce labor costs. These **CAT-5e** patch cables are pre-terminated with RJ45 style connectors on both ends. All cables are plenum rated and conform to the T568B pin-pair specification. The RJ-45 terminations are unbooted (i.e. no molded strain relief) which allows for easier connection to nLight devices. Cables are available in several lengths for convenience. All cables are white (with the exception of red isolation cables) and labeled "Acuity Brands Controls".

SPECIFICATIONS

- 350MHz
- 4 Pair 24 AWG Wire (Solid)
- ROHS Complaint
- TIA/EIA-568-B.2 Wired
- ETL
- FT6 and CMP Plenum Rated


Red CAT5 Isolation Cables only communicate, they do not provide bus power.

Note: Maximum cable length per zone is 1500 feet.



nLight®

CAT5
Preterminated Cable

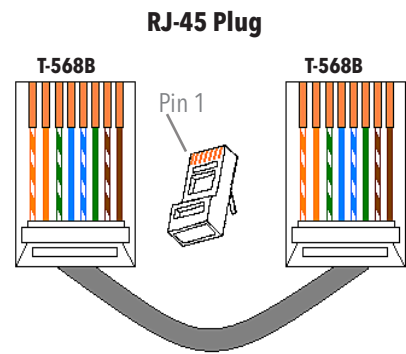

ORDERING INFORMATION

| CAT5 | | | |
|--------------|-------------|----------------|--|
| Cable | | Accessories | |
| CAT5 6IN J1 | 6 in Cable | CAT5 Y | All Female Y Splitters (10 count) |
| CAT5 2FT J1 | 2 ft Cable | CAT5 1FT Y | 1ft Cable & Male to Female Y Splitters (10 count) |
| CAT5 5FT J1 | 5 ft Cable | CAT5 CPLR J1 | 1 Female to 1 Female Coupler |
| CAT5 10FT J1 | 10 ft Cable | CAT5 ISO J1 | 6 in Isolation Cable & 1 Female to 2 Female Splitter |
| CAT5 15FT J1 | 15 ft Cable | CAT5 ISO EZ J1 | 6 in Isolation Cable & 1 Female to 1 Female Coupler |
| CAT5 30FT J1 | 30 ft Cable | | |
| CAT5 50FT J1 | 50 ft Cable | | |

Warranty

Five-year limited warranty. Complete warranty terms located at: www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Note: Actual performance may differ as a result of end-user environment and application. Specifications subject to change without notice.