
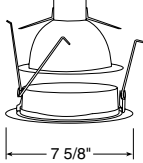


 





 


 








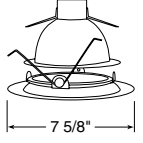

 


 


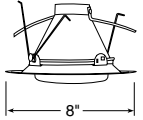


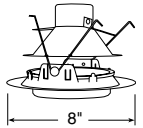







Project: _____

Fixture Type: _____

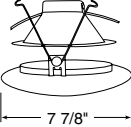Location: _____

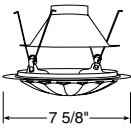Contact/Phone: _____

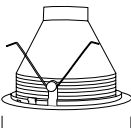Trim Series	Dimensions	Aperture	Catalog No.	Housing/Lamp Compatibility
 <p>Frosted Lens with Reflector</p>	 <p>7 5/8"</p>	 <p>Wet Location</p>	<p>239-WH - Frosted Lens, White Trim</p>	<p>IC2: 40W A19, 35W PAR30L TC2: 100W A19, TC2R: 75W A19 IC22LEDG4/IC22RLEDG4/IC22LWDG4N/IC22RLWDG4N Series* IC922LEDG4/IC922RLEDG4/IC922LWDG4/IC922RLWDG4 Series* IC1422LEDG4 Series*, TC1422LED4 Series*, TC922LEDG4 Series* ICPL/PL613: 13W, ICPL/PL618: 18W, ICPL626 Series: 26W, ICPL632 Series: 32W, PL642 Series: 32W</p>
*Do not use reflector shipped with trim for LED Housing.				
 <p>Albalite</p>	 <p>8"</p>	 <p>Wet Location</p>	<p>20-PW - Shower/Closet Light, Plastic White 20-WH - White Trim</p>	<p>IC2: 40W A19, TC2/TC2R: 70W A19 IC22LEDG4/IC22RLEDG4/IC22LWDG4N/IC22RLWDG4N Series IC922LEDG4/IC922RLEDG4/IC922LWDG4/IC922RLWDG4 Series IC1422LEDG4 Series, TC1422LED4 Series, TC922LEDG4 Series APT2: 75W A19</p>
 <p>Albalite Lens with Reflector</p>	 <p>7 5/8"</p>	 <p>Wet Location</p>	<p>220-PW - Shower/Closet Light, Plastic White 220-WH - White Trim</p>	<p>ICPL626 Series: 26W, ICPL632 Series: 26W, PL642 Series: 26W</p>
 <p>Albalite with Reflector</p>	 <p>8"</p>	 <p>Wet Location</p>	<p>240-PW - Shower/Closet Light, Plastic White 240-WH - White Trim</p>	<p>IC2: 60W A19, TC2/TC2R: 100W A19 ICPL/PL613: 13W, ICPL/PL618: 18W APT2: 75W A19</p>
 <p>Drop Opal</p>	 <p>8"</p>	 <p>Wet Location</p>	<p>21-PW - Shower/Closet Light, Plastic White 21-WH - White Trim</p>	<p>IC2: 40W A19, TC2/TC2R: 75W A19 IC22LEDG4/IC22RLEDG4/IC22LWDG4N/IC22RLWDG4N Series IC922LEDG4/IC922RLEDG4/IC922LWDG4/IC922RLWDG4 Series IC1422LEDG4 Series, TC1422LED4 Series, TC922LEDG4 Series APT2: 75W A19</p>
 <p>Drop Opal with Reflector</p>	 <p>8"</p>	 <p>Wet Location</p>	<p>241-PW - Shower/Closet Light, Plastic White 241-WH - White Trim</p>	<p>IC2: 60W A19, TC2/TC2R: 100W A19 IC21/IC21R: 40W A19 IC22/IC22W/IC22S/IC22R/IC23/IC23W: 40W A19 ICPL/PL613: 13W, ICPL/PL618: 18W, ICPL626 Series: 26W, ICPL632 Series: 26W, PL642 Series: 26W APT2: 100W A19</p>
 <p>Drop Opal with Reflector</p>	 <p>8"</p>	 <p>Wet Location</p>	<p>271-PW - Plastic White</p>	<p>ICPL/PL613: 13W, ICPL/PL618: 18W, ICPL626 Series: 26W, ICPL632 Series: 32W, PL642 Series: 32W</p>

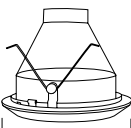Trim Series	Dimensions	Aperture	Catalog No.	Housing/Lamp Compatibility
 <p>Frosted Lens with Clear Center</p>	 <p>7 3/8"</p>	 <p>Wet Location</p>	<p>242-ABZ - Classic Aged Bronze Trim 242-SC - Satin Chrome Trim 242-WH - White Trim</p>	<p>IC2: 75W PAR38, TC2/TC2R: 120W PAR38 IC22/IC22W/IC22S/IC22R: 45W PAR38 IC22LEDG4/IC22RLEDG4/IC22LWDG4N/IC22RLWDG4N Series IC922LEDG4/IC922RLEDG4/IC922LWDG4/IC922RLWDG4 Series IC1422LEDG4 Series, TC1422LED4 Series, TC922LEDG4 Series ICPL626 Series: 26W, ICPL632 Series: 32W, PL642 Series: 32W APT2: 120W PAR38</p>
 <p>Fresnel</p>	 <p>8"</p>	 <p>Wet Location</p>	<p>22-WH - White Trim</p>	<p>IC2: 40W A19, TC2/TC2R: 75W A19 IC22LEDG4/IC22RLEDG4/IC22LWDG4N/IC22RLWDG4N Series IC922LEDG4/IC922RLEDG4/IC922LWDG4/IC922RLWDG4 Series IC1422LEDG4 Series, TC1422LED4 Series, TC922LEDG4 Series ICPL626 Series: 26W, PL642 Series: 32W APT2: 75W A19</p>
 <p>Decorative Swirled Etched Opal Glass</p>	 <p>7 7/8"</p>	 <p>Wet Location</p>	<p>243-WH - Opal Glass</p>	<p>IC2: 60W A19 TC2/TC2R: 100W A19 IC22LEDG4/IC22RLEDG4/IC22LWDG4N/IC22RLWDG4N Series* IC922LEDG4/IC922RLEDG4/IC922LWDG4/IC922RLWDG4 Series* IC1422LEDG4 Series*, TC1422LED4 Series*, TC922LEDG4 Series* ICPL/PL613: 13W, ICPL/PL618: 18W, ICPL626 Series: 26W, ICPL632 Series: 32W, PL642 Series: 32W</p>
*Do not use reflector shipped with trim for LED Housing.				
 <p>Fluted Drop Opal</p>	 <p>7 5/8"</p>	 <p>Wet Location</p>	<p>9900-WH - White Trim</p>	<p>IC2: 60W A19 TC2/TC2R: 75W A19 ICPL/PL613: 13W, ICPL/PL618: 18W, ICPL626 Series: 26W, ICPL632 Series: 32W, PL642 Series: 26W APT2: 75W A19</p>
 <p>Baffle, Regressed Frosted Dome Lens</p>	 <p>7 5/8"</p>	 <p>Wet Location</p>	<p>2330W-WH - White Baffle, White Trim 2330B-WH - Black Baffle, White Trim</p>	<p>ICPL/PL613: 13W, ICPL/PL618: 18W, ICPL626 Series: 26W, ICPL632 Series: 32W, PL642 Series: 32W IC22LEDG4/IC22RLEDG4/IC22LWDG4N/IC22RLWDG4N Series* IC922LEDG4/IC922RLEDG4/IC922LWDG4/IC922RLWDG4 Series* IC1422LEDG4 Series*, TC1422LED4 Series*, TC922LEDG4 Series*</p>
*Do not use reflector shipped with trim for LED Housing.				
 <p>Beveled Frame Frosted Dome Lens</p>	 <p>7 5/8"</p>	 <p>Wet Location</p>	<p>6101-ABZ - Classic Aged Bronze Trim 6101-SC - Satin Chrome Trim 6101-WH - White Trim</p>	<p>ICPL/PL613: 13W, ICPL/PL618: 18W, ICPL626 Series: 26W, ICPL632 Series: 32W, PL642 Series: 42W IC22LEDG4/IC22RLEDG4/IC22LWDG4N/IC22RLWDG4N Series* IC922LEDG4/IC922RLEDG4/IC922LWDG4/IC922RLWDG4 Series* IC1422LEDG4 Series*, TC1422LED4 Series*, TC922LEDG4 Series*</p>
*Do not use reflector shipped with trim for LED Housing.				