


TECHNICAL INFORMATION BULLETIN

ORDERING INFORMATION

Order code: **61949**
 Description: **T120V/60W/AR/MC/STD**
 UPC: 69549619494
 Warranty: 3 Years
 Certification: 

GENERAL INFORMATION


Ballast type: Halogen transformer
 Transformer Type: Electronic
 Lamp Connection: Parallel
 Input Voltage: 120 VAC ±10 %
 Input Frequency: 50/60 Hz
 Minimum Starting Temperature: 0 °F, -18 °C
 Maximum Case Temperature: 167 °F, 75 °C
 Transient Protection meets ANSI: ANSI/IEEE C62.41 Cat. A
 Short Circuit Protection: Yes
 Class: Class 2 transformer
 Dimmable: Yes

Lamp type	Input Watts (W)	Input Current (A)	Power Factor	Output Voltage (V)
12 V Halogen lamps	60	0.51	0.98	11.8


BALLAST DIMENSIONS

Length (L):	2.28 in.
Width (W):	1.30 in.
Height (H):	0.79 in.
Lead Length:	
White, Black:	8 in.
Red:	6 in.
Case material:	Aluminum


CASE DIAGRAM

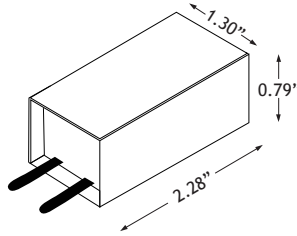

WIRING DIAGRAM

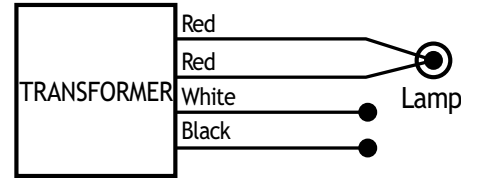

HOT SPOT LOCATION

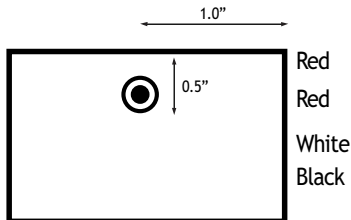

Data is based upon tests performed in a controlled environment and representative of relative performance. Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.