

## ORDERING INFORMATION


Order code: 10483  
 Description: FB32T8/35K/8/U6/RS/G13/STD ESV  
 UPC: 69549104839  
 Case quantity: 20

## PERFORMANCE DATA


Shape: T8  
 Base: G13 (Med Bipin)  
 Starting method: Rapid Start (RS)  
 Wattage (W): 32  
 Colour temperature (K): 3 500  
 CRI: 85  
 Rated life on IS<sup>1</sup> ballast:  
     Based on a 3 hour start 20 000  
 Initial lumens (lm): 2 800  
 Mean lumens (lm): 2 550  
 Nominal efficiency (lm/W): 88  
 TCLP compliant: Yes  
 Phosphor composition: Triphosphor  
 Nominal lamp operating frequency (Hz): 60  
<sup>2</sup> Minimum starting temperature (°C): -10

Nominal length : 22 ½ in. (572 mm)    Dia. : 1 in. (26 mm)

## DIMENSIONS

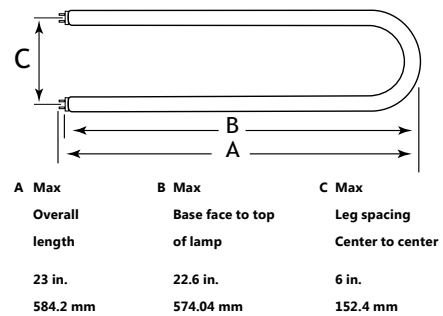

## SPECTRAL DISTRIBUTION

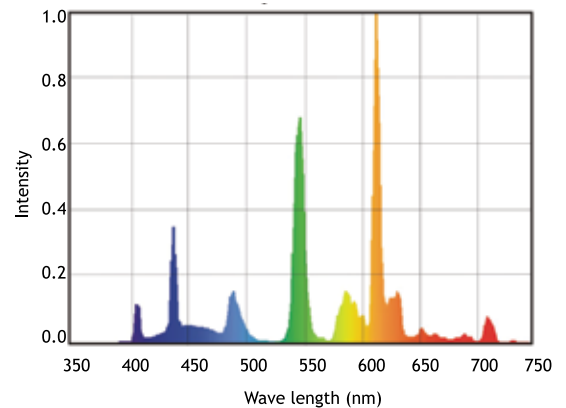

<sup>1</sup> The life rating indicated is based on 3 hour burning cycles under specified conditions and with ballast meeting ANSI specifications.

<sup>2</sup> The minimum starting temperature is a function of the ballast. The minimum starting temperature is based on a STANDARD brand T8 U-Bent 800 series ballast.



**E** Means this bulb meets federal minimum efficiency standards.