


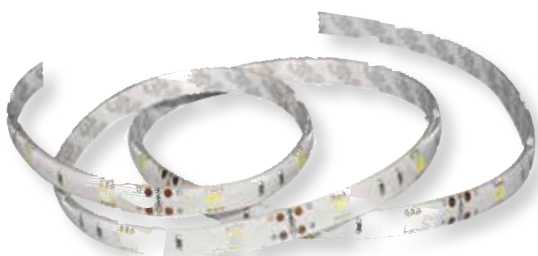

LED Linear Lights

STANDARD's flexible LED linear lights are designed to add ambience and character to any setting. Delivering even, brilliant light, the colour changing RGB, cool white and warm white colours can be used in a multitude of applications, both indoor and outdoor, ranging from under cabinets to cove and perimeter applications.



RGB



Cool White



Warm White

Linear Decorative



Kit includes

- ▶ Tape light
- ▶ 1 power supply
- ▶ Remote control (for RGB kit only)
- ▶ RGB controller (for RGB kit only)

Order code	Description	Watts ¹ (W)	Volts (VDC)	Colour	Average life (hrs)	Lumen output per foot	LED per foot	Length (ft) (m)	IP rating	Dimmable (Yes/No)	Case qty
------------	-------------	---------------------------	----------------	--------	-----------------------	--------------------------	-----------------	--------------------	-----------	----------------------	-------------

Low Voltage Tape Light Kit

61953	LED/TAPE/16.4/5050/RGB KIT/12V/50M/STD	27	12	RGB	50 000	-	9	16.4 5	64	Y	20
61954	LED/TAPE/16.4/5050/WW KIT/12V/50M/STD	28	12	Warm white	50 000	145	9	16.4 5	64	N	20
61955	LED/TAPE/16.4/5050/CW KIT/12V/50M/STD	28	12	Cool white	50 000	145	9	16.4 5	64	N	20

Power Supply

Length : 3 3/4 in. (95 mm) Width : 1 1/4 in. (43 mm) Height : 3/16 in. (30 mm)

62265	LED/TAPE/WW+CW/PS/STD	-	12	White	-	-	-	6.56 2	-	-	50
62266	LED/TAPE/RGB/PS/STD	-	12	White	-	-	-	6.56 2	-	-	50

Accessories

61956	LED/TAPE/RGB/CONNECTOR/STD	-	-	-	-	-	-	0.56 0.17	-	-	10
61957	LED/TAPE/WW+CW/CONNECTOR/STD	-	-	-	-	-	-	0.56 0.17	-	-	10
62017	LED/10PCS TAPE LIGHT 12V MOUNTING CLIPS	-	-	-	-	-	-	-	-	-	100

NOTE: To avoid decreases in light levels, avoid connecting more 16.4' (5 m) at a time.
¹ Watts for 16.4' (5 m)

