



## T2 Spirals

Order code	Description	Watts (W)	Base	Colour temp. (K)	CRI	Average life (hrs)	Initial lumens (lm)	Incandescent equivalent (W)	Case qty
62764	CF7/T2/27K/SPIRAL/E26/ELUME	7	E26	2 700	82	10 000	430	40	48
61020	CF9/T2/27K/SPIRAL/E26/ELUME	9	E26	2 700	82	10 000	550	40	48
62311	CF9/T2/41K/SPIRAL/E26/ELUME	9	E26	4 100	82	10 000	550	40	48
62765	CF11/T2/27K/SPIRAL/E26/ELUME	11	E26	2 700	82	10 000	730	40	48
61021	CF13/T2/27K/SPIRAL/E26/ELUME	13	E26	2 700	82	10 000	900	60	48
61024	CF13/T2/30K/SPIRAL/E26/ELUME	13	E26	3 000	82	10 000	900	60	48
61026	CF13/T2/35K/SPIRAL/E26/ELUME	13	E26	3 500	82	10 000	850	60	48
61029	CF15/T2/27K/SPIRAL/E26/ELUME	15	E26	2 700	82	10 000	1 010	60	48
61030	CF15/T2/30K/SPIRAL/E26/ELUME	15	E26	3 000	82	10 000	1 010	60	48
61031	CF20/T2/27K/SPIRAL/E26/ELUME	20	E26	2 700	82	10 000	1 330	75	48
61032	CF23/T2/27K/SPIRAL/E26/ELUME	23	E26	2 700	82	10 000	1 600	100	48
61033	CF23/T2/30K/SPIRAL/E26/ELUME	23	E26	3 000	82	10 000	1 600	100	48
61034	CF23/T2/41K/SPIRAL/E26/ELUME	23	E26	4 100	82	10 000	1 600	100	48
61035	CF23/T2/50K/SPIRAL/E26/ELUME	23	E26	5 000	82	10 000	1 600	100	48

12 pack




4 pack



Order code	Description	Watts (W)	Base	Colour temp. (K)	CRI	Average life (hrs)	Initial lumens (lm)	Incandescent equivalent (W)	Case qty
61022	CF13/T2/27K/SPIRAL/E26/ELUME 4P	13	E26	2 700	82	10 000	900	60	64
61025	CF13/T2/30K/SPIRAL/E26/ELUME 4P	13	E26	3 000	82	10 000	900	60	64
61027	CF13/T2/41K/SPIRAL/E26/ELUME 4P	13	E26	4 100	82	10 000	880	60	64
61028	CF13/T2/50K/SPIRAL/E26/ELUME 4P	13	E26	5 000	82	10 000	880	60	64
61023	CF13/T2/27K/SPIRAL/E26/ELUME 12P	13	E26	2 700	82	10 000	900	60	48

Starting temperature: -18 °C/0 °F  
 Visit our website for a complete listing of all E-LUME ENERGY STAR qualified products

# CFL Lamps

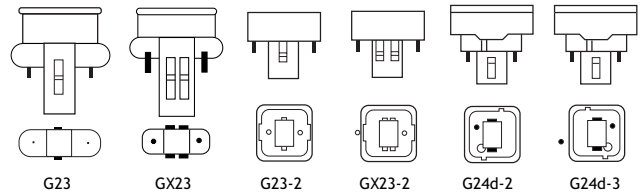

## 2-Pin Lamp Bases

Order code	Description	Watts (W)	Base	Colour temp. (K)	CRI	Average life (hrs)	Initial lumens (lm)	MOL (in.) (mm)	Case qty
------------	-------------	-----------	------	------------------	-----	--------------------	---------------------	----------------	----------

### 2-PIN Twin Tube

14105	PL5/27K/TT/2P/ELUME	5	G-23	2700	82	10000	210	4 1/8 105	96
14031	PL7/27K/TT/2P/ELUME	7	G-23	2700	82	10000	360	5 9/16 135	96
14032	PL7/41K/TT/2P/ELUME	7	G-23	4100	82	10000	360	5 9/16 135	96
14033	PL9/27K/TT/2P/ELUME	9	G-23	2700	82	10000	525	6 1/2 165	96
14034	PL9/41K/TT/2P/ELUME	9	G-23	4100	82	10000	525	6 1/2 165	96
14035	PL13/27K/TT/2P/ELUME	13	GX-23	2700	82	10000	720	7 3/32 180	96
14107	PL13/35K/TT/2P/ELUME	13	GX-23	3500	82	10000	720	7 3/32 180	96
14036	PL13/41K/TT/2P/ELUME	13	GX-23	4100	82	10000	720	7 3/32 180	96

### 2-PIN Double Twin Tube

14106	PL9/27K/DTT/2P/ELUME	9	G23-2	2700	82	10000	475	4 11/32 110	96
14037	PL13/27K/DTT/2P/ELUME	13	GX23-2	2700	82	10000	810	4 21/32 118	96
14108	PL13/35K/DTT/2P/ELUME	13	GX23-2	3500	82	10000	810	4 21/32 118	96
14109	PL13/41K/DTT/2P/ELUME	13	GX23-2	4100	82	10000	810	4 21/32 118	96
14112	PL18/41K/DTT/2P/ELUME	18	G24d-2	4100	82	10000	1035	5 31/32 152	96
14113	PL26/27K/DTT/2P/ELUME	26	G24d-3	2700	82	10000	1540	6 13/16 173	96
14114	PL26/35K/DTT/2P/ELUME	26	G24d-3	3500	82	10000	1540	6 13/16 173	96
14115	PL26/41K/DTT/2P/ELUME	26	G24d-3	4100	82	10000	1540	6 13/16 173	96



Twin Tube




Double Twin Tube

# CFL Lamps



## 4-Pin Lamp Bases

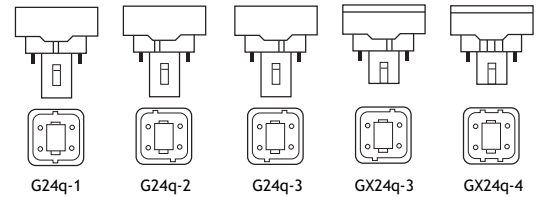

Order code	Description	Watts (W)	Base	Colour temp. (K)	CRI	Average life (hrs)	Initial lumens (lm)	MOL (in.)	MOL (mm)	Case qty
------------	-------------	-----------	------	------------------	-----	--------------------	---------------------	-----------	----------	----------

### 4-PIN Double Twin Tube

14116	PL13/27K/DTT/4P/ELUME	13	G24q-1	2700	82	10000	810	5 5/32	131	96
14117	PL13/30K/DTT/4P/ELUME	13	G24q-1	3000	82	10000	810	5 5/32	131	96
14118	PL13/35K/DTT/4P/ELUME	13	G24q-1	3500	82	10000	810	5 5/32	131	96
14119	PL13/41K/DTT/4P/ELUME	13	G24q-1	4100	82	10000	810	5 5/32	131	96
14120	PL18/30K/DTT/4P/ELUME	18	G24q-2	3000	82	10000	1035	5 25/32	147	96
14121	PL18/35K/DTT/4P/ELUME	18	G24q-2	3500	82	10000	1035	5 25/32	147	96
14122	PL18/41K/DTT/4P/ELUME	18	G24q-2	4100	82	10000	1035	5 25/32	147	96
14123	PL26/27K/DTT/4P/ELUME	26	G24q-3	2700	82	10000	1540	6 1/2	165	96
14124	PL26/30K/DTT/4P/ELUME	26	G24q-3	3000	82	10000	1540	6 1/2	165	96
14125	PL26/35K/DTT/4P/ELUME	26	G24q-3	3500	82	10000	1540	6 1/2	165	96
14126	PL26/41K/DTT/4P/ELUME	26	G24q-3	4100	82	10000	1540	6 1/2	165	96

### 4-PIN Triple Twin Tube

14128	PL26/35K/TTT/4P/ELUME	26	GX24q-3	3500	82	10000	1620	5 5/32	131	96
14129	PL26/41K/TTT/4P/ELUME	26	GX24q-3	4100	82	10000	1620	5 5/32	131	96
14130	PL32/30K/TTT/4P/ELUME	32	GX24q-3	3000	82	10000	2160	5 25/32	147	96
14131	PL32/35K/TTT/4P/ELUME	32	GX24q-3	3500	82	10000	2160	5 25/32	147	96
14132	PL32/41K/TTT/4P/ELUME	32	GX24q-3	4100	82	10000	2160	5 25/32	147	96
14134	PL42/35K/TTT/4P/ELUME	42	GX24q-4	3500	82	10000	2880	6 1/2	165	96
14135	PL42/41K/TTT/4P/ELUME	42	GX24q-4	4100	82	10000	2880	6 1/2	165	96





PAR20



PAR30LN



PAR38



Order code	Description	Watts (W)	Base	Colour temp. (K)	CRI	Average life (hrs)	Initial lumens (lm)	Halogen equivalent (W)	Case qty
<b>PAR20</b>									
MOL : 3 3/4 in. (95 mm)      Dia. : 2 15/32 in. (63 mm)									
59674	CF9/41K/PAR20/E26/ELUME	9	E26	4 100	82	8 000	300	50	48
<b>PAR30LN</b>									
MOL : 5 in. (127 mm)      Dia. : 3 3/4 in. (95 mm)									
59676	CF15/41K/PAR30LN/E26/ELUME	15	E26	4 100	82	8 000	700	75	24
<b>PAR38</b>									
MOL : 5 15/32 in. (139 mm)      Dia. : 4 13/16 in. (122 mm)									
59671	CF23/27K/PAR38/E26/ELUME	23	E26	2 700	82	8 000	1 280	90	24
59672	CF23/30K/PAR38/E26/ELUME	23	E26	3 000	82	8 000	1 280	90	24
59670	CF23/41K/PAR38/E26/ELUME	23	E26	4 100	82	8 000	1 280	90	24

# CFL Lamps