



## 4 1/4" Housings



Order code	Description	Opening diameter (In.)	Volts (V)	Socket	Case qty
------------	-------------	------------------------	-----------	--------	----------

### Remodeler - IC\*\* Airtight

64359	RF4in/REMOD/IC/LED/E26/ELUME	4 1/4	120	E26	6
64360	RF4in/REMOD/IC/LED/GU10/ELUME	4 1/4	120	GU10	6

### New Construction - IC\*\* Airtight

64361	RF4in/NC/IC/NOBOX/LED/GU10/ELUME	4 1/4	120	GU10	6
64362	RF4in/NC/IC/NOBOX/LED/E26/ELUME	4 1/4	120	E26	6

### New Construction - IC Airtight

64363 <sup>1</sup>	RF4in/NC/IC/E26/ELUME	4 1/4	120	E26	6
64364 <sup>1</sup>	RF4in/NC/IC/GU10/ELUME	4 1/4	120	GU10	6




\*For complete warranty information please visit [www.standardpro.com](http://www.standardpro.com)  
 \*\*Only valid with LED lamps

# Recessed Fixtures



## 4 1/4" Shower Trims - MR16 (GU10 & E26) & PAR16

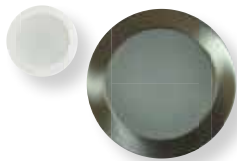


Order code	Description	Colour	Rotation angle (°)	Case qty
<b>Shower</b> Shape: Round Aperture: Round Dia. : 4 in. (101.6 mm)				
64386	RF4/TRIM/SWR/BR.NKL/MR16/ELUME	Brushed Nickel	NA	24
64388	RF4/TRIM/SWR/WH/MR16/ELUME	White	NA	24

### Compatible Lamps



## 4 1/4" Shower Trims - PAR20

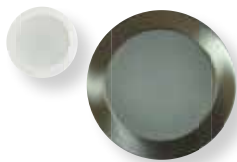

Order code	Description	Colour	Rotation angle (°)	Case qty
<b>Shower</b> Shape: Round Aperture: Round Dia. : 4 in. (101.6 mm)				
64387	RF4/TRIM/SWR/BR.NKL/PAR20/ELUME	Brushed Nickel	NA	24
64389	RF4/TRIM/SWR/WH/PAR20/ELUME	White	NA	24

### Compatible Lamps



Notes: Not recommended for use in steam showers or when directly exposed to water.  
 † Enclosed fixtures may reduce the LED or CFL lamp life.