



LED Gimbal Downlight

STANDARD's LED Gimbal Downlights are easy to install and allow you to direct the light where needed! The interchangeable trims give you many options to choose from and flexible installation. Whether in new construction or in retrofit applications, the module and trim combination will fit any application!

| Order code | Description | Watts (W) | Finish colour | Volts (VAC) | Colour temp. (K) | CRI | Average life ¹ (hrs) | Initial lumens ² (lm) | Traditional equivalent (W) | Beam angle (°) | Dimmable ³ (Yes/No) | Case qty |
|------------|-------------|-----------|---------------|-------------|------------------|-----|---------------------------------|----------------------------------|----------------------------|----------------|--------------------------------|----------|
|------------|-------------|-----------|---------------|-------------|------------------|-----|---------------------------------|----------------------------------|----------------------------|----------------|--------------------------------|----------|

Module Warm-Dim⁴

| | | | | | | | | | | | | |
|--------|------------------------------------|---|----------------|-----|---------------|-----|--------|-----|----|----|-----|------|
| 65981* | LED/DL/GIMBAL/MOD/7W/30-22K/WH/STD | 7 | White | 120 | 2 200 - 3 000 | >90 | 50 000 | 470 | 50 | 40 | Yes | 1/18 |
| 65982* | LED/DL/GIMBAL/MOD/7W/30-22K/BN/STD | 7 | Brushed Nickel | 120 | 2 200 - 3 000 | >90 | 50 000 | 470 | 50 | 40 | Yes | 1/18 |

Module

| | | | | | | | | | | | | |
|-------|---------------------------------|---|----------------|-----|-------|-----|--------|-----|----|----|-----|------|
| 65420 | LED/DL/GIMBAL/MOD/7W/30K/WH/STD | 7 | White | 120 | 3 000 | >80 | 50 000 | 600 | 50 | 40 | Yes | 1/18 |
| 65421 | LED/DL/GIMBAL/MOD/7W/40K/WH/STD | 7 | White | 120 | 4 000 | >80 | 50 000 | 620 | 50 | 40 | Yes | 1/18 |
| 65422 | LED/DL/GIMBAL/MOD/7W/30K/BN/STD | 7 | Brushed Nickel | 120 | 3 000 | >80 | 50 000 | 600 | 50 | 40 | Yes | 1/18 |
| 65423 | LED/DL/GIMBAL/MOD/7W/40K/BN/STD | 7 | Brushed Nickel | 120 | 4 000 | >80 | 50 000 | 620 | 50 | 40 | Yes | 1/18 |

| Order code | Description | Finish | Shape | Type | Case qty |
|------------|-------------|--------|-------|------|----------|
|------------|-------------|--------|-------|------|----------|

3" Trims


| | | | | | |
|-------|--|----------------|--------|--------|------|
| 65432 | LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/WH/STD | White | Round | Flat | 1/96 |
| 65433 | LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/BN/STD | Brushed Nickel | Round | Flat | 1/96 |
| 65434 | LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/WH/STD | White | Square | Flat | 1/96 |
| 65435 | LED/DL/GIMBAL/3IN/TRIM/SQR/FLAT/BN/STD | Brushed Nickel | Square | Flat | 1/96 |
| 65450 | LED/DL/GIMBAL/3IN/TRIM/RND/CURVED/WH/STD | White | Round | Curved | 1/96 |
| 65451 | LED/DL/GIMBAL/3IN/TRIM/RND/CURVED/BN/STD | Brushed Nickel | Round | Curved | 1/96 |

4" Trims

| | | | | | |
|-------|--|----------------|--------|------|------|
| 65436 | LED/DL/GIMBAL/4IN/TRIM/RND/FLAT/WH/STD | White | Round | Flat | 1/96 |
| 65437 | LED/DL/GIMBAL/4IN/TRIM/RND/FLAT/BN/STD | Brushed Nickel | Round | Flat | 1/96 |
| 65438 | LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/WH/STD | White | Square | Flat | 1/96 |
| 65439 | LED/DL/GIMBAL/4IN/TRIM/SQR/FLAT/BN/STD | Brushed Nickel | Square | Flat | 1/96 |

Accessories

| Order Code | Description | Type | Compatibility |
|------------|---------------------------|---------------------------------|---------------|
| 64264 | LPDL/ACC/6FT/EXTCABLE/STD | 6' extension cord | All modules |
| 66020 | ACC/MPLATE/2.75IN/SQR/STD | 2 3/4" square mounting plate | All modules |
| 66021 | ACC/MPLATE/2.75IN/ADJ/STD | 2 3/4" adjustable mounting plat | All modules |

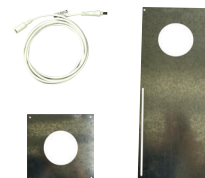

*Delivery in October 2017

¹Life rating based on L70 lumen depreciation design criteria. Average life of downlight that have been approved for ENERGY STAR early submission or complete submission can vary. ENERGY STAR early submission dictates that manufacturers can only claim 40 000 hour life with 3 000 hour actual life test data, 6 000 hour LM-80 data and in-situ temperature measurements. Once a product has been fully qualified, manufacturers may increase the lifetime of a product by demonstrating full compliance with the ENERGY STAR criteria at the new lifetime with lumen maintenance at the minimum required test period.

² Typical lumens +/- 10 %

³ For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit www.standardpro.com






LED Gimbal Downlight

- Mimics the look of a traditional halogen
- Designed for a sleek and glare free result
- Light output comparable to a PAR20 halogen lamp
- 360° module rotation to light any direction
- 3" and 4" trims perfect for new construction and retrofit



24° tilt

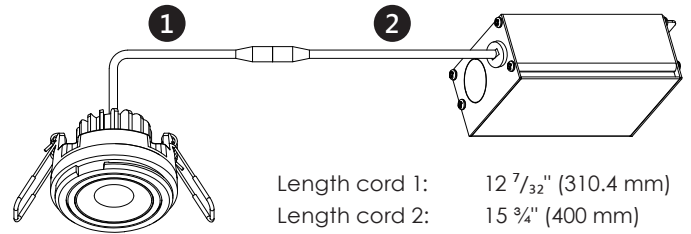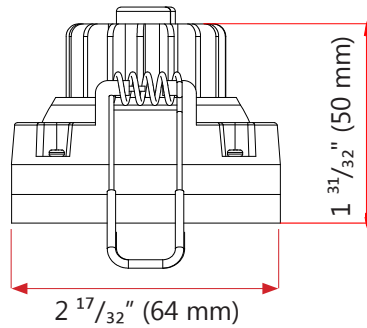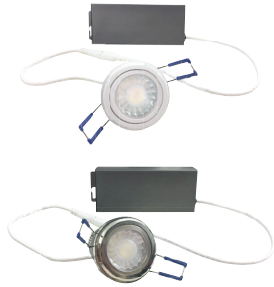

3" Trims

White round curved



White round flat




White square flat



1 7/8" (47.5 mm)

Brushed Nickel round curved

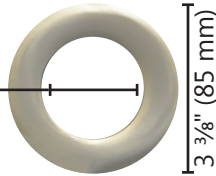


Brushed Nickel round flat



1 7/8" (47.5 mm)


Brushed Nickel square flat

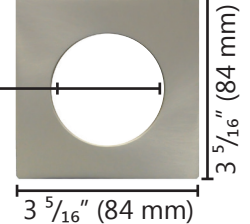

4" Trims

1 7/8" (47.5 mm)

White round flat

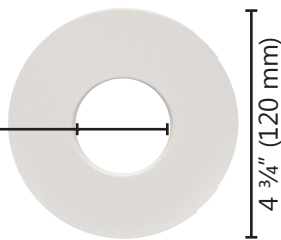

White square flat



Brushed Nickel round flat



1 7/8" (47.5 mm)

Brushed Nickel square flat

