


MINIATURES

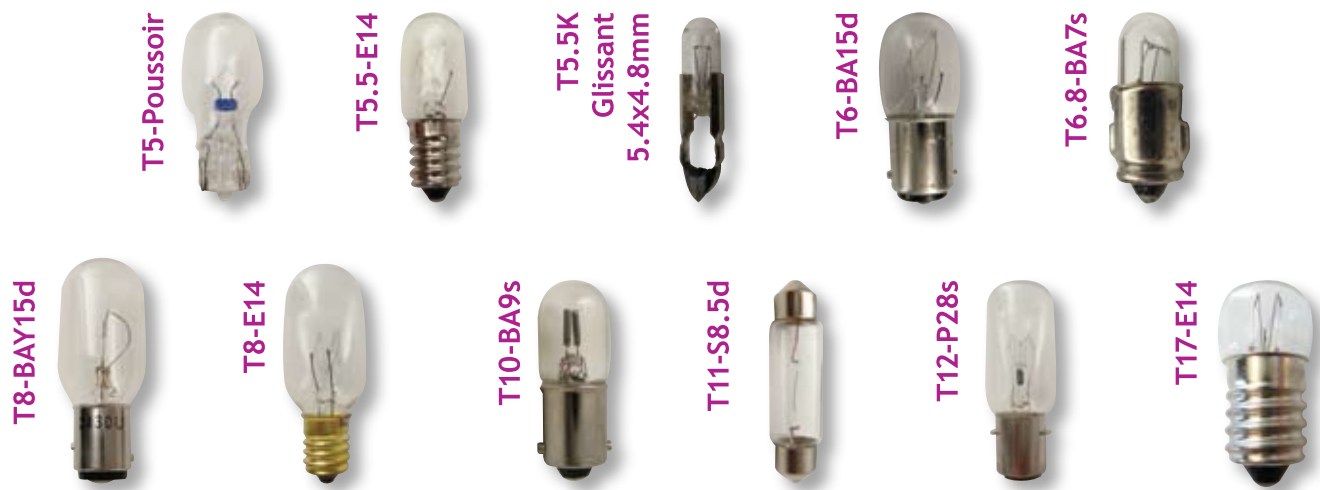

Les images ne sont pas à l'échelle. Toutes les lampes sont claires.

Code de commande	Description	Code de lampe	Forme	Culot	Tension (V)	Ampères (A)	Puissance (W)	Vie moyenne (h)	Diamètre (po) (mm)	HCL (po) (mm)	LHTM (po) (mm)	Qté paq.
------------------	-------------	---------------	-------	-------	-------------	-------------	---------------	-----------------	--------------------	---------------	----------------	----------

T (cont.)

50400	T5/CL/6V/1.5A/WDG/STD	908	T-5	Poussoir	6.00	1.500	9	50	0.63 15.90	0.81 20.60	1.50 38.00	10
50402	T5/CL/12V/0.75A/WDG/STD	915	T-5	Poussoir	12.00	0.750	9	50	0.63 15.90	0.81 20.60	1.50 38.00	10
22055	T5/CL/12.8V/0.31A/WDG/STD	901	T-5	Poussoir	12.80	0.310	4	500	0.63 15.90	0.81 20.60	1.50 38.00	10
50403	T5/CL/12.8V/0.56A/WDG/STD	918	T-5	Poussoir	12.80	0.560	7	50	0.63 15.90	0.81 20.60	1.50 38.00	10
50401	T5/CL/12.8V/1A/WDG/STD	912	T-5	Poussoir	12.80	1.000	13	1200	0.63 15.90	0.81 20.60	1.50 38.00	10
50404	T5/CL/12.8V/1.4A/WDG/STD	921	T-5	Poussoir	12.80	1.400	18	500	0.63 15.90	0.81 20.60	1.50 38.00	10
50399	T5/CL/13V/0.69A/WDG/STD	906	T-5	Poussoir	13.00	0.690	9	1000	0.63 15.90	0.81 20.60	1.50 38.00	10
50398	T5/CL/13.5V/0.69A/WDG/STD	904	T-5	Poussoir	13.50	0.690	9	5000	0.63 15.90	0.81 20.60	1.50 38.00	10
50318	9T5/CL/24V/WDG/STD	EMS-2409W	T-5	Poussoir	24.00	0.375	9	75	0.63 15.90	0.81 20.60	1.50 38.00	10
50320	18T5/CL/24V/WDG/STD	EMS-2218W	T-5	Poussoir	24.00	0.750	18	75	0.63 15.90	0.81 20.60	1.50 38.00	10
13022	10T5.5/CL/130V/E14	S.O.	T-5.5	E14	130.00	0.077	10	2000	0.74 18.80	1.48 37.50	2.13 54.00	10
50705	T5.5K/CL/30V/0.04A/SLB/STD	ATS-5804	T-5.5K	Glissant 5.4x4.8mm	30.00	0.040	1	5000	0.22 5.50	0.79 20.00	0.87 22.00	10
50708	5T6/CL/24V/BA15d/STD	SP-117	T-6	BA15d	24.00	0.208	5	1000	0.75 19.10	1.13 28.60	1.89 48.00	10
50709	10T6/CL/115V/BA15d/STD	SP-22	T-6	BA15d	115.00	0.087	10	1000	0.75 19.10	1.13 28.60	1.89 48.00	10
50259	1.2T6.8/CL/60V/BA7s/STD	6020S	T-6.8	BA7s	60.00	0.012	1	5000	0.27 6.80	0.75 18.98	0.79 20.00	10
22022	25T8/CL/12V/BAY15d/STD	1230U	T-8	BAY15d	12.00	2.083	25	1000	1.00 25.40	1.38 35.00	2.72 69.00	10
22025	25T8/CL/24V/BAY15d/STD	2430U	T-8	BAY15d	24.00	1.042	25	1000	1.00 25.40	1.38 35.00	2.72 69.00	50
22026	25T8/CL/32V/BAY15d/STD	3225U	T-8	BAY15d	32.00	0.781	25	1000	1.00 25.40	1.38 35.00	2.72 69.00	10
50713	15T8/CL/130V/E14/STD	SP-59U	T-8	E14	130.00	0.115	15	2000	1.00 25.40	1.73 43.90	2.56 65.00	10
50714	25T8/CL/130V/E14/STD	SP-60U	T-8	E14	130.00	0.192	25	2000	1.00 25.40	1.73 43.90	2.56 65.00	10
22070	15T8/CL/240V/E14/STD	SP-61U	T-8	E14	240.00	0.063	15	2000	1.00 25.40	1.73 43.90	2.56 65.00	10
10378	25T8/CL/240V/E14/STD	SP-70U	T-8	E14	240.00	0.104	25	2000	1.00 25.40	1.73 43.90	2.56 65.00	10
58706	T10/CL/110V/BA9s/STD	S.O.	T-10	BA9s	110.00	0.080	9	10000	0.39 10.00	0.97 24.53	1.11 28.30	10
22050	5T11/CL/12V/S8.5D/STD	A6413	T-11	S8.5d	12.00	0.417	5	4100	0.39 10.00	0.79 20.00	1.57 40.00	10
50315	5T11/CL/24V/S8.5D/STD	A6424	T-11	S8.5d	24.00	0.208	5	1000	0.39 10.00	0.87 22.00	1.73 44.00	10
50314	5T11/CL/24V/S8.5d/STD	A6423	T-11	S8.5d	24.00	0.208	5	1000	0.39 10.00	0.79 20.00	1.54 39.00	10
22057	10T11/CL/24V/S8.5D/STD	A6425	T-11	S8.5d	24.00	0.417	10	1000	0.39 10.00	0.87 22.00	1.73 44.00	10
22122	40T12/CL/24V/P28s/STD	2450C	T-12	P28s	24.00	1.667	40	1000	1.50 38.10	1.77 45.00	2.72 69.00	25
22118	60T12/CL/110V/P28s/STD	1150C	T-12	P28s	110.00	0.545	60	1000	1.50 38.00	1.77 45.00	4.07 103.50	10
50712	5T17mm/CL/24V/E14/STD	SP-56U	T-17	E14	24.00	0.208	5	2000	0.67 17.00	1.38 35.00	2.13 54.00	10
22068	5T17mm/CL/130V/E14/STD	SP-54U	T-17	E14	130.00	0.038	5	2000	0.67 17.00	1.38 35.00	2.13 54.00	10